


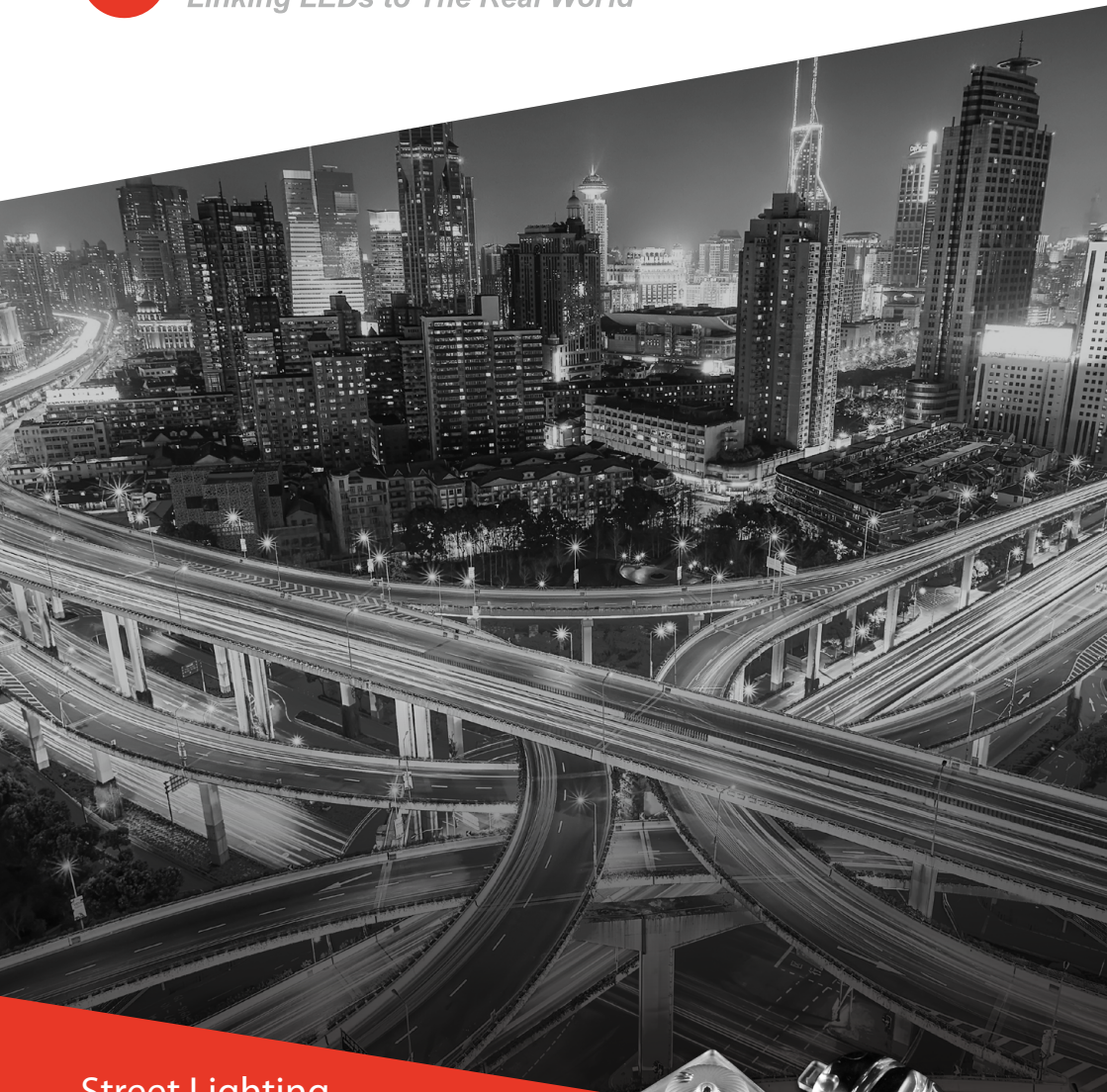

Street Lighting
Single Lens

www.ledlink-optics.com Ver. 1.2



Street Lighting

Single Lens

*All dimensions are in millimeters.



Type	Curve	Part No	FWHM	Dimensions	Tape	LED
I		LL01CR-KM6090L02-T	60°×90°	17.55×11.6×8.6	●	2525 3030 3045 3535
		LL01CR-AU85135L02	85°×135°	18×10.2×6.1	-	
		LL01CR-FT60135L02	60°×135°	18×9.3×5.9	-	2525 3030 3045 3535
		LL01CR-OW70130L02	70°×130°	17.4×12.75×7.2	-	4040 5050
		LL01CR-BAJ85135L02-T	85°×135°	18×12.5×6.1	●	2525 3030 3535
		LL01CR-AEC30140L02	30°×140°	22×19×10	-	5050
		LL01CR-AU45135L46	45°×135°	18.5×13.5×8.53	-	
		LL01CR-PB70140L02	70°×140°	22.4×11.4×6.9	-	2525/3030 3535/4040 5050
		LL01ED-AU70120L02	70°×120°	94×42×28.4	-	LESØ9.9~32
		LL01CR-XW70140L02	70°×140°	32×17.6×9.8	-	3535 5050 7070
		LL01LU-UQ70140L02	70°×140°	18×11×6.6	-	3045 3030 3535

Type	Curve	Part No	FWHM	Dimensions	Tape	LED
II		LL01OS-AU60140L02	60°×140°	16×8.8×5.3	-	
		LL01CR-APM80150L02-T	80°×150°	18×12.5×6.95	●	2525 3030 3045 3535
		LL01LU-AIK45135L02-T	45°×135°	18×12.5×7.05	●	
		LL01LU-AEV50150L02-T	50°×150°	18×12.5×6.3	●	3535 3045
		LL01LU-AGV80150L02	80°×150°	32×18.5×9.5	-	3535 5050 7070
III		LL01CR-OG85150L02	85°×150°	18×8.95×6.2	-	3030 3045 3535
		LL01ZZ-AGX45155L02-T	45°×155°	18×12.5×7	●	2525/3030 3045/3535
		LL01CR-APM95165L19	95°×165°	18×12.5×6.54	-	5050
V		LL01CR-CXE165L19	165°	18×18×5.8	-	3030 3535

Street Lighting

Silicone Material

*All dimensions are in millimeters.

Type	Curve	Part No	FWHM	Dimensions	LED
II		LL01CR-CQW90155L100	90°×155°	100×110.5×31.67	LES Ø6.5~23
III		LL01CR-CQW45150L100	45°×150°	99.7×110.5×32.78	

www.ledlink-optics.com

service@ledlink-optics.com

Ledlink Optics, Inc
Taiwan HQ

15F, No.655,Bannan Rd., Chung-Ho Dist.,
New Taipei City, Taiwan 235

Ledlink Optics (Dongguan) Co., Ltd
Dongguan Factory

No.5, TianKeng Industrial Dist., HengLi Town, DongGuan City,
GuangDong Province, China 523478

Ledlink Optics (Yangzhou) Co., Ltd
Yangzhou Factory

No.180, LinJiang Rd., YangZhou City, Jiangsu Province, China 225009

