

Moduplug Portfolio

Power	HDC MHP 200 AS	HDC MHP 200 PE	HDC MHP 100 AS	HDC MHP 70 AS	HDC MHX 2 AS	HDC MHX 2
						
Current / voltage	200 A / 1000 V	PE	100 A / 1000 V	70 A / 1000 V	40 A / 1000 V	40 A / 830 V
Part Numbers	Axial screw connection Female 2748250000 Male 2748240000	Axial screw connection Female 2748270000 Male 2748260000	Axial screw connection Female 2748290000 Male 2748280000	Axial screw connection Female 2748310000 Male 2748300000	Axial screw connection Female 2748330000 Male 2748320000	Crimp connection Female 2748350000 Male 2748340000
Power	HDC MHP 200	HDC MHP 100	HDC MHP 70	HDC MHX 4P	HDC MHX 3	HDC MHX 3/4
						
Current / voltage	200 A / 1000 V	100 A / 1000 V	70 A / 1000 V	40 A / 830 V	40 A / 690 V	10 A / 500V
Part Numbers	Crimp connection Female 2549260000 Male 2548900000	Crimp connection Female 1429080000 Male 1429060000	Crimp connection Female 2668180000 Male 2668190000	Crimp connection Female 1428970000 Male 1428950000	Crimp connection Female 1429350000 Male 1429340000	Crimp connection Female 2748370000 Male 2748360000
Power	HDC MHE 2 HV					
						
Current / voltage	16 A / 2900 V					
Part Numbers	Crimp connection Female 2748390000 Male 2748380000					

Moduplug Portfolio

Signal	HDC MHD 12	HDC MHD 12	HDC MHD 17	HDC MHD 36
				
Current / voltage	10 A / 250 V	10 A / 250 V	10 A / 160 V	10 A / 250 V
Part Numbers	Push In Connection Female 2748470000 Male 2748460000	Crimp connection Female 1428850000 Male 1428840000	Crimp connection Female 2748490000 Male 2748480000	Crimp connection Female 1428870000 Male 1428860000

Signal	HDC MHE 5	HDC MHE 5L	HDC MHE 6	HDC MHE 6P	HDC MHE 8	HDC MHE 20
						
Current / voltage	16 A / 400 V	16 A / 230 V	16 A / 500 V	16 A / 830 V	16 A / 400 V	16 A / 500 V
Part Numbers	Push In Connection Female 2636190000 Male 2636180000	Push In Connection Female 2748410000 Male 2748400000	Crimp connection Female 6 KV 1429370000 Male 6 KV 1429360000	Crimp connection Female 1505660000 Male 1505650000	Crimp connection Female 1428890000 Male 1428880000	Crimp connection Female 1428930000 Male 1428910000

Moduplug Portfolio

Data	HDC MGBIT 8	HDC C HS 0.2-0.5 AU	HDC C HS 0.08-0.12 AU	HDC MCOAX 4	HDC C COAX 50	HDC C COAX 75
						
Current / voltage	5 A / 50 V	Crimp contact	Crimp contact	1,5 A / 50 V	1,5 A / 50 V	2 A / 250 V
Part Numbers	Crimp connection Female 2748530000 Male 2748520000	Female 2748720000 Male 2748700000	Female 2748730000 Male 2748710000	Crimp connection Female 2748550000 Male 2748540000	Female 2748660000 Male 2748670000	Female 2748680000 Male 2748690000
Data	HDC MEMC 2	HDC MBUS HD 4	HDC MBUS HE 1	HDC MBUS HD 1	HDC MBUS HS 8	
						
Current / voltage	10 A / 50 V	10 A / 50 V	16 A / 50 V	10 A / 50 V	5 A / 50 V	
Part Numbers	Crimp connection Female 2748570000 Male 2748560000	Female 2748580000 Male 2748590000	Female 2748600000 Male 2748610000	Female 2748620000 Male 2748630000	Female 2748640000 Male 2748650000	
Terminal Block	HDC MHE 4X	HDC MHE 4X2	HDC MHE 4	HDC MMARK 4	HDC MXSCC* 4X	
						
	Terminal Block Module	Terminal Block Module w.potential distribution	Terminal Block Module	Markers 64 to a card	Cross-connector bridge 2 to 12 pole	
Part Numbers	Push In Female 2636060000 Male 2636070000	Push In Female 2636080000 Male 2636090000	Push In Female 2635990000 Male 2635980000	2710590000 10 Pack = 640	2709710000 - 2709820000	

Weidmüller

Moduplug Portfolio

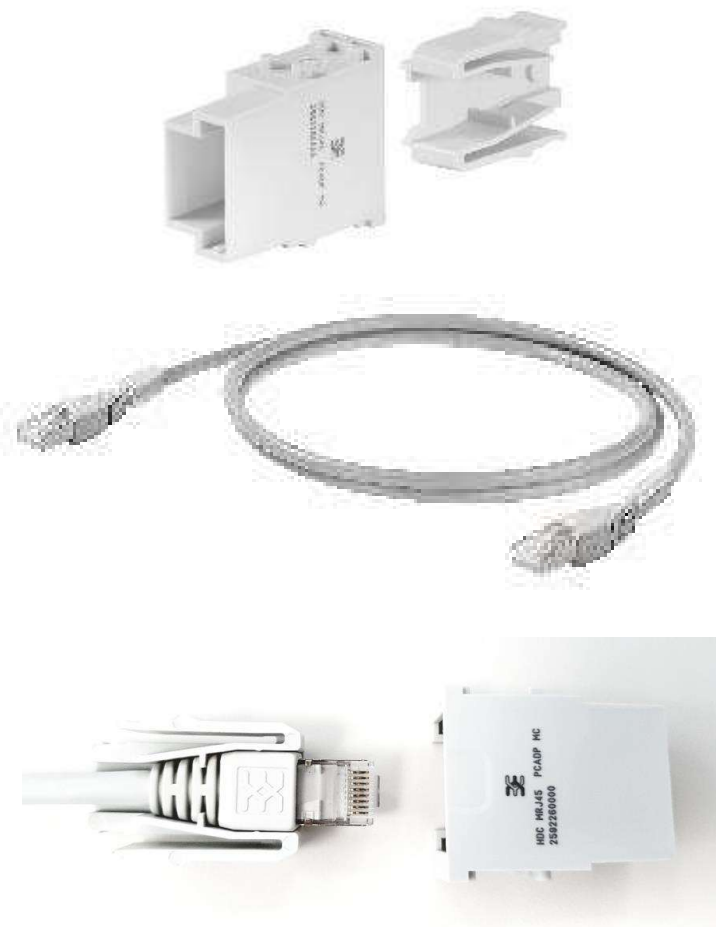
Data	HDC MRJ45 GC	HDC MRJ45 PCADP MC	HDC MRJ45 ABP MI	HDC MRJ45 A MI	HDC MRJ45 B MI	HDC MRJ45 P MI	HDC MRJ45 8 PLUG MC
							
Notes/ Current / voltage	Gender Changer - mating side to all others	Adapter - needs special patch cord (pg3)	TIA-568A, EIA/TIA T568 B, PROFINET	TIA-568A	EIA/TIA T568 B	Profinet	Crimp
Part Numbers	2592030000	2592260000	2592210000	2592220000	2592230000	2592240000	2592250000

Data	HDC MBUS	Industrial Cable	HDC MBUS4 D5E	HDC MBUS8 X6A	Railway Cable
					
Notes / Current / voltage	Requires WM Cable Only	4 A / 50 V	4 A / 50 V	0.5 A / 50 V	
Part Numbers	Female 1429020000 Male 1428990000	Industrial Cable Cat. 5e, D-coded and Cat. 6A X-coded Various depending on configuration	Field attachable Cat 5e, D-coded Female 2427930000 Male 2427920000	Field attachable Cat 6A, X-coded Female 2427910000 Male 2427900000	Industrial Cable Cat. 5e, D-coded and Cat. 6A X-coded Various depending on configuration

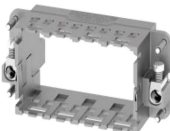
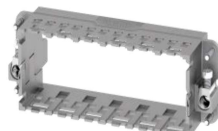
Pneumatic	HDC MPN 2	HDC MPN 6.0	HDC MPN 3	HDC MPN 1.6	HDC MPN 3.0	HDC MPN 4.0
						
Part Numbers	2637320000	Female 2637390000 Male 2637350000 SOF 2637400000	2637340000	Female 2637480000 Male 2637470000 SOF 2637490000	Female 2637450000 Male 2637440000 SOF 2637460000	Female 2637420000 Male 2637410000 SOF 2637430000

Moduplug Portfolio

Type	Part number	Description	Length	Qty.
Cat. 6A, LSZH, grey	2661950020	HDC RJ4501 MMSCAT6-0020	0.2 m	1 pc.
	2661950030	HDC RJ4501 MMSCAT6-0030	0.3 m	1 pc.
	2661950040	HDC RJ4501 MMSCAT6-0040	0.4 m	1 pc.
	2661950050	HDC RJ4501 MMSCAT6-0050	0.5 m	1 pc.
	2661950060	HDC RJ4501 MMSCAT6-0060	0.6 m	1 pc.
	2661950070	HDC RJ4501 MMSCAT6-0070	0.7 m	1 pc.
	2661950080	HDC RJ4501 MMSCAT6-0080	0.8 m	1 pc.
	2661950090	HDC RJ4501 MMSCAT6-0090	0.9 m	1 pc.
	2661950100	HDC RJ4501 MMSCAT6-0100	1.0 m	1 pc.
	2661950150	HDC RJ4501 MMSCAT6-0150	1.5 m	1 pc.
	2661950200	HDC RJ4501 MMSCAT6-0200	2.0 m	1 pc.
	2661950250	HDC RJ4501 MMSCAT6-0250	2.5 m	1 pc.
	2661950300	HDC RJ4501 MMSCAT6-0300	3.0 m	1 pc.
	2661950400	HDC RJ4501 MMSCAT6-0400	4.0 m	1 pc.
	2661950500	HDC RJ4501 MMSCAT6-0500	5.0 m	1 pc.
	2661950600	HDC RJ4501 MMSCAT6-0600	6.0 m	1 pc.
	2661950700	HDC RJ4501 MMSCAT6-0700	7.0 m	1 pc.
	2661950750	HDC RJ4501 MMSCAT6-0750	7.5 m	1 pc.
	2661950800	HDC RJ4501 MMSCAT6-0800	8.5 m	1 pc.
	2661950900	HDC RJ4501 MMSCAT6-0900	9.0 m	1 pc.
	2661951000	HDC RJ4501 MMSCAT6-1000	10.0 m	1 pc.
	2661951500	HDC RJ4501 MMSCAT6-1500	15.0 m	1 pc.
	2661952000	HDC RJ4501 MMSCAT6-2000	20.0 m	1 pc.



Moduplug Portfolio

Frame	HDC MF 6B	HDC MF 10B	HDC MF 16B	HDC MF 24B
				
Housing size	6B = Size 3	10B = Size 4	16B = Size 6	24B = Size 8
Part Numbers	AB 1428920000 BA 1428940000	AC 1428960000 CA 1428980000	AD 1429010000 DA 1429030000	AF 1429050000 FA 1429070000

Housings & Accessories	Housing Top Entry	Housing side Entry	HDC AF WM Cover	HDC AF WM	HDC MDU
					
Part Numbers	Size 3 M25 2716700000 Size 4 M32 2716720000 Size 6 M40 2716730000 Size 8 M40 2716740000	Size 3 M25 2716750000 Size 4 M32 2716760000 Size 6 M40 2716770000 Size 8 M40 2716780000	Size 3 2716810000 Size 4 2716820000 Size 6 2716830000 Size 8 2716840000	Adapters needed for mounting 2716790000 Pk 20 no screws 2716800000 2 pcs with screws	1429040000 Dummy Module ½ space size