



**MUELLER**  
Worldwide Instrumentation Supplier  
OEM & Custom Orders ... High Value, Low Cost, Quick Delivery

MANUFACTURED TO A HIGHER STANDARD  
**QUALITY & INNOVATION**  
SINCE 1908



A close-up photograph of a bright yellow robotic arm with black accents and blue cables. The arm is positioned over a dark, metallic circular component, likely a flange or part of a machine. The background is blurred, showing an industrial environment with other machinery and equipment.



Three smaller images at the bottom of the page provide a preview of the catalog's content. The first image shows a conveyor belt with blue cylindrical containers. The second image shows a conveyor belt with white rectangular boxes. The third image shows a complex, multi-tiered industrial machine with various components, wires, and sensors.



# FACTORY AUTOMATION CABLES



WORLDWIDE INSTRUMENTATION SUPPLIER



**MuellerElectric.com****T: 800.955.2629****T: 330.780.2525****F: 330.780.2524****sales@muellerelectric.com**

***In business for more than a century, Mueller Electric has become the electronic expert industry leaders have come to trust.***

## MUELLER ELECTRIC'S FACTORY AUTOMATION CABLE SERIES

### TABLE OF CONTENTS

Introduction To Mueller Electric's Factory Automation Cable Series .....	4
Coding For Connectors .....	6
Cable Jacket Insulations .....	7

### M12 CABLES

M12 Cables: 3, 4 & 5-Pin Positions, 18 & 22 AWG.....	8-12
M12 Cables: Straight Mold Connectors .....	13
M12 Cables: Right-Angle Mold Connectors .....	14
M12 Cables: Open-Ended Cables .....	15-16
M12 Cables: Double-Ended Cables .....	17-18
Non UL-Listed Cables .....	19
M12 Receptacles .....	20

### M8 CABLES

M8 Cables: 3, 4, 6 & 8-Pin Positions, 24 & 26 AWG .....	21-24
---	-------

M8 Cables: Straight Mold Connectors .....	25
M8 Cables: Right-Angle Mold Connectors .....	26
M8 Cables: Open-Ended Cables .....	27-28
M8 Cables: Double-Ended Cables .....	29-30
M8 Receptacles .....	31

#### ADDITIONAL CABLES

Additional Cables .....	32-37
7/8-16UN-M12 Cables .....	32
End Caps & Accessories .....	32
Ethernet Cables .....	33
Open-Ended M12 Cables with Junction Box .....	34
7/8-16UN Cables, Receptacles and M23 Equivalents .....	35
M12-M8 Cables .....	36
M12-M12 Light-Up Ethernet Cables .....	36
M8-M8 Molded Y-Connector Cables .....	37
Y Connectors .....	37
Field-Installable Connectors .....	37

#### OTHER INFORMATION

Custom Cable Orders .....	38
Industries Served .....	39
Warranty .....	39
Notes .....	40-43



The cover of the Mueller Factory Automation Catalog. It features the Mueller logo at the top left, followed by a large, bold title: "MUELLER ELECTRIC'S FACTORY AUTOMATION CABLE SERIES". Below the title, a tagline reads "The future of FACTORY AUTOMATION is here" in yellow, and at the bottom, it says "The time to change is NOW".

THE TIME TO CHANGE IS NOW.

Factory automation cables are part of an ongoing multi-million-dollar demand in manufacturing to automate equipment in order to produce products faster and more efficiently. With the advance of Industry 4.0, smart factories are now becoming a reality.

The events of the recent pandemic have further propelled this need to implement factory automation equipment as an inventive solution in all areas of manufacturing as a means to eliminate social distancing issues, human touch and also to fulfill a number of jobs created by the demand to ship more products on time. Not only are robots used heavily in production but they are now also being used to coordinate picking and shipping orders. Robotics and automated equipment are now very much needed in all phases and departments of manufacturing.

As a result plant managers are under pressure now more than ever to convert to new manufacturing methods and are left wondering how to upgrade systems while avoiding costly investments and staying within a given budget.

So what's a simple answer to this major shift in manufacturing culture?

**Mueller Electric** has just the solution with factory automation cables!



Simple yet technologically equipped, factory automation cables come ready to install with existing manufacturing equipment and can adapt with sensors, actuators, frequency converters, motor-operated switches and other components that are required as more and more smart factory practices come into play.

They're not just factory automation cables; they're technologically advanced to provide ultimate connectivity with both current equipment and progressive systems ... all at a high value and low cost designed so you can stay within a budget!





## SMART FACTORIES

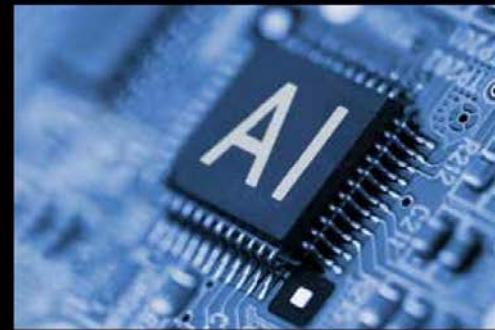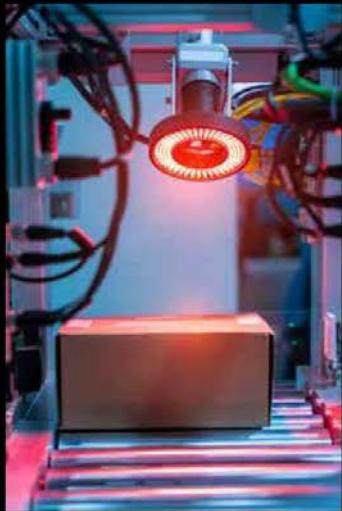

## INDUSTRIAL ARTIFICIAL INTELLIGENCE

## MACHINE VISION

## INDUSTRY 4.0



# CODING FOR CONNECTORS

## What Coding Do You Use For The Application?

### CODING FOR TODAY

With all the different types of coding available, knowing what coding to use for which application can be confusing. Below are 5 common types of coding currently used in today's work environment and their descriptions translated, followed by 4 types of coding that are emerging as up and coming coding for future use.



A CODE



B CODE



C CODE



D CODE



X CODE

#### A CODING (MICRO-DC OR M12)

The Micro-DC (MDC) series, perhaps known better as micro-changes or M12, is one of the most widely and currently used industrial quick disconnects in the industrial market. These connectors can be used in both AC or DC applications. Uses of M12s in industrial automation are limitless but are commonly used in factory automation for sensors, actuators, motors, switches, safety light curtains and mats and interlock switches.

#### B CODING (EURO AC)

The EURO AC (MEC) series has a reversed single keyway known as B-code. This allows 2 unique M12 connectors to be mounted on the same panel without fear of incorrectly coupling connectors to equipment with varying voltage and amperages.

#### C CODING (MICRO AC)

The MICRO-AC (MAC) series uses a  $\frac{1}{2}$ "-20 mating thread and has a first-make, last-break extended ground pin. The use of a double keyway (C code) prevents connectors from accidentally being plugged into other connectors of similar size.

#### D CODING (ETHERNET)

M12 Ethernet series (MDE45) utilizes 4 wire (D-code) connectors with 2 pair Cat 5e cables or M12 8 wire (A-code) connectors with 4 pair Cat 5e cables. The MDE45 is specifically used in industrial Ethernet applications and has real cable using twisted pairs of wires inside. D code is for 100-Mbit Ethernet.

#### X CODING (ETHERNET)

X-coded instrumentation cables are becoming more popular as they are used in Ethernet 10-Gbit environments. The X-coded type connection is becoming more and more popular for high-speed industrial Ethernet and will eventually replace the A- and D-coded parts for Ethernet applications.

### CODING FOR TOMORROW

#### L Coding

Used for power 12A / 63 V AC or DC applications.



L CODE



P CODE

**S Coding**

Used for AC power and will eventually replace C-coded power cables.



S CODE

**T Coding**

Used for DC power and will eventually replace A-coded power cables.



T CODE

# JACKET INSULATIONS

## PVC, PUR or TPE ... Which Jacket Insulation Best Fits My Purpose?

Jacket insulation plays a large part in a cable's performance for a particular application. Choosing the right jacket insulation for a cable's intended use will aid in preserving the longevity of your instrumentation cable.

Mueller Electric offers options for all types of uses for factory automation cables. Below is a description of three jacket insulation materials and a quick reference chart that shows what cable insulation type is best to use for specific applications. You can choose which jacket insulation type is best for your application needs!

**PVC**

**Polyvinyl Chloride** is a great choice for general purpose use which allows Mueller Electric to give you a great price point. Because of its high moisture resistance, PVC is great for use in wet or humid conditions.

**PUR**

**Polyurethane** offers good resistance against abrasion, oil and ozone. PUR is halogen free, meaning it does not contain chlorine, iodine, flourine, bromine or astatine.

**TPE**

**Thermoplastic Elastomer** is flexible, recyclable and has excellent cold temperature characteristics. TPE is resistant to aging in sunlight, UV and ozone. It also has a high flex rating, typically of 10 million.

RESISTANCE TO:	TPE	PVC	PUR
ABRASION	Excellent	Fair-Good	Excellent
ACID	Excellent	Good-Excellent	Excellent
ALCOHOL	Excellent	Good-Excellent	Excellent
ALKALI	Excellent	Good-Excellent	Excellent

	EXCELLENT	GOOD-EXCELLENT	EXCELLENT
ALKALI	Excellent	Poor-Fair	Excellent
BENZOL	Excellent	Poor-Fair	Excellent
DEGREASER SOLVENTS	Excellent	Fair-Good	Excellent
ELECTRICAL PROPERTIES	Excellent	Fair-Good	Excellent
FLAME	Outstanding	Excellent	Excellent
GASOLINE	Excellent	Poor	Excellent
HEAT	Outstanding	Good-Excellent	Excellent
LOW TEMPERATURE FLEXIBILITY	Outstanding	Poor-Good	Excellent
NUCLEAR RADIATION	Poor	Fair	Excellent
OIL	Outstanding	Fair	Outstanding
OXIDATION	Outstanding	Excellent	Excellent
OZONE	Excellent	Excellent	Excellent
WATER	Excellent	Good-Excellent	Good-Excellent
WEATHER, SUN	Outstanding	Good-Excellent	Excellent
WELD SLAG	Excellent	Fair	Excellent


Mueller Electric | 2850 Gilchrist Rd, Building 5A, Akron, OH 44305 | 800.955.2629 | [www.muellerelectric.com](http://www.muellerelectric.com)

7



# MUELLER ELECTRIC'S FACTORY AUTOMATION CABLE SERIES

## M12 CABLES

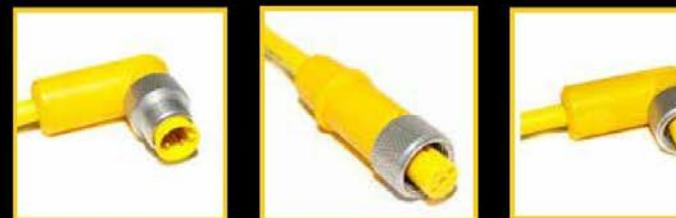

## MUELLER ELECTRIC'S M12 FACTORY AUTOMATION CABLE SERIES



### M12 Cables Full Listing: 3, 4 & 5-Pin Positions, 18 & 22 AWG

- PVC shielded or TPE unshielded jacket insulation
- Nickel-plated brass or anodized aluminum coupling nut material
- Standard cable lengths are 2, 5 & 10 meters
- Other cable lengths available upon request



Part Number	Cordset / Receptacle	Pin Count	Head Configuration		Plug Body	Cable Type	Cable Color	Coupling Nut Material	AWG	Cable Length (Meters)
			# 1	# 2						
<a href="#">C3A01M002</a>	Cord Set	3	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	2M

<a href="#">C3A01M005</a>	Cord Set	3	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C3A01M010</a>	Cord Set	3	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C3B01M002</a>	Cord Set	3	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C3B01M005</a>	Cord Set	3	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C3B01M010</a>	Cord Set	3	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C3C01M002</a>	Cord Set	3	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C3C01M005</a>	Cord Set	3	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C3C01M010</a>	Cord Set	3	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C3D01M002</a>	Cord Set	3	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C3D01M005</a>	Cord Set	3	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C3D01M010</a>	Cord Set	3	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C3AC01M002</a>	Cord Set	3	Male	Female	Straight-Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C3AC01M005</a>	Cord Set	3	Male	Female	Straight-Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C3AC01M010</a>	Cord Set	3	Male	Female	Straight-Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C3AD01M002</a>	Cord Set	3	Male	Female	Straight-Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C3AD01M005</a>	Cord Set	3	Male	Female	Straight-Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C3AD01M010</a>	Cord Set	3	Male	Female	Straight-Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C3BC01M002</a>	Cord Set	3	Male	Female	Right Angle-Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C3BC01M005</a>	Cord Set	3	Male	Female	Right Angle-Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C3BC01M010</a>	Cord Set	3	Male	Female	Right Angle-Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C3BD01M002</a>	Cord Set	3	Male	Female	Right Angle-Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C3BD01M005</a>	Cord Set	3	Male	Female	Right Angle-Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C3BD01M010</a>	Cord Set	3	Male	Female	Right Angle-Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C4A02M002</a>	Cord Set	4	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C4A02M005</a>	Cord Set	4	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C4A02M010</a>	Cord Set	4	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C4B02M002</a>	Cord Set	4	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C4B02M005</a>	Cord Set	4	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C4B02M010</a>	Cord Set	4	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C4C02M002</a>	Cord Set	4	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C4C02M005</a>	Cord Set	4	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C4C02M010</a>	Cord Set	4	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C4D02M002</a>	Cord Set	4	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C4D02M005</a>	Cord Set	4	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C4D02M010</a>	Cord Set	4	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	10M



### M12 Cables Full Listing: 3, 4 & 5-Pin Positions, 18 & 22 AWG

- PVC shielded or TPE unshielded jacket insulation



- Nickel-plated brass or anodized aluminum coupling nut material
- Standard cable lengths are 2, 5 & 10 meters



*Other cable lengths available upon request*

Part Number	Cordset / Receptacle	Pin Count	Head Configuration		Plug Body	Cable Type	Cable Color	Coupling Nut Material	AWG	Cable Length (Meters)
			# 1	# 2						
<a href="#"><u>C4AC02M002</u></a>	Cord Set	4	Male	Female	Straight-Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><u>C4AC02M005</u></a>	Cord Set	4	Male	Female	Straight-Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><u>C4AC02M010</u></a>	Cord Set	4	Male	Female	Straight-Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><u>C4AD02M002</u></a>	Cord Set	4	Male	Female	Straight-Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><u>C4AD02M005</u></a>	Cord Set	4	Male	Female	Straight-Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><u>C4AD02M010</u></a>	Cord Set	4	Male	Female	Straight-Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><u>C4BC02M002</u></a>	Cord Set	4	Male	Female	Right Angle-Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><u>C4BC02M005</u></a>	Cord Set	4	Male	Female	Right Angle-Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><u>C4BC02M010</u></a>	Cord Set	4	Male	Female	Right Angle-Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><u>C4BD02M002</u></a>	Cord Set	4	Male	Female	Right Angle-Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><u>C4BD02M005</u></a>	Cord Set	4	Male	Female	Right Angle-Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><u>C4BD02M010</u></a>	Cord Set	4	Male	Female	Right Angle-Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><u>C5A03M002</u></a>	Cord Set	5	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><u>C5A03M005</u></a>	Cord Set	5	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><u>C5A03M010</u></a>	Cord Set	5	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><u>C5B03M002</u></a>	Cord Set	5	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><u>C5B03M005</u></a>	Cord Set	5	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><u>C5B03M010</u></a>	Cord Set	5	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><u>C5C03M002</u></a>	Cord Set	5	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><u>C5C03M005</u></a>	Cord Set	5	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><u>C5C03M010</u></a>	Cord Set	5	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><u>C5D03M002</u></a>	Cord Set	5	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><u>C5D03M005</u></a>	Cord Set	5	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><u>C5D03M010</u></a>	Cord Set	5	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><u>C5AC03M002</u></a>	Cord Set	5	Male	Female	Straight-Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><u>C5AC03M005</u></a>	Cord Set	5	Male	Female	Straight-Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><u>C5AC03M010</u></a>	Cord Set	5	Male	Female	Straight-Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><u>C5AD03M002</u></a>	Cord Set	5	Male	Female	Straight-Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><u>C5AD03M005</u></a>	Cord Set	5	Male	Female	Straight-Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><u>C5AD03M010</u></a>	Cord Set	5	Male	Female	Straight-Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><u>C5BC03M002</u></a>	Cord Set	5	Male	Female	Right Angle-Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><u>C5BC03M005</u></a>	Cord Set	5	Male	Female	Right Angle-Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><u>C5BC03M010</u></a>	Cord Set	5	Male	Female	Right Angle-Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><u>C5BD03M002</u></a>	Cord Set	5	Male	Female	Right Angle-Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><u>C5BD03M005</u></a>	Cord Set	5	Male	Female	Right Angle-Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><u>C5BD03M010</u></a>	Cord Set	5	Male	Female	Right Angle-Right Angle	TPE	Yellow	Anodized Aluminum	18	10M



### M12 Cables Full Listing: 3, 4 & 5-Pin Positions, 18 & 22 AWG

- PVC shielded or TPE unshielded jacket insulation
- Nickel-plated brass or anodized aluminum coupling nut material
- Standard cable lengths are 2, 5 & 10 meters



*Other cable lengths available upon request*

Part Number	Cordset / Receptacle	Pin Count	Head Configuration		Plug Body	Cable Type	Cable Color	Coupling Nut Material	AWG	Cable Length (Meters)
			# 1	# 2						
<a href="#">C3A04M002</a>	Cord Set	3	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C3A04M005</a>	Cord Set	3	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C3A04M010</a>	Cord Set	3	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C3B04M002</a>	Cord Set	3	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C3B04M005</a>	Cord Set	3	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C3B04M010</a>	Cord Set	3	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C3C04M002</a>	Cord Set	3	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C3C04M005</a>	Cord Set	3	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C3C04M010</a>	Cord Set	3	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C3D04M002</a>	Cord Set	3	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C3D04M005</a>	Cord Set	3	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C3D04M010</a>	Cord Set	3	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C3AC04M002</a>	Cord Set	3	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C3AC04M005</a>	Cord Set	3	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C3AC04M010</a>	Cord Set	3	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C3AD04M002</a>	Cord Set	3	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C3AD04M005</a>	Cord Set	3	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C3AD04M010</a>	Cord Set	3	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C3BC04M002</a>	Cord Set	3	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C3BC04M005</a>	Cord Set	3	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C3BC04M010</a>	Cord Set	3	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C3BD04M002</a>	Cord Set	3	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C3BD04M005</a>	Cord Set	3	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C3BD04M010</a>	Cord Set	3	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C4A05M002</a>	Cord Set	4	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C4A05M005</a>	Cord Set	4	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C4A05M010</a>	Cord Set	4	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C4B05M002</a>	Cord Set	4	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C4B05M005</a>	Cord Set	4	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C4B05M010</a>	Cord Set	4	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M

Part Number	Cord Set	#	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	CC	SWL
<a href="#">C4B05M010</a>	Cord Set	4	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C4C05M002</a>	Cord Set	4	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C4C05M005</a>	Cord Set	4	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C4C05M010</a>	Cord Set	4	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C4D05M002</a>	Cord Set	4	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C4D05M005</a>	Cord Set	4	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C4D05M010</a>	Cord Set	4	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M



### M12 Cables Full Listing: 3, 4 & 5-Pin Positions, 18 & 22 AWG

- PVC shielded or TPE unshielded jacket insulation
- Nickel-plated brass or anodized aluminum coupling nut material
- Standard cable lengths are 2, 5 & 10 meters

*Other cable lengths available upon request*



Part Number	Cordset / Receptacle	Pin Count	Head Configuration		Plug Body	Cable Type	Cable Color	Coupling Nut Material	AWG	Cable Length (Meters)
			# 1	# 2						
<a href="#">C4AC05M002</a>	Cord Set	4	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C4AC05M005</a>	Cord Set	4	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C4AC05M010</a>	Cord Set	4	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C4AD05M002</a>	Cord Set	4	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C4AD05M005</a>	Cord Set	4	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C4AD05M010</a>	Cord Set	4	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C4BC05M002</a>	Cord Set	4	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C4BC05M005</a>	Cord Set	4	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C4BC05M010</a>	Cord Set	4	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C4BD05M002</a>	Cord Set	4	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C4BD05M005</a>	Cord Set	4	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C4BD05M010</a>	Cord Set	4	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C5A06M002</a>	Cord Set	5	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C5A06M005</a>	Cord Set	5	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C5A06M010</a>	Cord Set	5	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C5B06M002</a>	Cord Set	5	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C5B06M005</a>	Cord Set	5	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C5B06M010</a>	Cord Set	5	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C5C06M002</a>	Cord Set	5	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	2M

<a href="#">C5C06M005</a>	Cord Set	5	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C5C06M010</a>	Cord Set	5	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C5D06M002</a>	Cord Set	5	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C5D06M005</a>	Cord Set	5	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C5D06M010</a>	Cord Set	5	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">CSAC06M002</a>	Cord Set	5	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">CSAC06M005</a>	Cord Set	5	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">CSAC06M010</a>	Cord Set	5	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">CSAD06M002</a>	Cord Set	5	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">CSAD06M005</a>	Cord Set	5	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">CSAD06M010</a>	Cord Set	5	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">CSBC06M002</a>	Cord Set	5	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">CSBC06M005</a>	Cord Set	5	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">CSBC06M010</a>	Cord Set	5	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">CSBD06M002</a>	Cord Set	5	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">CSBD06M005</a>	Cord Set	5	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">CSBD06M010</a>	Cord Set	5	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M

12 Mueller Electric | 2850 Gilchrist Rd. Building 5A, Akron, OH 44305 | 800.955.2629 | [www.muellerelectric.com](http://www.muellerelectric.com)

### M12 Cables: Straight Mold Types

- PVC shielded or TPE unshielded jacket insulation
- Nickel-plated brass or anodized aluminum coupling nut material
- Standard cable lengths are 2, 5 & 10 meters

*Other cable lengths available upon request*



Part Number	Cordset / Receptacle	Pin Count	Head Configuration		Plug Body	Cable Type	Cable Color	Coupling Nut Material	AWG	Cable Length (Meters)
			# 1	# 2						
<a href="#">C3A01M002</a>	Cord Set	3	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C3A01M005</a>	Cord Set	3	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C3A01M010</a>	Cord Set	3	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C3C01M002</a>	Cord Set	3	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C3C01M005</a>	Cord Set	3	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C3C01M010</a>	Cord Set	3	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C4A02M002</a>	Cord Set	4	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C4A02M005</a>	Cord Set	4	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C4A02M010</a>	Cord Set	4	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C4C02M002</a>	Cord Set	4	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	2M

<a href="#">C4C02M005</a>	Cord Set	4	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C4C02M010</a>	Cord Set	4	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C5A03M002</a>	Cord Set	5	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C5A03M005</a>	Cord Set	5	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C5A03M010</a>	Cord Set	5	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C5C03M002</a>	Cord Set	5	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C5C03M005</a>	Cord Set	5	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C5C03M010</a>	Cord Set	5	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C3A04M002</a>	Cord Set	3	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C3A04M005</a>	Cord Set	3	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C3A04M010</a>	Cord Set	3	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C3C04M002</a>	Cord Set	3	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C3C04M005</a>	Cord Set	3	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C3C04M010</a>	Cord Set	3	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C4A05M002</a>	Cord Set	4	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C4A05M005</a>	Cord Set	4	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C4A05M010</a>	Cord Set	4	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C4C05M002</a>	Cord Set	4	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C4C05M005</a>	Cord Set	4	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C4C05M010</a>	Cord Set	4	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C5A06M002</a>	Cord Set	5	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C5A06M005</a>	Cord Set	5	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C5A06M010</a>	Cord Set	5	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C5C06M002</a>	Cord Set	5	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C5C06M005</a>	Cord Set	5	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C5C06M010</a>	Cord Set	5	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	10M



### M12 Cables: Right-Angle Mold Types

- PVC shielded or TPE unshielded jacket insulation
- Nickel-plated brass or anodized aluminum coupling nut material
- Standard cable lengths are 2, 5 & 10 meters

*Other cable lengths available upon request*



Part Number	Cordset / Receptacle	Pin Count	Head Configuration		Plug Body	Cable Type	Cable Color	Coupling Nut Material	AWG	Cable Length (Meters)
			# 1	# 2						
<a href="#">C3B01M002</a>	Cord Set	3	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	2M

<a href="#"><b>C3B01M005</b></a>	Cord Set	3	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><b>C3B01M010</b></a>	Cord Set	3	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><b>C3D01M002</b></a>	Cord Set	3	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><b>C3D01M005</b></a>	Cord Set	3	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><b>C3D01M010</b></a>	Cord Set	3	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><b>C4B02M002</b></a>	Cord Set	4	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><b>C4B02M005</b></a>	Cord Set	4	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><b>C4B02M010</b></a>	Cord Set	4	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><b>C4D02M002</b></a>	Cord Set	4	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><b>C4D02M005</b></a>	Cord Set	4	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><b>C4D02M010</b></a>	Cord Set	4	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><b>C5B03M002</b></a>	Cord Set	5	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><b>C5B03M005</b></a>	Cord Set	5	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><b>C5B03M010</b></a>	Cord Set	5	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><b>C5D03M002</b></a>	Cord Set	5	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><b>C5D03M005</b></a>	Cord Set	5	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><b>C5D03M010</b></a>	Cord Set	5	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><b>C3B04M002</b></a>	Cord Set	3	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#"><b>C3B04M005</b></a>	Cord Set	3	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#"><b>C3B04M010</b></a>	Cord Set	3	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#"><b>C3D04M002</b></a>	Cord Set	3	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#"><b>C3D04M005</b></a>	Cord Set	3	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#"><b>C3D04M010</b></a>	Cord Set	3	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#"><b>C4B05M002</b></a>	Cord Set	4	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#"><b>C4B05M005</b></a>	Cord Set	4	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#"><b>C4B05M010</b></a>	Cord Set	4	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#"><b>C4D05M002</b></a>	Cord Set	4	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#"><b>C4D05M005</b></a>	Cord Set	4	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#"><b>C4D05M010</b></a>	Cord Set	4	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#"><b>C5B06M002</b></a>	Cord Set	5	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#"><b>C5B06M005</b></a>	Cord Set	5	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#"><b>C5B06M010</b></a>	Cord Set	5	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#"><b>C5D06M002</b></a>	Cord Set	5	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#"><b>C5D06M005</b></a>	Cord Set	5	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#"><b>C5D06M010</b></a>	Cord Set	5	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M



### M12 Cables: Open-Ended Cables

- PVC shielded or TPE unshielded jacket insulation





- Nickel-plated brass or anodized aluminum coupling nut material
- Standard cable lengths are 2, 5 & 10 meters

*Other cable lengths available upon request*



Part Number	Cordset / Receptacle	Pin Count	Head Configuration		Plug Body	Cable Type	Cable Color	Coupling Nut Material	AWG	Cable Length (Meters)
			# 1	# 2						
<a href="#">C3A01M002</a>	Cord Set	3	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C3A01M005</a>	Cord Set	3	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C3A01M010</a>	Cord Set	3	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C3B01M002</a>	Cord Set	3	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C3B01M005</a>	Cord Set	3	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C3B01M010</a>	Cord Set	3	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C3C01M002</a>	Cord Set	3	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C3C01M005</a>	Cord Set	3	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C3C01M010</a>	Cord Set	3	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C3D01M002</a>	Cord Set	3	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C3D01M005</a>	Cord Set	3	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C3D01M010</a>	Cord Set	3	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C4A02M002</a>	Cord Set	4	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C4A02M005</a>	Cord Set	4	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C4A02M010</a>	Cord Set	4	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C4B02M002</a>	Cord Set	4	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C4B02M005</a>	Cord Set	4	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C4B02M010</a>	Cord Set	4	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C4C02M002</a>	Cord Set	4	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C4C02M005</a>	Cord Set	4	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C4C02M010</a>	Cord Set	4	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C4D02M002</a>	Cord Set	4	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C4D02M005</a>	Cord Set	4	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C4D02M010</a>	Cord Set	4	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C5A03M002</a>	Cord Set	5	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C5A03M005</a>	Cord Set	5	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C5A03M010</a>	Cord Set	5	Male	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C5B03M002</a>	Cord Set	5	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C5B03M005</a>	Cord Set	5	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C5B03M010</a>	Cord Set	5	Male	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C5C03M002</a>	Cord Set	5	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C5C03M005</a>	Cord Set	5	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C5C03M010</a>	Cord Set	5	Female	Open End	Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#">C5D03M002</a>	Cord Set	5	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#">C5D03M005</a>	Cord Set	5	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#">C5D03M010</a>	Cord Set	5	Female	Open End	Right Angle	TPE	Yellow	Anodized Aluminum	18	10M



### M12 Cables: Open-Ended Cables

- PVC shielded or TPE unshielded jacket insulation
- Nickel-plated brass or anodized aluminum coupling nut material
- Standard cable lengths are 2, 5 & 10 meters

*Other cable lengths available upon request*



Part Number	Cordset / Receptacle	Pin Count	Head Configuration		Plug Body	Cable Type	Cable Color	Coupling Nut Material	AWG	Cable Length (Meters)
			# 1	# 2						
<a href="#"><u>C3A04M002</u></a>	Cord Set	3	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#"><u>C3A04M005</u></a>	Cord Set	3	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#"><u>C3A04M010</u></a>	Cord Set	3	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#"><u>C3B04M002</u></a>	Cord Set	3	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#"><u>C3B04M005</u></a>	Cord Set	3	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#"><u>C3B04M010</u></a>	Cord Set	3	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#"><u>C3C04M002</u></a>	Cord Set	3	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#"><u>C3C04M005</u></a>	Cord Set	3	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#"><u>C3C04M010</u></a>	Cord Set	3	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#"><u>C3D04M002</u></a>	Cord Set	3	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#"><u>C3D04M005</u></a>	Cord Set	3	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#"><u>C3D04M010</u></a>	Cord Set	3	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#"><u>C4A05M002</u></a>	Cord Set	4	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#"><u>C4A05M005</u></a>	Cord Set	4	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#"><u>C4A05M010</u></a>	Cord Set	4	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#"><u>C4B05M002</u></a>	Cord Set	4	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#"><u>C4B05M005</u></a>	Cord Set	4	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#"><u>C4B05M010</u></a>	Cord Set	4	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#"><u>C4C05M002</u></a>	Cord Set	4	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#"><u>C4C05M005</u></a>	Cord Set	4	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#"><u>C4C05M010</u></a>	Cord Set	4	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#"><u>C4D05M002</u></a>	Cord Set	4	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#"><u>C4D05M005</u></a>	Cord Set	4	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#"><u>C4D05M010</u></a>	Cord Set	4	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#"><u>C5A06M002</u></a>	Cord Set	5	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#"><u>C5A06M005</u></a>	Cord Set	5	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#"><u>C5A06M010</u></a>	Cord Set	5	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#"><u>C5B06M002</u></a>	Cord Set	5	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M

<a href="#"><b>C5B06M005</b></a>	Cord Set	5	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#"><b>C5B06M010</b></a>	Cord Set	5	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#"><b>C5C06M002</b></a>	Cord Set	5	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#"><b>C5C06M005</b></a>	Cord Set	5	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#"><b>C5C06M010</b></a>	Cord Set	5	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#"><b>C5D06M002</b></a>	Cord Set	5	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#"><b>C5D06M005</b></a>	Cord Set	5	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#"><b>C5D06M010</b></a>	Cord Set	5	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M

16 Mueller Electric | 2850 Gilchrist Rd, Building 5A, Akron, OH 44305 | 800.955.2629 | [www.muellerelectric.com](http://www.muellerelectric.com)



### M12 Cables: Double-Ended Cables

- PVC shielded or TPE unshielded jacket insulation
- Nickel-plated brass or anodized aluminum coupling nut material
- Standard cable lengths are 2, 5 & 10 meters

*Other cable lengths available upon request*



Part Number	Cordset / Receptacle	Pin Count	Head Configuration		Plug Body	Cable Type	Cable Color	Coupling Nut Material	AWG	Cable Length (Meters)
			# 1	# 2						
<a href="#"><b>C3AC01M002</b></a>	Cord Set	3	Male	Female	Straight-Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><b>C3AC01M005</b></a>	Cord Set	3	Male	Female	Straight-Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><b>C3AC01M010</b></a>	Cord Set	3	Male	Female	Straight-Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><b>C3AD01M002</b></a>	Cord Set	3	Male	Female	Straight-Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><b>C3AD01M005</b></a>	Cord Set	3	Male	Female	Straight-Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><b>C3AD01M010</b></a>	Cord Set	3	Male	Female	Straight-Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><b>C3BC01M002</b></a>	Cord Set	3	Male	Female	Right Angle-Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><b>C3BC01M005</b></a>	Cord Set	3	Male	Female	Right Angle-Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><b>C3BC01M010</b></a>	Cord Set	3	Male	Female	Right Angle-Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><b>C3BD01M002</b></a>	Cord Set	3	Male	Female	Right Angle-Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><b>C3BD01M005</b></a>	Cord Set	3	Male	Female	Right Angle-Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><b>C3BD01M010</b></a>	Cord Set	3	Male	Female	Right Angle-Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><b>C4AC02M002</b></a>	Cord Set	4	Male	Female	Straight-Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><b>C4AC02M005</b></a>	Cord Set	4	Male	Female	Straight-Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><b>C4AC02M010</b></a>	Cord Set	4	Male	Female	Straight-Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><b>C4AD02M002</b></a>	Cord Set	4	Male	Female	Straight-Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><b>C4AD02M005</b></a>	Cord Set	4	Male	Female	Straight-Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><b>C4AD02M010</b></a>	Cord Set	4	Male	Female	Straight-Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><b>C4BC02M002</b></a>	Cord Set	4	Male	Female	Right Angle-Straight	TPE	Yellow	Anodized Aluminum	18	2M

<a href="#"><b>C4BC02M005</b></a>	Cord Set	4	Male	Female	Right Angle-Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><b>C4BC02M010</b></a>	Cord Set	4	Male	Female	Right Angle-Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><b>C4BD02M002</b></a>	Cord Set	4	Male	Female	Right Angle-Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><b>C4BD02M005</b></a>	Cord Set	4	Male	Female	Right Angle-Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><b>C4BD02M010</b></a>	Cord Set	4	Male	Female	Right Angle-Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><b>C5AC03M002</b></a>	Cord Set	5	Male	Female	Straight-Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><b>C5AC03M005</b></a>	Cord Set	5	Male	Female	Straight-Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><b>C5AC03M010</b></a>	Cord Set	5	Male	Female	Straight-Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><b>C5AD03M002</b></a>	Cord Set	5	Male	Female	Straight-Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><b>C5AD03M005</b></a>	Cord Set	5	Male	Female	Straight-Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><b>C5AD03M010</b></a>	Cord Set	5	Male	Female	Straight-Right Angle	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><b>C5BC03M002</b></a>	Cord Set	5	Male	Female	Right Angle-Straight	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><b>C5BC03M005</b></a>	Cord Set	5	Male	Female	Right Angle-Straight	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><b>C5BC03M010</b></a>	Cord Set	5	Male	Female	Right Angle-Straight	TPE	Yellow	Anodized Aluminum	18	10M
<a href="#"><b>C5BD03M002</b></a>	Cord Set	5	Male	Female	Right Angle-Right Angle	TPE	Yellow	Anodized Aluminum	18	2M
<a href="#"><b>C5BD03M005</b></a>	Cord Set	5	Male	Female	Right Angle-Right Angle	TPE	Yellow	Anodized Aluminum	18	5M
<a href="#"><b>C5BD03M010</b></a>	Cord Set	5	Male	Female	Right Angle-Right Angle	TPE	Yellow	Anodized Aluminum	18	10M

Mueller Electric | 2850 Gilchrist Rd, Building 5A, Akron, OH 44305 | 800.955.2629 | [www.muellerelectric.com](http://www.muellerelectric.com)

17



### M12 Cables: Double-Ended Cables

- PVC shielded or TPE unshielded jacket insulation
- Nickel-plated brass or anodized aluminum coupling nut material
- Standard cable lengths are 2, 5 & 10 meters

*Other cable lengths available upon request*



Part Number	Cordset / Receptacle	Pin Count	Head Configuration		Plug Body	Cable Type	Cable Color	Coupling Nut Material	AWG	Cable Length (Meters)
			# 1	# 2						
<a href="#"><b>C3AC04M002</b></a>	Cord Set	3	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#"><b>C3AC04M005</b></a>	Cord Set	3	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#"><b>C3AC04M010</b></a>	Cord Set	3	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#"><b>C3AD04M002</b></a>	Cord Set	3	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#"><b>C3AD04M005</b></a>	Cord Set	3	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#"><b>C3AD04M010</b></a>	Cord Set	3	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#"><b>C3BC04M002</b></a>	Cord Set	3	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#"><b>C3BC04M005</b></a>	Cord Set	3	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#"><b>C3BC04M010</b></a>	Cord Set	3	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#"><b>C3BD04M002</b></a>	Cord Set	2	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M

Part Number	Cord Set	Pin	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C3BD04M005</a>	Cord Set	3	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C3BD04M010</a>	Cord Set	3	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C4AC05M002</a>	Cord Set	4	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C4AC05M005</a>	Cord Set	4	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C4AC05M010</a>	Cord Set	4	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C4AD05M002</a>	Cord Set	4	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C4AD05M005</a>	Cord Set	4	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C4AD05M010</a>	Cord Set	4	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C4BC05M002</a>	Cord Set	4	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C4BC05M005</a>	Cord Set	4	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C4BC05M010</a>	Cord Set	4	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C4BD05M002</a>	Cord Set	4	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C4BD05M005</a>	Cord Set	4	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C4BD05M010</a>	Cord Set	4	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C5AC06M002</a>	Cord Set	5	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C5AC06M005</a>	Cord Set	5	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C5AC06M010</a>	Cord Set	5	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C5AD06M002</a>	Cord Set	5	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C5AD06M005</a>	Cord Set	5	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C5AD06M010</a>	Cord Set	5	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C5BC06M002</a>	Cord Set	5	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C5BC06M005</a>	Cord Set	5	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C5BC06M010</a>	Cord Set	5	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	22	10M
<a href="#">C5BD06M002</a>	Cord Set	5	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	2M
<a href="#">C5BD06M005</a>	Cord Set	5	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	5M
<a href="#">C5BD06M010</a>	Cord Set	5	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	22	10M

18 Mueller Electric | 2850 Gilchrist Rd, Building 5A, Akron, OH 44305 | 800.955.2629 | [www.muellerelectric.com](http://www.muellerelectric.com)


### Non-UL Listed Cables

- PVC or PUR jacket insulation
- Anodized aluminum coupling nut material
- Standard cable lengths are shown below

*Other cable lengths available upon request*

Part Number	Cordset / Receptacle	Pin Count	Head Configuration		Plug Body	Cable Type	Cable Color	Coupling Nut Material	AWG	Cable Length
			# 1	# 2						

<a href="#">AI-000709</a>	Cordset	25	Male	Male	Straight-RS	PVC	Black	Anodized Aluminum	26	30"
<a href="#">AI-000712-100</a>	Cordset	9	Male	Female	Straight-RS	PVC	Black	Anodized Aluminum	26	100'
<a href="#">AI-000712-3</a>	Cordset	9	Male	Female	Straight-RS	PVC	Black	Anodized Aluminum	26	3'
<a href="#">BU-122730291</a>	Cordset	4	Female	Open	Straight-M12	PVC	Black	Anodized Aluminum	22	1.5M
<a href="#">BU-122730424</a>	Cordset	3	Male	Open	Straight-M12	PVC	Black	Anodized Aluminum	22	10M
<a href="#">BU-1402551</a>	Cordset	12	Male	Female	Straight-M12	PUR	Black	Anodized Aluminum	26	3M
<a href="#">BU-1404940</a>	Cordset	12	Male	Female	Straight-M12	PUR	Black	Anodized Aluminum	24	5M
<a href="#">BU-1406094</a>	Cordset	8	Male	Open	Straight-M12	PVC	Black	Anodized Aluminum	24	2M
<a href="#">BU-1406105</a>	Cordset	8	Female	Open	Straight-M12	PUR	Black	Anodized Aluminum	24	2M
<a href="#">BU-1406416</a>	Cordset	12	Female	Open	Straight-M12	PUR	Black	Anodized Aluminum	26	20M
<a href="#">BU-1669848</a>	Cordset	5	Female	Open	Straight-M12	PUR	Black	Anodized Aluminum	22	5M
<a href="#">BU-1682935</a>	Cordset	5	Female	Open	Straight-M12	PUR	Black	Anodized Aluminum	22	1.5M
<a href="#">BU-21349300405010</a>	Cordset	4	Female	Open	Straight-M12	PVC	Black	Anodized Aluminum	22	1M
<a href="#">BU-22731031</a>	Cordset	8	Female	Open	Right Angle-M12	PUR	Black	Anodized Aluminum	24	1.5M
<a href="#">BU-T4171110405002</a>	Receptacle	5	Female	Open	Rear Panel Mount-M12	PVC	N/A	Anodized Aluminum	22	.5M

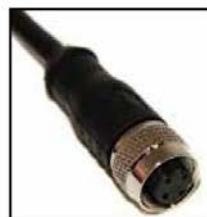

### M12 Cables: Receptacles

- UL 1007 PVC





- Front panel mount plug body
- Stainless steel coupling nut material
- Standard cable lengths are 2, 5 & 10 meters



***Other cable lengths available upon request***

Part Number	Cordset / Receptacle	Pin Count	Head Configuration		Plug Body	Cable Type	Coupling Nut Material	AWG	Cable Length (Meters)
			# 1	# 2					
<a href="#"><u>R3A07M002</u></a>	Receptacle	3	Male	Open End	Front Panel Mount	PVC	Stainless Steel	18	2
<a href="#"><u>R3A07M005</u></a>	Receptacle	3	Male	Open End	Front Panel Mount	PVC	Stainless Steel	18	5
<a href="#"><u>R3A07M010</u></a>	Receptacle	3	Male	Open End	Front Panel Mount	PVC	Stainless Steel	18	10
<a href="#"><u>R3C07M002</u></a>	Receptacle	3	Female	Open End	Front Panel Mount	PVC	Stainless Steel	18	2
<a href="#"><u>R3C07M005</u></a>	Receptacle	3	Female	Open End	Front Panel Mount	PVC	Stainless Steel	18	5
<a href="#"><u>R3C07M010</u></a>	Receptacle	3	Female	Open End	Front Panel Mount	PVC	Stainless Steel	18	10
<a href="#"><u>R4A08M002</u></a>	Receptacle	4	Male	Open End	Front Panel Mount	PVC	Stainless Steel	18	2
<a href="#"><u>R4A08M005</u></a>	Receptacle	4	Male	Open End	Front Panel Mount	PVC	Stainless Steel	18	5
<a href="#"><u>R4A08M010</u></a>	Receptacle	4	Male	Open End	Front Panel Mount	PVC	Stainless Steel	18	10
<a href="#"><u>R4C08M002</u></a>	Receptacle	4	Female	Open End	Front Panel Mount	PVC	Stainless Steel	18	2
<a href="#"><u>R4C08M005</u></a>	Receptacle	4	Female	Open End	Front Panel Mount	PVC	Stainless Steel	18	5
<a href="#"><u>R4C08M010</u></a>	Receptacle	4	Female	Open End	Front Panel Mount	PVC	Stainless Steel	18	10
<a href="#"><u>R5A09M002</u></a>	Receptacle	5	Male	Open End	Front Panel Mount	PVC	Stainless Steel	18	2
<a href="#"><u>R5A09M005</u></a>	Receptacle	5	Male	Open End	Front Panel Mount	PVC	Stainless Steel	18	5
<a href="#"><u>R5A09M010</u></a>	Receptacle	5	Male	Open End	Front Panel Mount	PVC	Stainless Steel	18	10
<a href="#"><u>R5C09M002</u></a>	Receptacle	5	Female	Open End	Front Panel Mount	PVC	Stainless Steel	18	2
<a href="#"><u>R5C09M005</u></a>	Receptacle	5	Female	Open End	Front Panel Mount	PVC	Stainless Steel	18	5
<a href="#"><u>R5C09M010</u></a>	Receptacle	5	Female	Open End	Front Panel Mount	PVC	Stainless Steel	18	10



# MUELLER ELECTRIC'S FACTORY AUTOMATION CABLE SERIES

## M8 CABLES





Mueller Electric | 2850 Gilchrist Rd, Building 5A, Akron, OH 44305 | 800.955.2629 | [www.muellerelectric.com](http://www.muellerelectric.com)

21



## MUELLER ELECTRIC'S M8 FACTORY AUTOMATION CABLE SERIES



### M8 Cables Full Listing: 3, 4, 6 & 8-Pin Positions, 22, 24 & 26 AWG

- Shielded PVC jacket insulation; unshielded PVC & un/shielded PUR also available
- Nickel-plated brass coupling nut material
- Standard cable lengths are 2, 5 & 10 meters
- Other cable lengths available upon request



Part Number	Cordset / Receptacle	Pin Count	Head Configuration		Plug Body	Cable Type	Cable Color	Coupling Nut Material	AWG	Cable Length (Meters)
			# 1	# 2						
<a href="#"><u>C83A01M002</u></a>	Cord Set	3	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><u>C83A01M005</u></a>	Cord Set	3	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><u>C83A01M010</u></a>	Cord Set	3	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><u>C83B01M002</u></a>	Cord Set	3	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><u>C83B01M005</u></a>	Cord Set	3	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><u>C83B01M010</u></a>	Cord Set	3	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><u>C83C01M002</u></a>	Cord Set	3	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><u>C83C01M005</u></a>	Cord Set	3	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><u>C83C01M010</u></a>	Cord Set	3	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><u>C83D01M002</u></a>	Cord Set	3	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><u>C83D01M005</u></a>	Cord Set	3	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><u>C83D01M010</u></a>	Cord Set	3	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><u>C83AC01M002</u></a>	Cord Set	3	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><u>C83AC01M005</u></a>	Cord Set	3	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><u>C83AC01M010</u></a>	Cord Set	3	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><u>C83AD01M002</u></a>	Cord Set	3	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><u>C83AD01M005</u></a>	Cord Set	3	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><u>C83AD01M010</u></a>	Cord Set	3	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	24	10M

<a href="#">C83BC01M002</a>	Cord Set	3	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#">C83BC01M005</a>	Cord Set	3	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#">C83BC01M010</a>	Cord Set	3	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#">C83BD01M002</a>	Cord Set	3	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#">C83BD01M005</a>	Cord Set	3	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#">C83BD01M010</a>	Cord Set	3	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#">C84A02M002</a>	Cord Set	4	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#">C84A02M005</a>	Cord Set	4	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#">C84A02M010</a>	Cord Set	4	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#">C84B02M002</a>	Cord Set	4	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#">C84B02M005</a>	Cord Set	4	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#">C84B02M010</a>	Cord Set	4	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#">C84C02M002</a>	Cord Set	4	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#">C84C02M005</a>	Cord Set	4	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#">C84C02M010</a>	Cord Set	4	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#">C84D02M002</a>	Cord Set	4	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#">C84D02M005</a>	Cord Set	4	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#">C84D02M010</a>	Cord Set	4	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	10M

22 Mueller Electric | 2850 Gilchrist Rd, Building 5A, Akron, OH 44305 | 800.955.2629 | [www.muellerelectric.com](http://www.muellerelectric.com)

### M8 Cables Full Listing: 3, 4, 6 & 8-Pin Positions, 22, 24 & 26 AWG

- Shielded PVC jacket insulation
- Unshielded PVC and un/shielded PUR jacket insulation also available
- Nickel-plated brass coupling nut material
- Standard cable lengths are 2, 5 & 10 meters



*Other cable lengths available upon request*

Part Number	Cordset / Receptacle	Pin Count	Head Configuration		Plug Body	Cable Type	Cable Color	Coupling Nut Material	AWG	Cable Length (Meters)
			# 1	# 2						
<a href="#">C84AC02M002</a>	Cord Set	4	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#">C84AC02M005</a>	Cord Set	4	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#">C84AC02M010</a>	Cord Set	4	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#">C84AD02M002</a>	Cord Set	4	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#">C84AD02M005</a>	Cord Set	4	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#">C84AD02M010</a>	Cord Set	4	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#">C84BC02M002</a>	Cord Set	4	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#">C84BC02M005</a>	Cord Set	4	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#">C84BC02M010</a>	Cord Set	4	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	24	10M

<a href="#">C84BD02M002</a>	Cord Set	4	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#">C84BD02M005</a>	Cord Set	4	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#">C84BD02M010</a>	Cord Set	4	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#">C86A03M002</a>	Cord Set	6	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#">C86A03M005</a>	Cord Set	6	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#">C86A03M010</a>	Cord Set	6	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#">C86B03M002</a>	Cord Set	6	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#">C86B03M005</a>	Cord Set	6	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#">C86B03M010</a>	Cord Set	6	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#">C86C03M002</a>	Cord Set	6	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#">C86C03M005</a>	Cord Set	6	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#">C86C03M010</a>	Cord Set	6	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#">C86D03M002</a>	Cord Set	6	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#">C86D03M005</a>	Cord Set	6	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#">C86D03M010</a>	Cord Set	6	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#">C86AC03M002</a>	Cord Set	6	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#">C86AC03M005</a>	Cord Set	6	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#">C86AC03M010</a>	Cord Set	6	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#">C86AD03M002</a>	Cord Set	6	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#">C86AD03M005</a>	Cord Set	6	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#">C86AD03M010</a>	Cord Set	6	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#">C86BC03M002</a>	Cord Set	6	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#">C86BC03M005</a>	Cord Set	6	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#">C86BC03M010</a>	Cord Set	6	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#">C86BD03M002</a>	Cord Set	6	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#">C86BD03M005</a>	Cord Set	6	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#">C86BD03M010</a>	Cord Set	6	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	26	10M

Mueller Electric | 2850 Gilchrist Rd, Building 5A, Akron, OH 44305 | 800.955.2629 | [www.muellerelectric.com](http://www.muellerelectric.com)

23



#### M8 Cables Full Listing: 3, 4, 6 & 8-Pin Positions, 22, 24 & 26 AWG

- Shielded PVC jacket insulation
- Unshielded PVC and un/shielded PUR jacket insulation also available
- Nickel-plated brass coupling nut material
- Standard cable lengths are 2, 5 & 10 meters



*Other cable lengths available upon request*

Part Number	Cordset / Receptacle	Pin Count	Head Configuration		Plug Body	Cable Type	Cable Color	Coupling Nut Material	AWG	Cable Length (Meters)
			# 1	# 2						

<a href="#"><b>C88A04M002</b></a>	Cord Set	8	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#"><b>C88A04M005</b></a>	Cord Set	8	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#"><b>C88A04M010</b></a>	Cord Set	8	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#"><b>C88B04M002</b></a>	Cord Set	8	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#"><b>C88B04M005</b></a>	Cord Set	8	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#"><b>C88B04M010</b></a>	Cord Set	8	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#"><b>C88C04M002</b></a>	Cord Set	8	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#"><b>C88C04M005</b></a>	Cord Set	8	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#"><b>C88C04M010</b></a>	Cord Set	8	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#"><b>C88D04M002</b></a>	Cord Set	8	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#"><b>C88D04M005</b></a>	Cord Set	8	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#"><b>C88D04M010</b></a>	Cord Set	8	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#"><b>C88AC04M002</b></a>	Cord Set	8	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#"><b>C88AC04M005</b></a>	Cord Set	8	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#"><b>C88AC04M010</b></a>	Cord Set	8	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#"><b>C88AD04M002</b></a>	Cord Set	8	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#"><b>C88AD04M005</b></a>	Cord Set	8	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#"><b>C88AD04M010</b></a>	Cord Set	8	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#"><b>C88BC04M002</b></a>	Cord Set	8	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#"><b>C88BC04M005</b></a>	Cord Set	8	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#"><b>C88BC04M010</b></a>	Cord Set	8	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#"><b>C88BD04M002</b></a>	Cord Set	8	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#"><b>C88BD04M005</b></a>	Cord Set	8	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#"><b>C88BD04M010</b></a>	Cord Set	8	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	26	10M





- Shielded PVC jacket insulation
- Unshielded PVC and un/shielded PUR jacket insulation also available
- Nickel-plated brass coupling nut material
- Standard cable lengths are 2, 5 & 10 meters



*Other cable lengths available upon request*

Part Number	Cordset / Receptacle	Pin Count	Head Configuration		Plug Body	Cable Type	Cable Color	Coupling Nut Material	AWG	Cable Length (Meters)
			# 1	# 2						
<a href="#"><u>C83A01M002</u></a>	Cord Set	3	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><u>C83A01M005</u></a>	Cord Set	3	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><u>C83A01M010</u></a>	Cord Set	3	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><u>C83C01M002</u></a>	Cord Set	3	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><u>C83C01M005</u></a>	Cord Set	3	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><u>C83C01M010</u></a>	Cord Set	3	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><u>C84A02M002</u></a>	Cord Set	4	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><u>C84A02M005</u></a>	Cord Set	4	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><u>C84A02M010</u></a>	Cord Set	4	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><u>C84C02M002</u></a>	Cord Set	4	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><u>C84C02M005</u></a>	Cord Set	4	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><u>C84C02M010</u></a>	Cord Set	4	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><u>C86A03M002</u></a>	Cord Set	6	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#"><u>C86A03M005</u></a>	Cord Set	6	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#"><u>C86A03M010</u></a>	Cord Set	6	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#"><u>C86C03M002</u></a>	Cord Set	6	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#"><u>C86C03M005</u></a>	Cord Set	6	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#"><u>C86C03M010</u></a>	Cord Set	6	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#"><u>C88A04M002</u></a>	Cord Set	8	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#"><u>C88A04M005</u></a>	Cord Set	8	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#"><u>C88A04M010</u></a>	Cord Set	8	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#"><u>C88C04M002</u></a>	Cord Set	8	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#"><u>C88C04M005</u></a>	Cord Set	8	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#"><u>C88C04M010</u></a>	Cord Set	8	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	10M



### M8 Cables: Right-Angle Mold Types

- Shielded PVC jacket insulation
- Unshielded PVC and un/shielded PUR jacket insulation also available
- Nickel-plated brass coupling nut material
- Standard cable lengths are 2, 5 & 10 meters



*Other cable lengths available upon request*

Part Number	Cordset / Receptacle	Pin Count	Head Configuration		Plug Body	Cable Type	Cable Color	Coupling Nut Material	AWG	Cable Length (Meters)
			# 1	# 2						
<a href="#"><u>C83B01M002</u></a>	Cord Set	3	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><u>C83B01M005</u></a>	Cord Set	3	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><u>C83B01M010</u></a>	Cord Set	3	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><u>C83D01M002</u></a>	Cord Set	3	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><u>C83D01M005</u></a>	Cord Set	3	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><u>C83D01M010</u></a>	Cord Set	3	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><u>C84B02M002</u></a>	Cord Set	4	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><u>C84B02M005</u></a>	Cord Set	4	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><u>C84B02M010</u></a>	Cord Set	4	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><u>C84D02M002</u></a>	Cord Set	4	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><u>C84D02M005</u></a>	Cord Set	4	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><u>C84D02M010</u></a>	Cord Set	4	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><u>C86B03M002</u></a>	Cord Set	6	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#"><u>C86B03M005</u></a>	Cord Set	6	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#"><u>C86B03M010</u></a>	Cord Set	6	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#"><u>C86D03M002</u></a>	Cord Set	6	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#"><u>C86D03M005</u></a>	Cord Set	6	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#"><u>C86D03M010</u></a>	Cord Set	6	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#"><u>C88B04M002</u></a>	Cord Set	8	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#"><u>C88B04M005</u></a>	Cord Set	8	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#"><u>C88B04M010</u></a>	Cord Set	8	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#"><u>C88D04M002</u></a>	Cord Set	8	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#"><u>C88D04M005</u></a>	Cord Set	8	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#"><u>C88D04M010</u></a>	Cord Set	8	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	10M



### M8 Cables: Open-Ended Cables

- Shielded PVC jacket insulation
- Unshielded PVC and un/shielded PUR jacket insulation also available
- Nickel-plated brass coupling nut material
- Standard cable lengths are 2, 5 & 10 meters



*Other cable lengths available upon request*

Part Number	Cordset / Receptacle	Pin Count	Head Configuration		Plug Body	Cable Type	Cable Color	Coupling Nut Material	AWG	Cable Length (Meters)
			# 1	# 2						
<a href="#"><u>C83A01M002</u></a>	Cord Set	3	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><u>C83A01M005</u></a>	Cord Set	3	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><u>C83A01M010</u></a>	Cord Set	3	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><u>C83B01M002</u></a>	Cord Set	3	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><u>C83B01M005</u></a>	Cord Set	3	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><u>C83B01M010</u></a>	Cord Set	3	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><u>C83C01M002</u></a>	Cord Set	3	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><u>C83C01M005</u></a>	Cord Set	3	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><u>C83C01M010</u></a>	Cord Set	3	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><u>C83D01M002</u></a>	Cord Set	3	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><u>C83D01M005</u></a>	Cord Set	3	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><u>C83D01M010</u></a>	Cord Set	3	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><u>C84A02M002</u></a>	Cord Set	4	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><u>C84A02M005</u></a>	Cord Set	4	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><u>C84A02M010</u></a>	Cord Set	4	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><u>C84B02M002</u></a>	Cord Set	4	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><u>C84B02M005</u></a>	Cord Set	4	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><u>C84B02M010</u></a>	Cord Set	4	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	10M

<a href="#">C84C02M002</a>	Cord Set	4	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#">C84C02M005</a>	Cord Set	4	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#">C84C02M010</a>	Cord Set	4	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#">C84D02M002</a>	Cord Set	4	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#">C84D02M005</a>	Cord Set	4	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#">C84D02M010</a>	Cord Set	4	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#">C86A03M002</a>	Cord Set	6	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#">C86A03M005</a>	Cord Set	6	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#">C86A03M010</a>	Cord Set	6	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#">C86B03M002</a>	Cord Set	6	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#">C86B03M005</a>	Cord Set	6	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#">C86B03M010</a>	Cord Set	6	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#">C86C03M002</a>	Cord Set	6	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#">C86C03M005</a>	Cord Set	6	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#">C86C03M010</a>	Cord Set	6	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#">C86D03M002</a>	Cord Set	6	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#">C86D03M005</a>	Cord Set	6	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#">C86D03M010</a>	Cord Set	6	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	10M

Mueller Electric | 2850 Gilchrist Rd, Building 5A, Akron, OH 44305 | 800.955.2629 | [www.muellerelectric.com](http://www.muellerelectric.com)

27



### M8 Cables: Open-Ended Cables

- Shielded PVC jacket insulation
- Unshielded PVC and un/shielded PUR jacket insulation also available
- Nickel-plated brass coupling nut material
- Standard cable lengths are 2, 5 & 10 meters



*Other cable lengths available upon request*

Part Number	Cordset / Receptacle	Pin Count	Head Configuration		Plug Body	Cable Type	Cable Color	Coupling Nut Material	AWG	Cable Length (Meters)
			# 1	# 2						
<a href="#">C88A04M002</a>	Cord Set	8	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#">C88A04M005</a>	Cord Set	8	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#">C88A04M010</a>	Cord Set	8	Male	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#">C88B04M002</a>	Cord Set	8	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#">C88B04M005</a>	Cord Set	8	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#">C88B04M010</a>	Cord Set	8	Male	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#">C88C04M002</a>	Cord Set	8	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#">C88C04M005</a>	Cord Set	8	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#">C88C04M010</a>	Cord Set	8	Female	Open End	Straight	PVC	Yellow	Nickel-Plated Brass	26	10M

<a href="#">C88D04M002</a>	Cord Set	8	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#">C88D04M005</a>	Cord Set	8	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#">C88D04M010</a>	Cord Set	8	Female	Open End	Right Angle	PVC	Yellow	Nickel-Plated Brass	26	10M

28 Mueller Electric | 2850 Gilchrist Rd, Building 5A, Akron, OH 44305 | 800.955.2629 | [www.muellerelectric.com](http://www.muellerelectric.com)

### M8 Cables: Double-Ended Cables

- Shielded PVC jacket insulation
- Unshielded PVC and un/shielded PUR jacket insulation also available
- Nickel-plated brass coupling nut material
- Standard cable lengths are 2, 5 & 10 meters

*Other cable lengths available upon request*



Part Number	Cordset / Receptacle	Pin Count	Head Configuration		Plug Body	Cable Type	Cable Color	Coupling Nut Material	AWG	Cable Length (Meters)
			# 1	# 2						

<a href="#"><b>C83AC01M002</b></a>	Cord Set	3	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><b>C83AC01M005</b></a>	Cord Set	3	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><b>C83AC01M010</b></a>	Cord Set	3	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><b>C83AD01M002</b></a>	Cord Set	3	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><b>C83AD01M005</b></a>	Cord Set	3	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><b>C83AD01M010</b></a>	Cord Set	3	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><b>C83BC01M002</b></a>	Cord Set	3	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><b>C83BC01M005</b></a>	Cord Set	3	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><b>C83BC01M010</b></a>	Cord Set	3	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><b>C83BD01M002</b></a>	Cord Set	3	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><b>C83BD01M005</b></a>	Cord Set	3	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><b>C83BD01M010</b></a>	Cord Set	3	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><b>C84AC02M002</b></a>	Cord Set	4	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><b>C84AC02M005</b></a>	Cord Set	4	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><b>C84AC02M010</b></a>	Cord Set	4	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><b>C84AD02M002</b></a>	Cord Set	4	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><b>C84AD02M005</b></a>	Cord Set	4	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><b>C84AD02M010</b></a>	Cord Set	4	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><b>C84BC02M002</b></a>	Cord Set	4	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><b>C84BC02M005</b></a>	Cord Set	4	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><b>C84BC02M010</b></a>	Cord Set	4	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><b>C84BD02M002</b></a>	Cord Set	4	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	24	2M
<a href="#"><b>C84BD02M005</b></a>	Cord Set	4	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	24	5M
<a href="#"><b>C84BD02M010</b></a>	Cord Set	4	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	24	10M
<a href="#"><b>C86AC03M002</b></a>	Cord Set	6	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#"><b>C86AC03M005</b></a>	Cord Set	6	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#"><b>C86AC03M010</b></a>	Cord Set	6	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#"><b>C86AD03M002</b></a>	Cord Set	6	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#"><b>C86AD03M005</b></a>	Cord Set	6	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#"><b>C86AD03M010</b></a>	Cord Set	6	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#"><b>C86BC03M002</b></a>	Cord Set	6	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#"><b>C86BC03M005</b></a>	Cord Set	6	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#"><b>C86BC03M010</b></a>	Cord Set	6	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#"><b>C86BD03M002</b></a>	Cord Set	6	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#"><b>C86BD03M005</b></a>	Cord Set	6	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#"><b>C86BD03M010</b></a>	Cord Set	6	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	26	10M



### M8 Cables: Double-Ended Cables



- Shielded PVC jacket insulation
- Unshielded PVC and un/shielded PUR jacket insulation also available
- Nickel-plated brass coupling nut material
- Standard cable lengths are 2, 5 & 10 meters



*Other cable lengths available upon request*

Part Number	Cordset / Receptacle	Pin Count	Head Configuration		Plug Body	Cable Type	Cable Color	Coupling Nut Material	AWG	Cable Length (Meters)
			# 1	# 2						
<a href="#"><u>C88AC04M002</u></a>	Cord Set	8	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#"><u>C88AC04M005</u></a>	Cord Set	8	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#"><u>C88AC04M010</u></a>	Cord Set	8	Male	Female	Straight-Straight	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#"><u>C88AD04M002</u></a>	Cord Set	8	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#"><u>C88AD04M005</u></a>	Cord Set	8	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#"><u>C88AD04M010</u></a>	Cord Set	8	Male	Female	Straight-Right Angle	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#"><u>C88BC04M002</u></a>	Cord Set	8	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#"><u>C88BC04M005</u></a>	Cord Set	8	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#"><u>C88BC04M010</u></a>	Cord Set	8	Male	Female	Right Angle-Straight	PVC	Yellow	Nickel-Plated Brass	26	10M
<a href="#"><u>C88BD04M002</u></a>	Cord Set	8	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	26	2M
<a href="#"><u>C88BD04M005</u></a>	Cord Set	8	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	26	5M
<a href="#"><u>C88BD04M010</u></a>	Cord Set	8	Male	Female	Right Angle-Right Angle	PVC	Yellow	Nickel-Plated Brass	26	10M



### M8 Cables: Receptacles

- UL1007 PVC
- Stainless steel coupling nut material
- Standard cable lengths are 2, 5 & 10 meters

*Other cable lengths available upon request*



Part Number	Cordset / Receptacle	Pin Count	Head Configuration		Plug Body	Cable Type	Coupling Nut Material	AWG	Cable Length (Meters)
			# 1	# 2					
<a href="#">R83A17M002</a>	Receptacle	3	Male	Open End	Front Panel Mount	PVC	Stainless Steel	24	2
<a href="#">R83A17M005</a>	Receptacle	3	Male	Open End	Front Panel Mount	PVC	Stainless Steel	24	5
<a href="#">R83A17M010</a>	Receptacle	3	Male	Open End	Front Panel Mount	PVC	Stainless Steel	24	10
<a href="#">R83C17M002</a>	Receptacle	3	Female	Open End	Front Panel Mount	PVC	Stainless Steel	24	2
<a href="#">R83C17M005</a>	Receptacle	3	Female	Open End	Front Panel Mount	PVC	Stainless Steel	24	5
<a href="#">R83C17M010</a>	Receptacle	3	Female	Open End	Front Panel Mount	PVC	Stainless Steel	24	10
<a href="#">R84A18M002</a>	Receptacle	4	Male	Open End	Front Panel Mount	PVC	Stainless Steel	24	2
<a href="#">R84A18M005</a>	Receptacle	4	Male	Open End	Front Panel Mount	PVC	Stainless Steel	24	5
<a href="#">R84A18M010</a>	Receptacle	4	Male	Open End	Front Panel Mount	PVC	Stainless Steel	24	10
<a href="#">R84C18M002</a>	Receptacle	4	Female	Open End	Front Panel Mount	PVC	Stainless Steel	24	2
<a href="#">R84C18M005</a>	Receptacle	4	Female	Open End	Front Panel Mount	PVC	Stainless Steel	24	5
<a href="#">R84C18M010</a>	Receptacle	4	Female	Open End	Front Panel Mount	PVC	Stainless Steel	24	10
<a href="#">R86A19M002</a>	Receptacle	6	Male	Open End	Front Panel Mount	PVC	Stainless Steel	26	2
<a href="#">R86A19M005</a>	Receptacle	6	Male	Open End	Front Panel Mount	PVC	Stainless Steel	26	5
<a href="#">R86A19M010</a>	Receptacle	6	Male	Open End	Front Panel Mount	PVC	Stainless Steel	26	10
<a href="#">R86C19M002</a>	Receptacle	6	Female	Open End	Front Panel Mount	PVC	Stainless Steel	26	2
<a href="#">R86C19M005</a>	Receptacle	6	Female	Open End	Front Panel Mount	PVC	Stainless Steel	26	5
<a href="#">R86C19M010</a>	Receptacle	6	Female	Open End	Front Panel Mount	PVC	Stainless Steel	26	10
<a href="#">R88A20M002</a>	Receptacle	8	Male	Open End	Front Panel Mount	PVC	Stainless Steel	26	2
<a href="#">R88A20M005</a>	Receptacle	8	Male	Open End	Front Panel Mount	PVC	Stainless Steel	26	5
<a href="#">R88A20M010</a>	Receptacle	8	Male	Open End	Front Panel Mount	PVC	Stainless Steel	26	10
<a href="#">R88C20M002</a>	Receptacle	8	Female	Open End	Front Panel Mount	PVC	Stainless Steel	26	2
<a href="#">R88C20M005</a>	Receptacle	8	Female	Open End	Front Panel Mount	PVC	Stainless Steel	26	5
<a href="#">R88C20M010</a>	Receptacle	8	Female	Open End	Front Panel Mount	PVC	Stainless Steel	26	10

Mueller Electric | 2850 Gilchrist Rd, Building 5A, Akron, OH 44305 | 800.955.2629 | [www.muellerelectric.com](http://www.muellerelectric.com)


31



## ADDITIONAL CABLES




7/8-16UN - M12

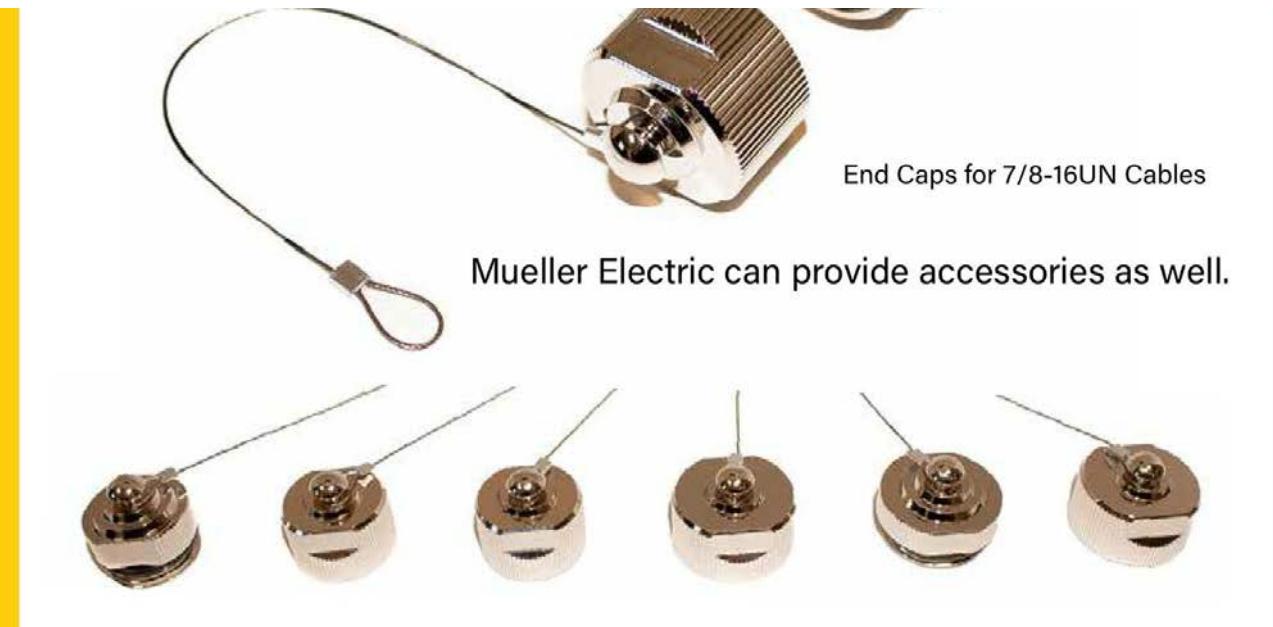

32 Mueller Electric | 2850 Gilchrist Rd, Building 5A, Akron, OH 44305 | 800.955.2629 | [www.muellerelectric.com](http://www.muellerelectric.com)



### Purple Ethernet Cable, 5-Pin

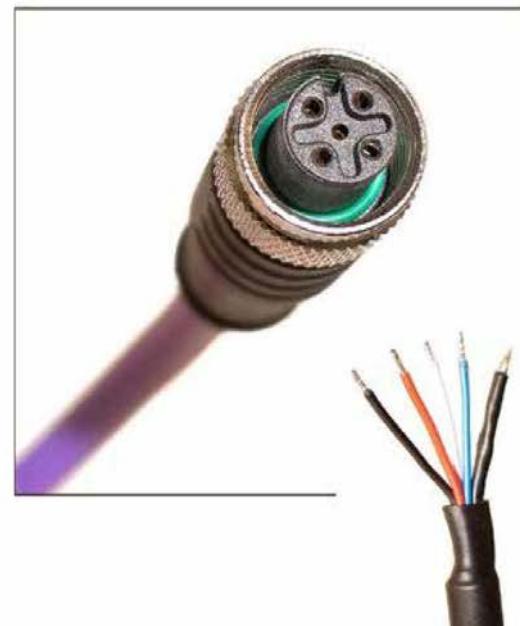



Mueller Electric offers a wide range of Ethernet cables.  
Here are just a couple of examples.



Blue Ethernet Cable, 4-Pin

Mueller Electric | 2850 Gilchrist Rd, Building 5A, Akron, OH 44305 | 800.955.2629 | [www.muellerelectric.com](http://www.muellerelectric.com)

33





Open-Ended M12 Cable With Junction Box

Custom-Designed Instrumentation Cables Available Upon Request



Open-Ended M12 Cable With Junction Box



7/8 - 16UN, 8-Pin  
Instrumentation Cable

M23 cables available through Mueller Electric.  
All English and Metric sizes available.



7/8 - 16UN, 6-Pin Instrumentation Cable & Male Receptacle




M12 - M8 Instrumentation Cable, 4-Pin



M12 - M12 Light-Up  
Ethernet Cable, 4-Pin



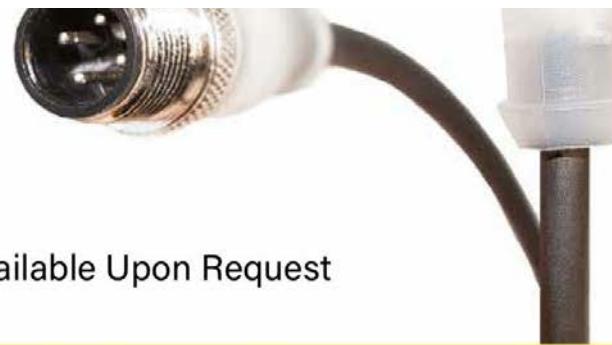

Custom Cable Designs Available Upon Request

36 Mueller Electric | 2850 Gilchrist Rd, Building 5A, Akron, OH 44305 | 800.955.2629 | [www.muellerelectric.com](http://www.muellerelectric.com)

 MUELLER





## M8 - M8 Molded Y-Connector Cable



Field Installable Connectors, Male & Female



Y Connector

Mueller Electric | 2850 Gilchrist Rd, Building 5A, Akron, OH 44305 | 800.955.2629 | [www.muellerelectric.com](http://www.muellerelectric.com)

37



# MUELLER ELECTRIC SPECIALIZES IN CUSTOM CABLE ASSEMBLY ORDERS

Unique challenges call for customized solutions.

**Mueller Electric** specializes in custom cable solutions in addition to standard OEM orders.

In business for more than a century, **Mueller Electric** has become the electronic expert industry leaders have come to trust. Ever since our beginning more than a century ago, Mueller Electric's name has become synonymous with quality and reliability.

mous with quality, durability and reliability. Throughout the years, our attention has remained squarely focused on the quality aspects of our products. As we've always said, Mueller products "outlast all others and cost less because they last."

**Mueller Electric** specializes in cable assemblies that are built to exact customer specifications. Short- and medium-production run quantities are welcome. These assemblies may incorporate standard or non-standard components and can be built to designated CE industry standards. Our in-house engineering, molding and production capabilities keep your project in plain view. Typical applications are for the industrial automation, test & measurement, medical, aerospace, military & defense, telecom and automotive markets.

Give **Mueller Electric** a try and let us prove our high standards to you. Contact our sales department to discuss your custom assembly needs. Be sure to ask about our sample assembly and prototype program.

**CONTACT MUELLER ELECTRIC TO GET CUSTOM CABLE ASSEMBLIES  
DESIGNED TO FIT YOUR UNIQUE NEEDS!**

**800.955.2629**

**[sales@muellerelectric.com](mailto:sales@muellerelectric.com)**



**INDUSTRIES SERVED**

- Factory Automation
- Manufacturing
- Automotive
- Transportation
- Medical Equipment
- Aerospace
- Military & Defense
- Information Technology
- Data Communications
- Telecommunications
- Test & Measurement

## WARRANTY

**Mueller Electric** products are warranted to be free from defects in materials and workmanship for a period of 12 months. For the full text of the Terms & Conditions of the Warranty, please go to [www.MuellerElectric.com/Warranty](http://www.MuellerElectric.com/Warranty)

Information in this catalog is subject to change without notice.

**Mueller Electric** reserves the right to make modifications to the information presented.



**MuellerElectric.com**

T: 800.955.2629

T: 330.780.2525

F: 330.780.2524

**[sales@muellerelectric.com](mailto:sales@muellerelectric.com)**

© 2021 by Mueller Electric. All rights reserved.  
No part of this publication may be reproduced without written permission.

[www.muellerelectric.com](http://www.muellerelectric.com)

