

**TRUST
THE
ORIGINAL**


powerCON[®] & etherCON[®]
Connectors for LED display applications



NEUTRIK[®]

SETTING STANDARDS

Neutrik Headquarters in Schaan, Principality of Liechtenstein

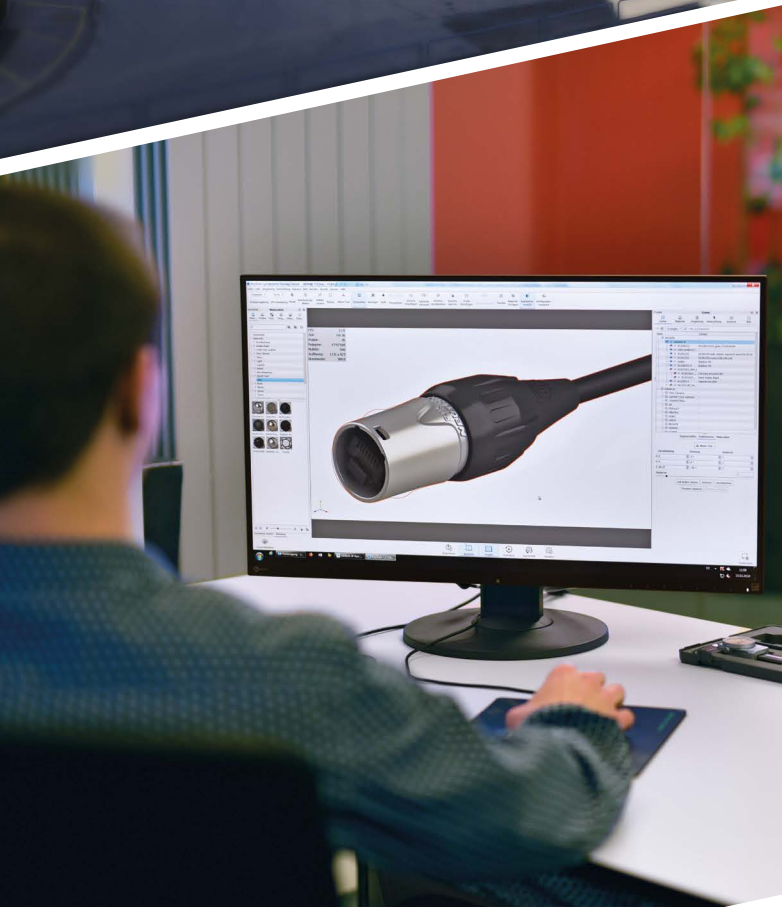



NEUTRIK® – the premium brand of the Neutrik Group

Neutrik is the worldwide leading supplier of professional connectors and connector systems for the entertainment industry and other complex special applications.

Located in The Principality of Liechtenstein, in the middle of Europe, Neutrik is synonymous with the development, production and distribution of innovative products which have set the standards. No matter whether a rock band or a lighting designer, an industrial application, a broadcast studio or LED Display application – Neutrik offers a superior quality and reliable connector solution for every application.

STATE-OF-THE-ART MANUFACTURING

More than 1000 highly trained employees, modern production facilities and standardized workflows ensure superior quality. Since the start in 1975 Neutrik produced more than 1 billion connectors that have set standards in functionality, technical reliability and durability around the world.

Neutrik's management system and processes are certified according to ISO 9001 and comply to the environmental standards RoHS, REACH and Sony Green Partner.

NEUTRIK powerCON® / NEUTRIK etherCON®

With the development of powerCON® and etherCON® Neutrik has set the standard for power- and data-connectors for a whole industry. For innovative solutions, superior quality and unmatched reliability – TRUST THE ORIGINAL.

**TRUST
THE
ORIGINAL**



SUPERIOR QUALITY AND RELIABILITY

4



NAC3FCB



NAC3FCA



NAC3MPA-1



NAC3MPB-1

powerCON®

ORDERING INFORMATION

NAC3FCA	Cable connector A-type for power inlet
NAC3MPA-1	Appliance connector, A-type for power inlet
NAC3MPA-1-WOT	Appliance connector, A-type for power inlet, without insulation divider
NAC3FCB	Cable connector B-type for power outlet
NAC3MPB-1	Appliance connector, B-type for power outlet
NAC3MPB-1-WOT	Appliance connector, B-type for power outlet, without insulation divider

- Lockable 3 pole single phase equipment (AC) connector
- High current capacity, rated at 20 A / 250 V ac
- Colour coded for easy identification, powerCON offers power-in (blue) and power-out (grey) versions with different keying to avoid the possibility of intermating
- Fast and easy locking system
- Extremely robust and reliable
- Excellent cable retention
- UL, cUL recognized components (file no. E 135070)
VDE certified (Reg. No. 6360),
- New latch design for easier handling and secure locking





NAC3FX-W-TOP



NAC3MX-W-TOP



NAC3PX-TOP



NAC3MPX-TOP



NAC3FPX-TOP

powerCON® TRUE1® TOP

ORDERING INFORMATION

NAC3FX-W-TOP	Locking Power-In cable connector
NAC3MX-W-TOP	Locking Power-Out cable connector
NAC3PX-TOP	Appliance inlet-outlet combination
NAC3MPX-TOP	Appliance inlet connector
NAC3MPX-WOT-TOP	Appliance inlet connector, without insulation divider
NAC3FPX-TOP	Appliance outlet connector
NAC3FPX-ST-TOP	Appliance outlet connector, screw terminals
NAC3FPX-WOT-TOP	Appliance outlet connector, without insulation divider
SCNAC-PX	Rubber sealing cover for NAC3PX-TOP
SCNAC-MPX	Rubber sealing cover for NAC3MPX-TOP
SCNAC-FPX	Rubber sealing cover for NAC3FPX-TOP

- True mains connector with breaking capacity (CBC)
- Designed to be engaged and disengaged in normal use when live or under load
- Lockable 16A (acc. IEC, VDE) / 20A (acc. UL) connector
- Complete system with inlet and outlet connectors
- Outdoor protection acc. IP65 and UL50E enclosure type 4
- Uses high impact, UV resistant materials per UL
- Certified according IEC 60320-1 and UL 498



**TRUE
OUTDOOR
PROTECTION**

**TRUST
THE
ORIGINAL**

SETTING STANDARDS

6

TRUE OUTDOOR
PROTECTION

RUGGED
& RELIABLE



**SUPERIOR
QUALITY**

**UV RESISTANT
IP65 RATED**



**TRUST
THE
ORIGINAL**

RUGGEDIZED DATA CONNECTORS



NE8MX6



NE8FDX-Y6-W



NE8FDX-P6

etherCON® CAT6_A

ORDERING INFORMATION

NE8MX6	cable connector CAT6A, nickel, Insulation diameter: > 1.10 - 1.60 mm
NE8MX6-B	cable connector CAT6A, black, Insulation diameter: > 1.10 - 1.60 mm
NE8MX6-T	cable connector CAT6A, nickel, Insulation diameter: > 0.85 - 1.10 mm
NE8MX6-B-T	cable connector CAT6A, black, Insulation diameter: > 0.85 - 1.10 mm
NE8FDX-P6	chassis CAT6A shielded feedthrough, nickel plating
NE8FDX-P6-B	chassis CAT6A shielded feedthrough, black plating
NE8FDX-Y6	chassis CAT6A shielded IDC, nickel plating
NE8FDX-Y6-B	chassis CAT6A shielded IDC, black plating
NE8FDX-P6-W	chassis CAT6A shielded feedthrough, with integrated rubber sealing cap, IP 65
NE8FDX-Y6-W	chassis CAT6A shielded IDC, with integrated rubber sealing cap, IP 65

- Ruggedized connector range with CAT6_A component compliance according to ISO / IEC 11801 respectively EN50173-1 and CAT6_A according to TIA / EIA 568-C.2
- D-size chassis connector for IDC self-termination or as feedthrough adapter
- IP 65 protected version available
- PoE+ compliant according to 802.3at Type2
- Downwards compatible with the existing etherCON CAT5 range



NE8MX-TOP



NE8FDV-TOP

etherCON® TOP

ORDERING INFORMATION

NE8MX-TOP	Rugged RJ45 cable connector carrier
NE8FDV-TOP	Rugged D-size chassis connector
NE8FDP-TOP	Rugged D-size feedthrough
NE8FDH-C5E-TOP	Rugged D-size PCB mount
SE8FD-TOP	Outdoor assembly kit

- Heavy-duty sealed RJ45 system for harsh environment
- Rugged cable connector carrier accepting most common RJ45 plugs
- D-sized receptacles for PCB mount or as feedthrough adapter
- Outdoor protection acc. IP65 and UL50E
- Uses high impact UV resistant materials per UL
- Sealing when disconnected by attached cover
- Class D or CAT5e acc. ISO/IEC 11801 and TIA/EIA 568B





**TRUE
OUTDOOR
PROTECTION**


**TRUST
THE
ORIGINAL**

LEADING EDGE SOLUTIONS

10

World's largest outdoor center-hung screen "Colossus" on Bristol Motor Speedway.
digiLED / Display LED Screens Ltd and GoVision

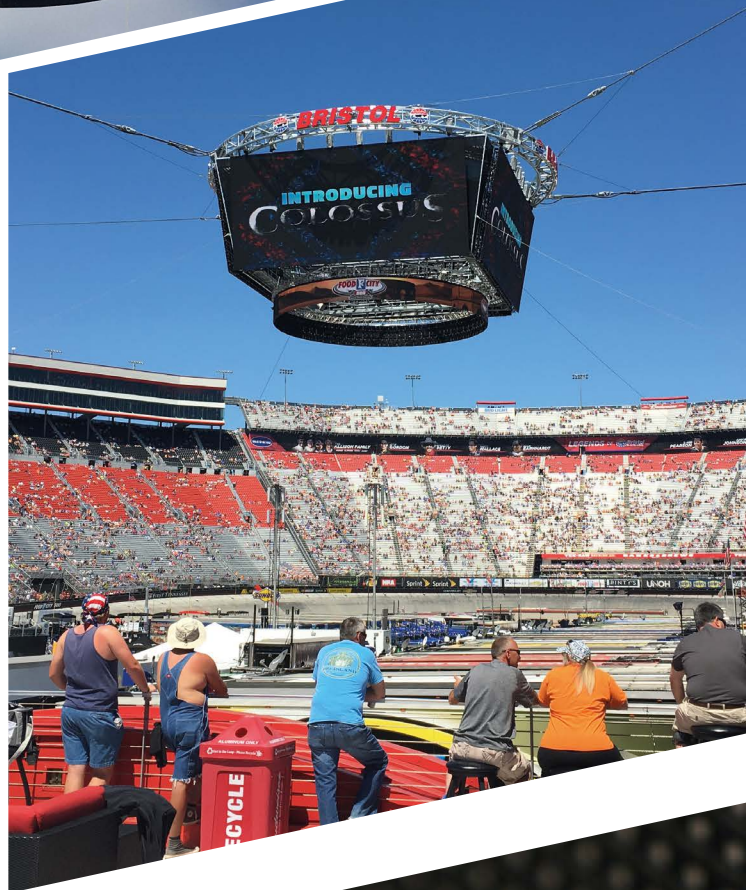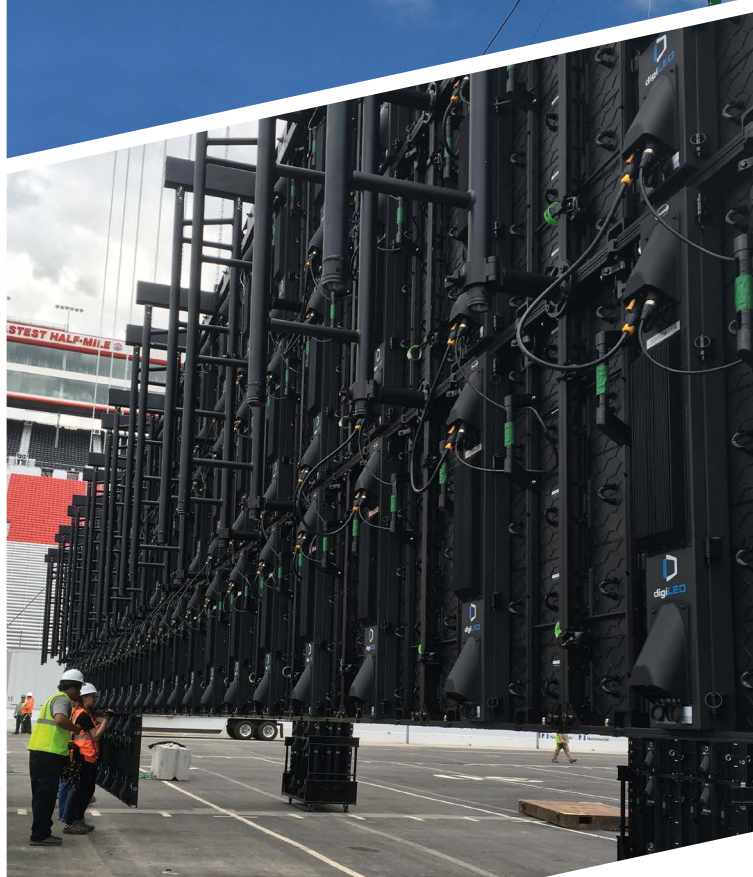

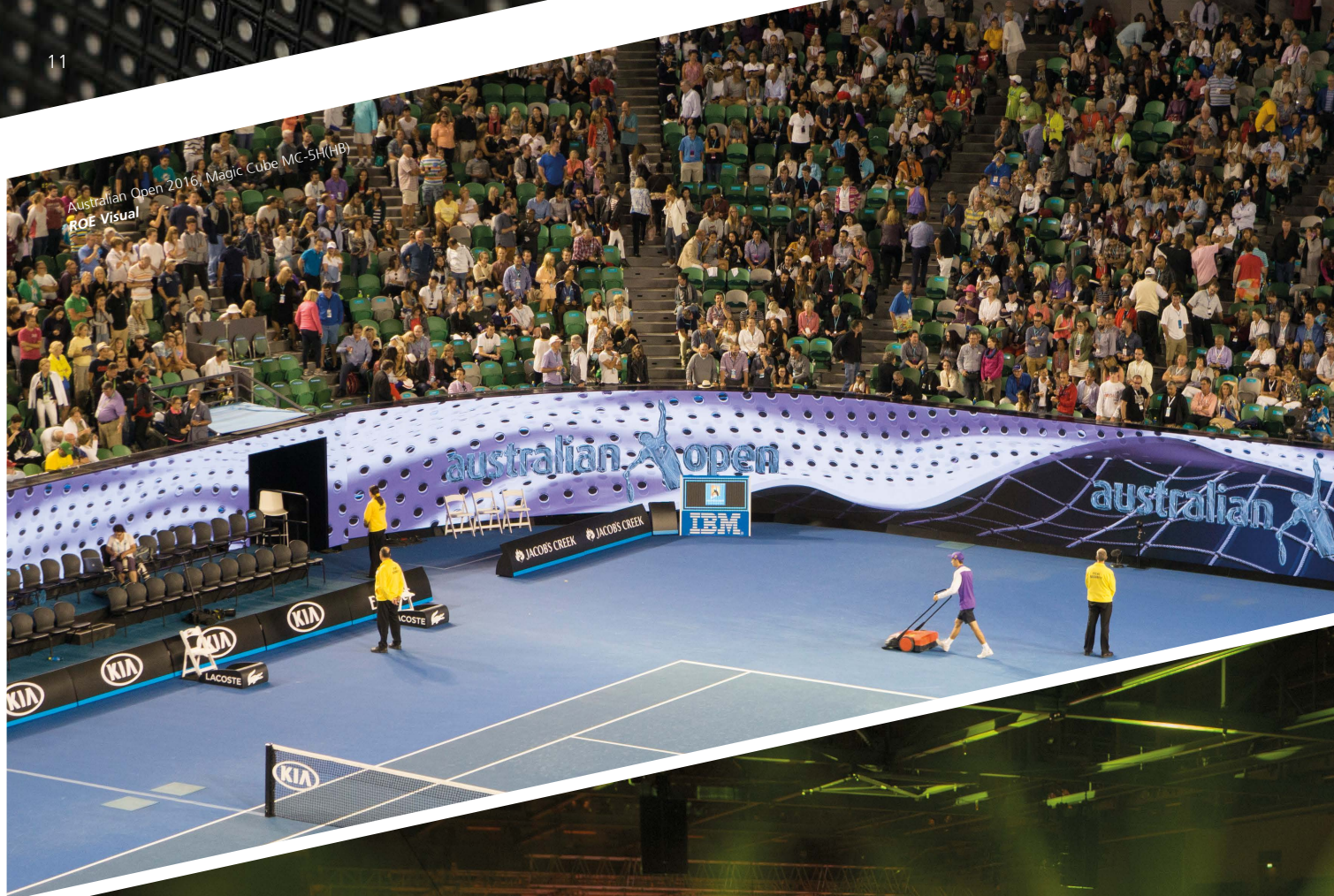

**TRUST
THE
ORIGINAL**

LIECHTENSTEIN (HEADQUARTERS)

Neutrik AG, Im alten Riet 143,
9494 Schaan, Liechtenstein
T +423 237 24 24, F +423 232 53 93, neutrik@neutrik.com

CHINA

Ningbo Neutrik Trading Co., Ltd., Shiqi Street, Yinxian Road West
Fengjia Village, Hai Shu District, Ningbo, Zhejiang, 315153
T +86 574 88250833, sales@neutrik.com.cn

HONG KONG

Neutrik Hong Kong LTD., Suite 18,
7th Floor Shatin Galleria Fotan, Shatin
T +852 2687 6055, sales@neutrik.com.hk

USA

Neutrik USA Inc., 4115 Taggart Creek Road,
Charlotte, North Carolina, 28208
T +1 704 972 30 50, info@neutrikusa.com

GERMANY / NETHERLANDS / DENMARK / AUSTRIA

Neutrik Vertriebs GmbH, Felix-Wankel-Strasse 1,
85221 Dachau, Germany
T +49 8131 28 08 90, neutrik@neutrik.de

FRANCE

Neutrik® France, 52 Rue d'aguessau,
92100 Boulogne
T +33 1 41 31 67 50, info@neutrik.fr

GREAT BRITAIN

Neutrik (UK) Ltd., Westridge Business Park, Cothey Way Ryde,
Isle of Wight PO33 1 QT
T +44 1983 811 441, sales@neutrik.co.uk

JAPAN

Neutrik Limited, Yusen-Higashinihonbashi-Ekimae Bldg., 3-7-19
Higashinihonbashi, Chuo-ku, Tokyo 103
T +81 3 3663 47 33, mail@neutrik.co.jp

INDIA

Neutrik India Pvt. Ltd., Level 3, Neo Vikram, New Link Road,
Above Audi Show Room, Andheri West, Mumbai, 400053
T +91 982 05 43 424, anklesaria@neutrik.com

ASSOCIATED COMPANIES

Contrik AG, Steinackerstrasse 35, 8902 Urdorf, Switzerland
T +41 44 736 50 10, contrik@contrik.ch

H. Adam GmbH, Felix-Wankel-Straße 1, 85221 Dachau, Germany
T +49 08131 28 08-0, anfrage@adam-gmbh.de

Connectors for LED display applications – NF20-V4-E 2019 03 – Data subject to change without prior notice. © 2019 NEUTRIK®.
NEUTRIK®, powerCON®, etherCON® are registered trademarks of NEUTRIK AG. ALL RIGHTS RESERVED.



www.neutrik.com