


Avery Dennison
Fastener Solutions
Product Guide

December 2023


Avery Dennison Cable Tie & Engineered Fastener Guide

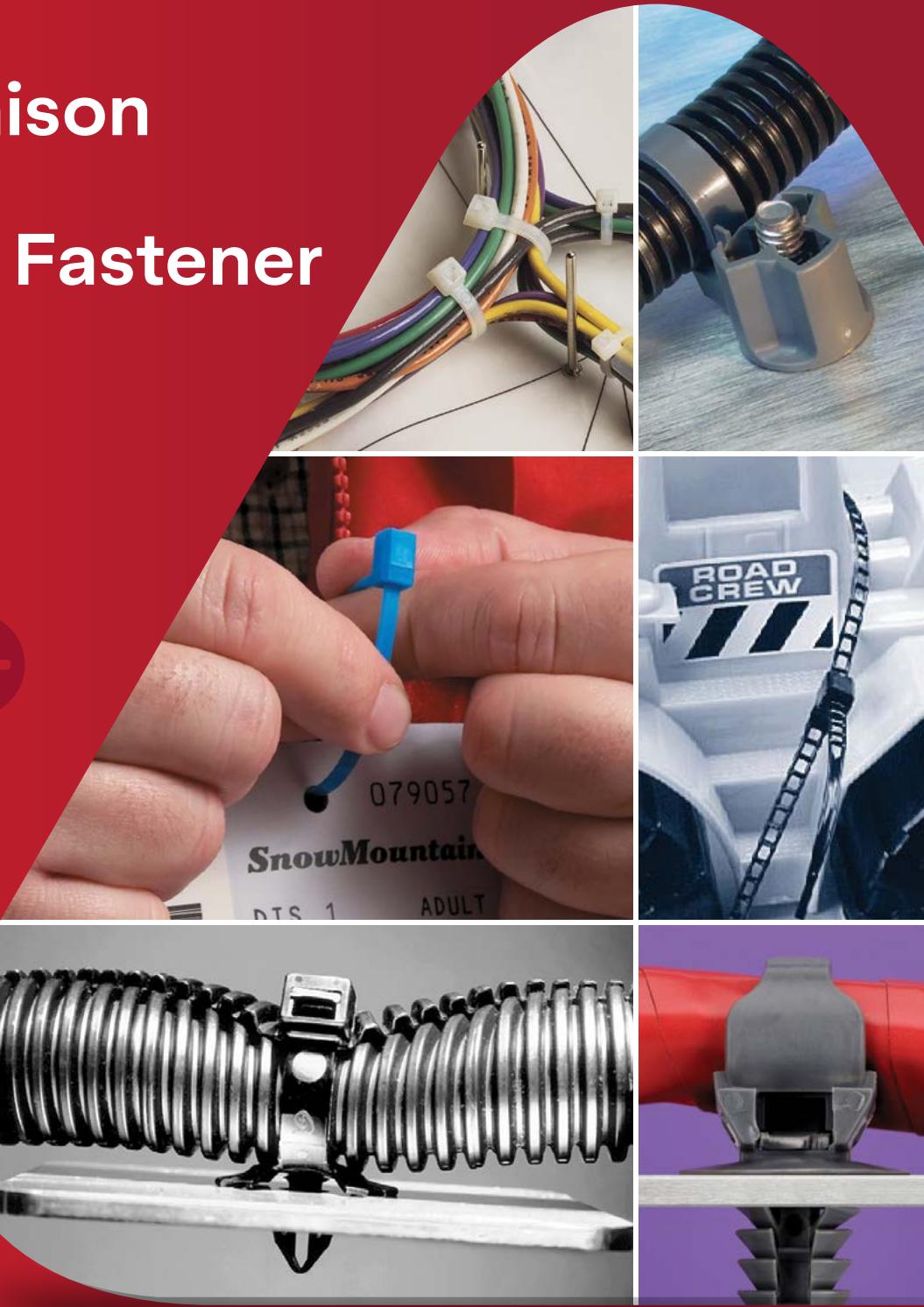

HOLE TIES

200940
004

CLICK PART# TO VIEW ONLINE

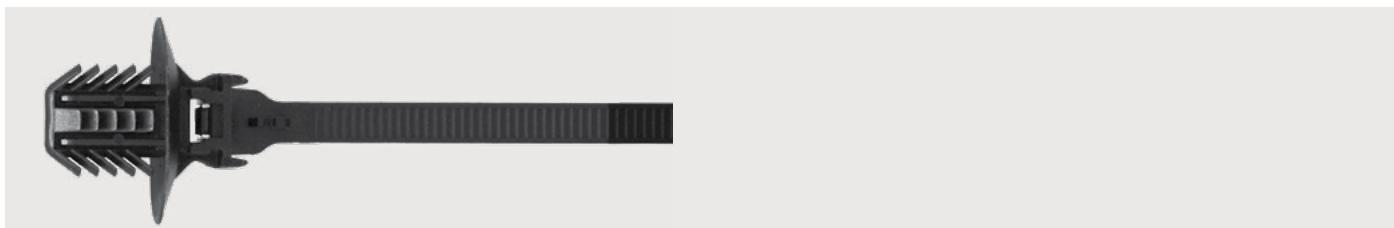

Oval Hole Fir Tree

[VIEW ONLINE](#)

PART #	DESCRIPTION	COLOR	TYPICAL MOUNT SIZE	MAX. PANEL THICKNESS	BUNDLE DIAMETER	MATERIAL	HS PART #	HHBN 150° C PART #
20185-0	Oval Fir Tree 38mm Max Bundle	Black	6.2 x 12.2 mm 6.5 x 12.5 mm 6.5 x 13.0 mm 7 x 12.0 mm	≤ 7.0 mm	1.6 - 38.1mm	PA66 IMHS	20196-0	20185-HHBN
20276-0	Oval Fir Tree 50mm Max Bundle	Black	6.2 x 12.2 mm 6.5 x 12.5 mm 6.5 x 13.0 mm 7 x 12.0 mm	≤ 7.0 mm	1.6 - 50.0mm	PA66 IMHS	20277-0	20276-HHBN
20297-0	2 Piece Oval Fir Tree HD	Black	6.2 x 12.2 mm 6.5 x 12.5 mm 6.5 x 13.0 mm 7 x 12.0 mm	≤ 7.0 mm	4.7-101.6mm	PA66 IMHS	20298-0	20297-HHBN
20299-0	2 Piece Oval Fir Tree Std	Black	6.2 x 12.2 mm 6.5 x 12.5 mm 6.5 x 13.0 mm 7 x 12.0 mm	≤ 7.0 mm	1.6 - 44.5mm	PA66 IMHS	20300-0	20299-HHBN
20317-0	Long 2 Piece Oval Fir Tree HD	Black	6.2 x 12.2 mm 6.5 x 12.5 mm 6.5 x 13.0 mm 7 x 12.0 mm	≤ 16mm	4.7-101.6mm	PA66 IMHS		
20318-0	Long 2 Piece Oval Fir Tree Std. No HS	Black	6.2 x 12.2 mm 6.5 x 12.5 mm 6.5 x 13.0 mm 7 x 12.0 mm	≤ 16mm	1.6 - 44.5mm	PA66 IMHS		



Offset Oval Hole Fir Tree

[VIEW ONLINE](#)

PART #	DESCRIPTION	COLOR	TYPICAL MOUNT SIZE	MAX. PANEL THICKNESS	BUNDLE DIAMETER	MATERIAL	HS PART #	HHBN 150° C PART #
20289-0	12.5mm Offset Oval Std	Black	6.2 x 12.2 mm 6.5 x 12.5 mm 6.5 x 13.0 mm 7 x 12.0 mm	≤ 7.0 mm	1.6 - 50.0mm	PA66 IMHS	20290-0	20289-HHBN
20291-0	25mm Offset Oval Std	Black	6.2 x 12.2 mm 6.5 x 12.5 mm 6.5 x 13.0 mm 7 x 12.0 mm	≤ 7.0 mm	1.6 - 50.0mm	PA66 IMHS	20292-0	20291-HHBN
20293-0	12.5mm Offset Oval Rev	Gray	6.2 x 12.2 mm 6.5 x 12.5 mm 6.5 x 13.0 mm 7 x 12.0 mm	≤ 7.0 mm	1.6 - 50.0mm	PA66 IMHS	20294-0	20293-HHBN
20295-0	25mm Offset Oval Rev	Gray	6.2 x 12.2 mm 6.5 x 12.5 mm 6.5 x 13.0 mm 7 x 12.0 mm	≤ 7.0 mm	1.6 - 50.0mm	PA66 IMHS	20296-0	20295-HHBN

World Wide Locations

USA & CANADA

Avery Dennison
224 Industrial Road
Fitchburg, MA 01420
USA
Tel. 800-225-5913
Tel. 978-345-8100
Fax. 800-848-2169
Email fastener@averydennison.com

ASIA

Avery Dennison
No. 7 Chun Ying Street
Tseung Kwan O Industrial Estate
New Territories
Hong Kong
Tel. 852-2372-3000
Fax. 852-2873-6436

EUROPE, MIDDLE EAST & AFRICA

Avery Dennison
Unit 5 Elia Close, Chapel Lane
High Wycombe
Buckinghamshire, HP12 4FX
United Kingdom
Tel. +44 0 1628 859500

LATIN AMERICA

Avery Dennison
Aristóteles #123
Parque Industrial Kalos
Apodaca, Nuevo León
66600
México
Tel. +52 (81) 3348 0700
Fax. + 52 (81) 8864 4101



Item numbers, descriptions and availability are subject to change. Please check website for current updates.

fastener.averydennison.com

To learn more or to get a quote, contact your sales representative, or visit:
fastener.averydennison.com

Connect with us on:



For more information on technical performance and printing recommendations, please refer to the respective datasheets. Please note that the Avery Dennison product range and service offering can be subject to changes. For an accurate overview, please check our website fastener.averydennison.com or contact your local Avery Dennison sales representative.

DISCLAIMER — ©2023 Avery Dennison Corporation. All rights reserved. Avery Dennison and all other Avery Dennison brands, this publication, its content, product names and codes are owned by Avery Dennison Corporation. All other brands and product names are trademarks of their respective owners. This publication must not be used, copied or reproduced in whole or in part for any purposes other than marketing by Avery Dennison. All Avery Dennison statements, technical information and recommendations are based on tests believed to be reliable but do not constitute a guarantee or warranty. All Avery Dennison products are sold with the understanding that purchaser has independently determined the suitability of such products for its purposes. All Avery Dennison's products are sold subject to Avery Dennison's general terms and conditions of sale.