



SOIC-14 to DIP-14 SMT Adapter (150 mil / 200 mil body)
Compact Series Extra Narrow

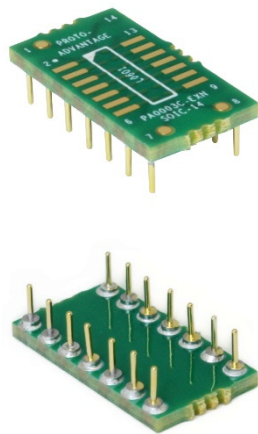


REF.	DIMENSIONS					
	mm			inches		
	MIN.	TYP.	MAX.	MIN.	TYP.	MAX.
A		4.12				
B		2.03				
C		0.64				
D		0.63				
E		1.27				
F					0.300	
G					0.100	
H		0.46				
X					0.380	
Y					0.700	

Top View (SMT Footprint)

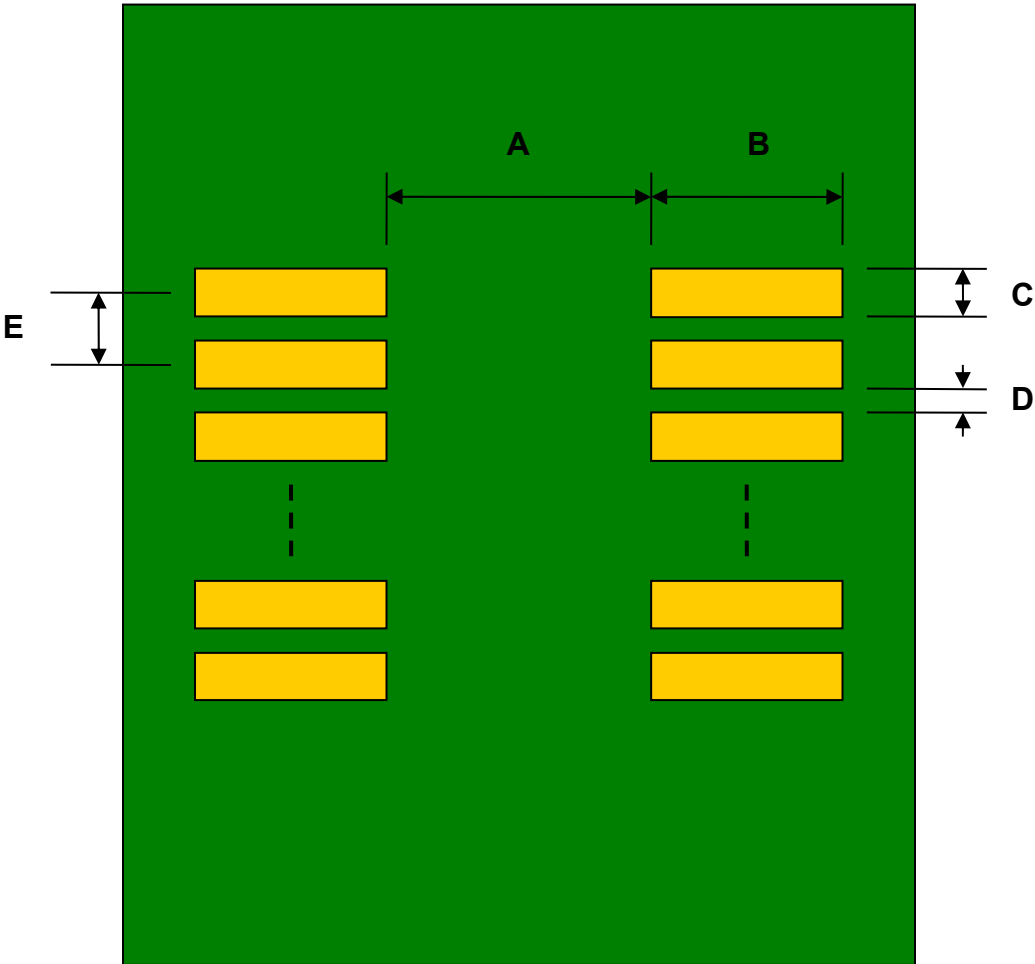


(Representative drawing only - not to scale)

Bottom View (DIP Pins)

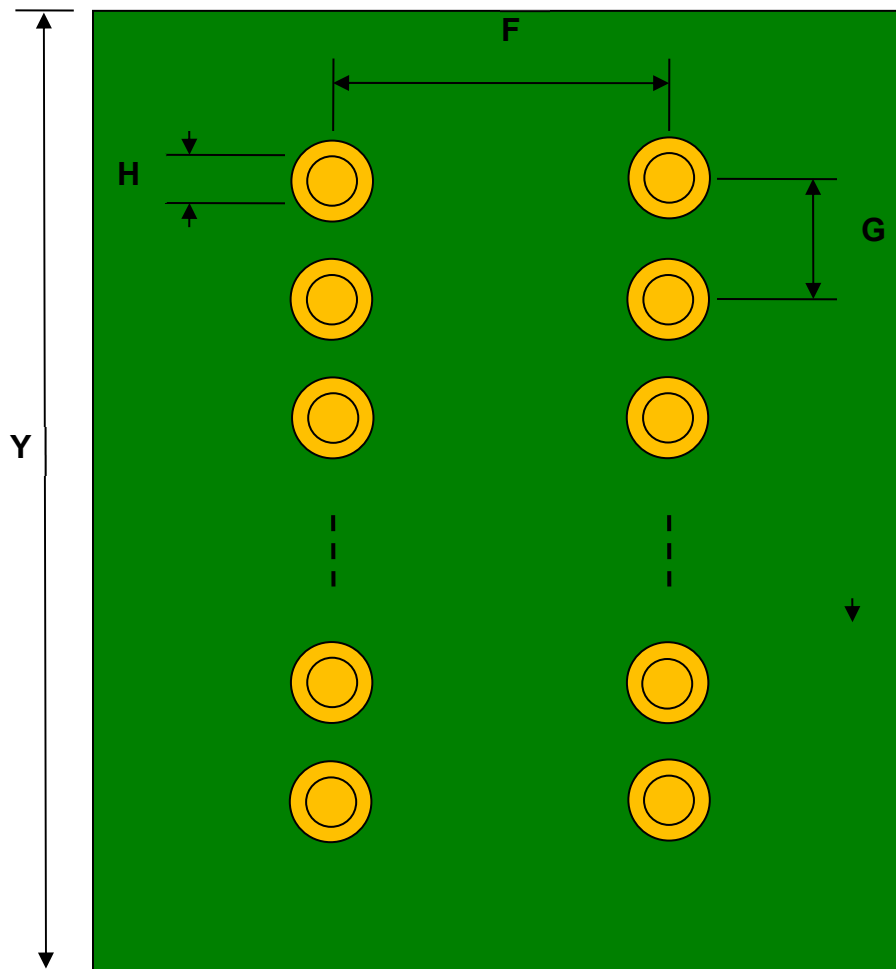

(Representative drawing only - not to scale)

Side View (DIP Pins)

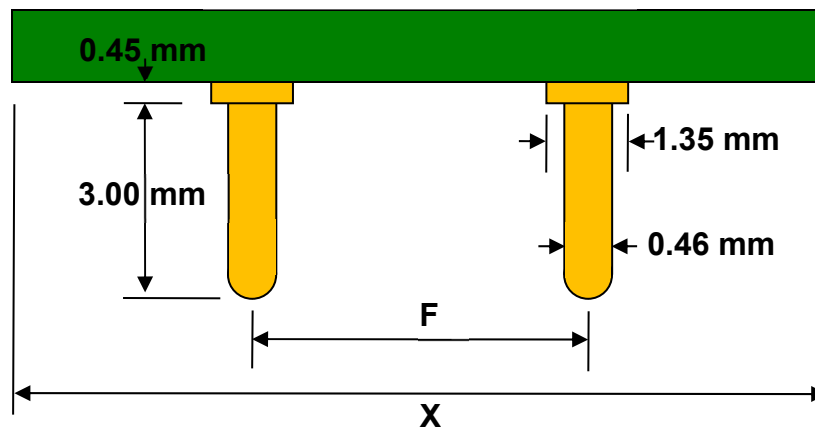

(Representative drawing only - not to scale)