

# 8-Digital LED Segment Display Modules

DFR0646


## Product Overview

06-14-2022

For the most up-to-date information, visit [www.mouser.com](http://www.mouser.com) or the supplier's website.

## Description

DFRobot DFR0646 8-Digital LED Segment Display Modules are steady performance devices that feature 5V operating voltage, <130mA operating current, a gravity IIC port, 16-level brightness adjustment, and 4 slave addresses. These modules operate at -40°C to 85°C temperature range and are available in 117mm x 22mm dimensions, red, and green colors.

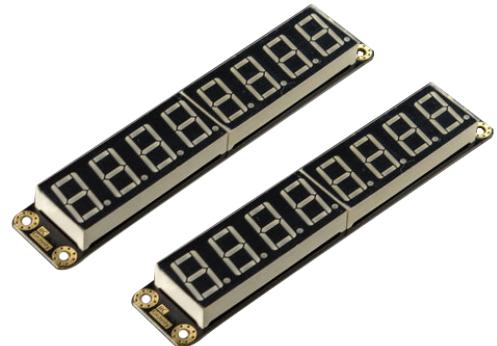

## Features

- Gravity IIC port
- 16-level brightness adjustment
- 4 slave addresses
- 5V operating voltage
- <130mA operating current
- 117mm x 22mm dimensions
- 10.1cm x 1.9 cm/3.970.75"
- Delicate appearance
- Steady appearance
- I<sup>2</sup>C communication
- Available in red and green colors

## Mouser Part Numbers

[View all Parts](#)

To learn more, visit <https://www.mouser.com/new/dfrobot/dfrobot-dfr0646-display-modules/>