


OCP ORV3

OCP-COMPLIANT AC INPUT CONNECTORS

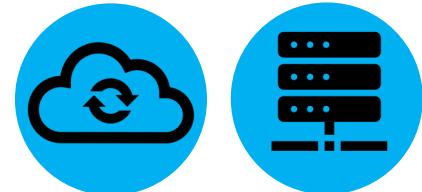


- Termination styles: right-angle PCB and crimp: 8AWG, 10AWG, 12 AWG, 16AWG
- Female crimp connectors available with backshell, locking latch, and shrouded contacts for safety
- Male PCB connectors available with solid-machined right-angle contacts, threaded inserts for improved structural integrity, and recessed contacts for safety
- Available with build-to-order cable whips
- All connector components are UL approved. Power cord shall meet UL/CSA SOOW or EU CENELEC <HAR> H07RN-F with +75°C temperature rating.

APPLICATIONS

- Power Management
- Power Shelves
- Servers

THE SCIENCE
OF **CERTAINTY**®

[View the catalog](#)

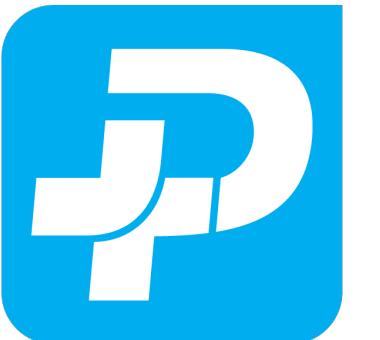

Positronic®
an Amphenol company