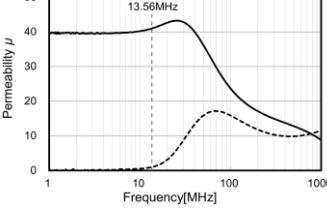
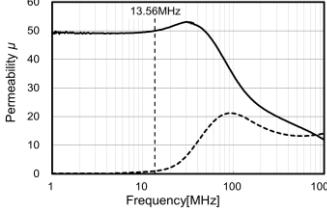


Features		High Magnetic Permeability & Low Magnetic Loss Type	
Type	M4	RM4A	
Effective Carrier Frequency	13.56 MHz and below		
Operating Temperature (°C)	-40 to +105	-40 to +85	
Thickness (mm)	0.1/0.2/0.3	0.1/0.2/0.25/0.3	
Standard Dimensions (mm)	240 X 240 (Roll on request)	220X185	
	40 typical	50 typical	
Permeability at 13.56 MHz			
Specific Gravity ¹	3.1 typical	3.6 typical	
Surface Resistivity (Ω/sq.)	1.0 X 10 ⁷ typical		
Approved Standard	UL 94 HB UL File No. E176124	-	
Environment	RoHS	Compliant	
	Halogen	Free	
	PVC	Free	
	Lead	Free	
	Red Phosphorus	Free	

¹ Value in 23°C atmosphere

Above specifications are for the Flex Suppressor® only (adhesives, etc., not included.)