

Soft Grip Series

Ties & Mounts

MADE FOR REAL®



Product overview

HellermannTyton



Soft Grip Ties (SGT)



Soft Grip Ties (SGT)



Soft Grip Tie (SGT) assembled with Soft Grip Mount (SGM) for holes




Unassembled set HDM320

- The Soft Grip Series consists of 2-component cable ties (PA66HS and TPE) and is designed for the flexible and easy bundling and fastening of smooth and sensitive bundles, such as pipes in vehicle fluid management applications
- Includes mounts that can be combined to make highly versatile fastening solutions
- The Soft Grip Tie has been tested and shown to reduce axial slide
- One Soft Grip cable tie can replace various P-Clamp diameters, significantly reducing individual part inventory and save installation time
- Can also be used in place where tape and a tie are used to reduce installation time

Features and benefits

HellermannTyton

Ties

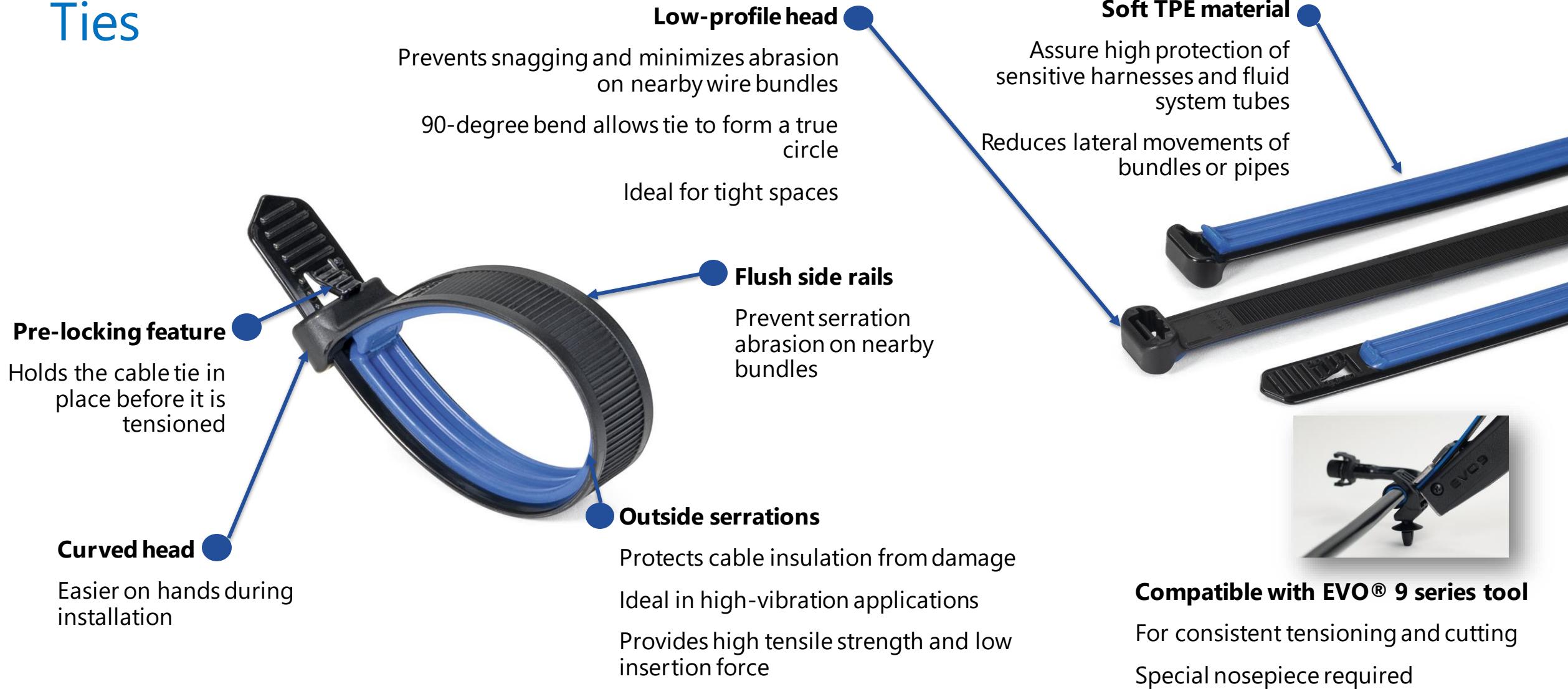

Ties with Mounts

Reduces the number of steps for fastening



Arrowhead mount for hole mounting



Screw mount with rivet for bolts, studs or screws

Applications

- Fluid management and cooling systems in vehicles
- Hoses and tubes
- Commonly used in
 - Automotive
 - Bus
 - Heavy Equipment/Truck



Additional info

Available as individual cable ties, cable tie assembly with mount (arrowhead) and unassembled with mount (HD mount)

Samples: SPLSGT (111-50001)



	SGT100S-PA66HS	SGT100S-PA66HIRHSUV
UNS	111-50000	111-50001
Type	Outside serrated	Outside serrated
Material	Cable Tie: PA66HS Soft Component: TPE	Cable Tie: PA66HIRHSUV Soft Component: TPE
Bundle diameter	5.0 – 25.4 mm	5.0 – 25.4 mm
Dimensions	140.0 mm x 12.7 mm	140.0 mm x 12.7 mm
Tensile strength	445 N	315 N
Operating temperature	-40°C up to +105°C	-40°C up to +105°C
Package quantity	500 pcs	500 pcs



	SGT100SAHD6.5S2.0	SGT100SHDM320SET
UNS	156-04097	156-03169
Type	For holes	For bolts, stud, or screw
Material	Cable Tie: PA66HS+TPE Mount: PA66HS	Cable Tie: PA66HIRHSUV+TPE Mount: PA66HIRHSUV, metal bushing
Bundle diameter	5.0 – 25.4 mm	10.0 – 25.4 mm
Fixation	Arrowhead for hole 6.5 mm	Screw mounting and rivet
Tensile strength	445 N	315 N
Operating temperature	-40°C up to +105°C	-40°C up to +105°C
Package quantity	250 assembled sets	500 unassembled sets

HellermannTyton