



a PennEngineering® Company

.....

Engineered Component Solutions for the Solar Industry

.....



PV Module Clips

Manage up to 4 cables directly on the PV module frame, frameless modules, or other similar materials.

● =  Covered under Heyco's 20 Year Solar Warranty

			100 Pack	Bulk Pack	
	SunRunner	(1 or 2 PV cables) for standard applications	S6405	S6445	●
	SunRunner Vidrio	(1 or 2 PV cables) for frameless modules	S6460	S6500	●
	SunRunner EZ	(1 or 2 PV cables) designed for thicker panels	S6407	S6447	●
	SunRunner Short Flange	(1 or 2 PV cables) for newer modules with shorter flanges	S6570	S6571	●
	RevRunner	(1 or 2 PV cables) for positioning cables within PV module frame	S6507	S6547	●
	SunRunner 2X2	(up to 4 PV cables) stacks PV cables 2X2 within frame	S6565	S6566	●
	SunRunner PVHR	Holds 2x PV cables and 1x Home Run in a single clip	S6600	S6601	●
	SunRunner 4	(up to 4 PV cables or 3 Enphase iQ cables) for standard applications	S6443	S6483	●
	SunRunner 4 EZ	(up to 4 PV cables or 3 Enphase iQ cables) designed for thicker panels	S6400	S6440	●
	SunRunner No Flange - 14	(1 or 2 PV cables) for newer modules without a flange - 14mm	S6592	S6593	●
	SunRunner No Flange - 16	(1 or 2 PV cables) for newer modules without a flange - 16mm	S6598	S6599	●
	SunRunner No Flange - 18	(1 or 2 PV cables) for newer modules without a flange - 18mm	S6595	S6596	●
	SunRunner 2-S	(For larger cables/Home Run)	S6448	S6488	●
	SunRunner 2-S EZ	(For larger cables/Home Run) designed for thicker panels	S6449	S6489	●
	SunRunner Bi-Directional	(1 or 2 PV cables) two mounting platforms for North/South or East/West	S6590	S6591	●
	SunRunner Short Flange 90	(1 or 2 PV cables) 90 degree clip for newer modules with shorter flanges	S6575	S6576	●
	SunRunner 90	(1 PV cable) 90 degree clip	S6406	S6446	●
	SunRunner 90-2	(1 or 2 PV cables) 90 degree clip	S6436	S6476	●
	SunRunner 90-4	(up to 4 PV cables) 90 degree clip	S6439	S6479	●
	Modular Wire Routing	(multiple wire sizes/configurations) modular design allows for flexibility/pre-assembly	See All Options on Website		
	Helios Clip Bi-Directional	(1 or 2 PV cables) works on either 7X10, 7X12, 9X14 or 8.5X16 oval mounting holes on frames	S6620 S6622 S6624 S6626	S6621 S6623 S6625 S6627	
	Helios Edge Clip	(1 or 2 PV cables) for panel frames between 1mm and 3mm	S6555	S6556	

Top Rail Clips

 
Manage trunk cables and/or PV wires along popular racking extrusions. Available in stainless steel or UV/Heat Stable nylon material.

● =  Covered under Heyco's 20 Year Solar Warranty

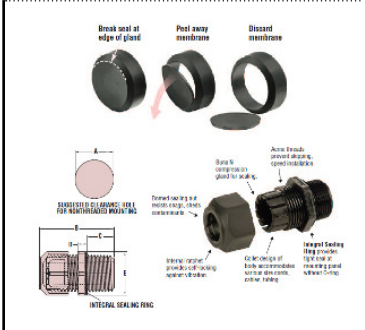
			100 Pack	Bulk Pack	
	SunRunner 4-2 Clip	(Enphase Q cable or SolarEdge cable) K2 Systems, SnapNRack and similar rail profiles	S6504	S6544	●
	SunRunner 2U Clip	(Round trunk cable) Unirac, Ironridge and similar rail profiles	S6401	S6441	●
	SunRunner 4-2U Clip	(Enphase Q cable or SolarEdge cable) Unirac, Ironridge and similar rail profiles	S6505	S6545	●
	SunRunner 2R Clip	(Round trunk cable) S:Flex, Renusol and similar rail profiles	S6402	S6442	●
	SunRunner 2 UVX Clip	(Nylon Clip for Round trunk cable) K2 Systems, SnapNRack and similar rail profiles	S6463	S6473	●
	SunRunner 2U UVX Clip	(Nylon Clip for Round trunk cable) Unirac, Ironridge and similar rail profiles	S6461	S6471	●
	SunRunner 2R UVX Clip	(Nylon Clip for Round trunk cable) S:Flex, Renusol and similar rail profiles	S6462	S6472	●
	Modular Wire Routing	(multiple wire sizes/configurations possible) Unirac, Ironridge and similar rail profiles	See All Options on Website		
	Quarter-Turn Fasteners for T-Slots	(multiple wire sizes/configurations possible) Compatible with popular T-Slot sizes			

Bundling Solutions & Other Accessories

● =  Covered under Heyco's 20 Year Solar Warranty

			100 Pack	Bulk Pack
	SunBundler	(For managing larger bundles ranging from .95" to 13.63" in diameter) Aircraft grade stainless steel wire with UV protected vinyl jacket. UL Specification 62275 for indoor and outdoor usage for Type 2 & 2S classifications	S6484	S6485
			S6486	S6487
			S6408	S6409
			S6410	S6411
			S6412	S6413
			S6414	S6415
			S6420	S6421
			S6424	S6425
			S6426	S6427
			S6428	S6429
			S6430	S6431
			S6491	S6492
			S6493	S6494
	SunStrap	Reusable Bundling Solution with 200lb. Tensile Strength PVC coated stainless steel Feed through eyelet and bend back over itself - easy installation!	S6608 S6612	
	SunHanger 1375	Releasable and Reusable - allows for easy maintenance and serviceability Heavy Duty Stainless Steel construction for harsh outdoor environments Easy installation - hang from module mounting holes or other structures PVC coated options provide additional abrasion protection	S6580	
	SunHanger 1375 Coated Black		S6581	
	SunHanger 1375-90		S6582	
	SunHanger 1375-90 Coated Black		S6583	
	SunHanger 2000		S6584	
	SunHanger 2000 Coated Black		S6585	
	SunHanger 2000-90		S6586	
	SunHanger 2000-90 Coated Black		S6587	
	Stainless Steel Cable Ties	(Bundles up to 11.81" in circumference) Stainless steel cable ties have more strength and better durability than nylon cable ties. Coated ties offer additional protection on the wire/cable bundle.		
	Heyco® Nytye® Nylon 12 Cable Ties	(Manages bundles ranging from .87" to 7.80" in diameter) Weather/UV resistant and suitable for high moisture, corrosive, and low temperature indoor or outdoor applications. Various tensile strengths and lengths available.		
	Heyco® Nytye® Nylon Cable Ties	(Manages bundles ranging from .63" to 18.07" in diameter) Easy-to-install way for managing cables. Light UV resistance-not recommended as the primary method for securing cables due to sensitivity to environmental conditions.		
	SunRunner CT & SunRunner CT-EZ	(Works with SunBundlers, Stainless Steel Cable Ties, & UV Nylon Cable Ties) Ideal for use where holes cannot be used or where adhesives are unacceptable. CT version accommodates panels from .06" - .13" CT-EZ version accommodates panels from .13" - .25"		
	MaxRunner	(Hold up to 12 cables with wire diameters ranging from .20" (5,2 mm) to .28" (7,2 mm). Attaches to materials from .06" to .25" thick with clip mount version or for more versatility, the flush mount version attaches with screws (not included).		
	SunScreener® Stainless Steel Wire Mesh Clips & SunScreen™ Wire Mesh	(Used together, helps protect solar panels from damage caused by rodents and nesting birds) Mesh size: 0.5" x 0.5" openings. Available in 4", 6", & 8" widths x 100' rolls.		
	Heyco® Edge Clips	Steel clip provides high panel retention forces, while requiring low insertion force. Plastic housing ensures easy, ergonomic installation. Ideal solution for applications where holes are not available or temperatures are too extreme for adhesive solutions.		

Cordgrips / Solar Mastheads

	Heyco®-Tite Solar Masthead® II	Liquid Tight Cordgrips (Eliminates the need for multiple entries into combiner boxes, junction boxes and other enclosures) Unique, skinned-over technology remains liquid tight even if all holes are not being used. New sizes now accommodate #6AWG!
	Heyco®-Tite Liquid Tight Cordgrips for Enphase Q	(Designed specifically for Enphase Q Cables) Provides a liquid tight connection into junction boxes for either 2 Enphase cables and 1 ground (3/4" NPT) or a single Enphase cable (1/2" NPT)
	Heyco-Tite Tear-Away Liquid Tight Cordgrips	The new Tear-Away Liquid Tight Cordgrips function as a plug prior to cable assembly, protecting your enclosure from rain, insects, and air contaminants while waiting to be installed. When it's time for cable installation, simply puncture the gland edge with a flat-head screwdriver and tear away the inner section for easy cable pass-through—just like with any standard Heyco Cable Gland.
	Heyco®-Tite Liquid Tight Cordgrips	(Provides a liquid tight connection for single cables or multiple cable configurations into micro-inverters, junction boxes, and other pieces of equipment) Available in NPT, Metric, and PG.

For more information or to order, contact:

800.526.4182 | renewables@heyco.com | www.heyco.com



**Covered
under Heyco's
20 Year Solar
Warranty**



a PennEngineering® Company

“Stay Connected with Heyco” Solar Power Components



Go to www.heyco.com and click on the Rep/Distributor box at the top of the home page to locate a representative near you.



To access Rep/Distributor lists for the following areas:

Americas

Canada | Mexico
South America | US (by state)

International

Africa | Europe | Asia
Middle East | Pacific/Oceania

Phone: 732-286-1800 Toll Free: 800-526-4182
renewables@heyco.com | www.heyco.com

©Copyright, Heyco Products Corp., 2022 Printed in USA

Heyco®, SunRunner®, SunBundler®, SunScreener®, Lockit™, and Nytye® are trademarks/registered trademarks of Heyco Products Corp.