

Terminal Blocks For Lighting Equipment

Amphenol
ANYTEK

INDUSTRIAL@AMPHENOL
TRUSTED GLOBALLY

新品发布-New Products



TQT
2P/3P/4P/5P



EQT
1-2P/1-3P/1-4P/1-5P

- 快速接线端子，一插即可使用，省时省力
Quick wiring terminal, can be used with just one plug, saving time and effort.
- 代替胶布，颠覆传统接线方式
Replace adhesive tape and overturn traditional wiring methods.
- 多种款式 - 少进多出/多进多出
Multiple styles - less in more out/more in more out.
- 不同位数和多种颜色可供选择
Different poles and multiple colors to choose from.

快速简单 - 接线不一样

Quick and Easy - Different Wiring




绝缘阻燃
Inflaming Retarding



接线牢固
Secure Connection




快速高效
Fast And Efficient

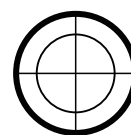


应用广泛
Wide Application

接线演示 Wiring demonstration


轻松接线 - 简单三步 Easy wiring - Three easy steps

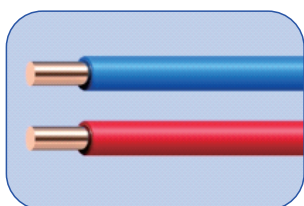

步骤1: 剥去电线外皮10mm
Step 1: Peel off the outer skin of the wire by 10mm.

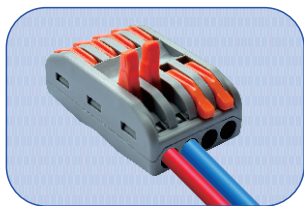

步骤2: 扳开助推手柄至垂直后, 把电线插入接线孔中
Step 2: After opening the boost handle to vertical, insert the wire into the wiring hole.

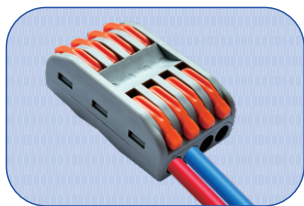

步骤3: 电线插入到位后, 将助推手柄按下即可
Step 3: Once the wire is in place, press down on the boost handle.

应用场景-Application Scenarios




灯具照明
Luminaire Lighting



家居家用
Household Appliance



大型仓库
Bulk Storage

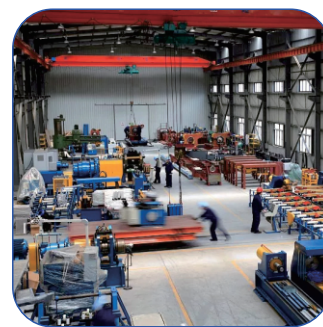


工厂设备
Factory Equipment

TQT Series



电气性能 - Electrical

产品型号 / Product Model	TQT	
间距 / Pitch	5.0mm	
位数 / Poles	2P/3P/4P/5P	
额定参数 / Rated Parameters	cULus	CQC
额定电压 / Voltage rating	600V	250V
额定电流 / Current rating	20A	32A
单芯线径 / Solid wire	12-24 AWG	0.2-4mm ²
多芯线径 / Stranded wire	12-24 AWG	0.2-4mm ²
剥线长度 / Wire strip length	9-10mm	
工作温度 / Operating Temperature	-20°C to +105°C	
安规认证 / Safety Approval	cULus	CQC
标准色 / Standard Colors		

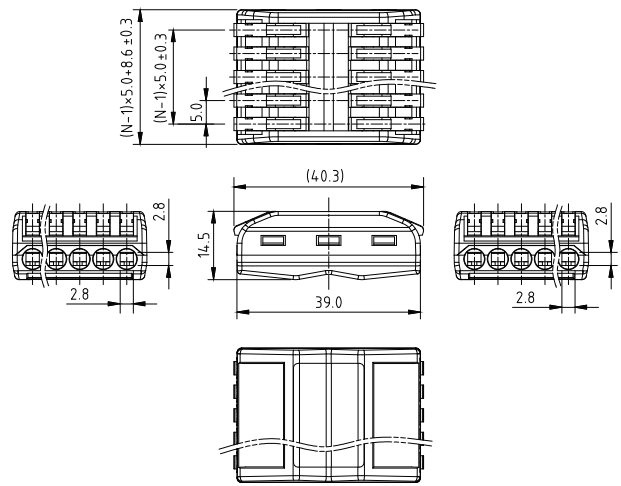


TQT

XX	X	X	X	X
Number of contacts	Body Color	Lever Color	Style	Serial Number
02 : 2 Poles 03 : 3 Poles 04 : 4 Poles 05 : 5 Poles	1 : Orange 2 : Gray 3 : Red 4 : Yellow 5 : Green 6 : Blue 7 : Brown 8 : Black 9 : White P : Pink V : Violet T : Transparent	1 : Orange 2 : Gray 3 : Red 4 : Yellow 5 : Green 6 : Blue 7 : Brown 8 : Black 9 : White P : Pink V : Violet M : Multiple Color	0 : Standard M : Min Style	


X	X	X
00 Standard (Steel screw plating Cr ³⁺) Any special item by customer request, please contact sales department.		G ROHS compliant (lead<4%) In copper alloy (High current)

EQT Series

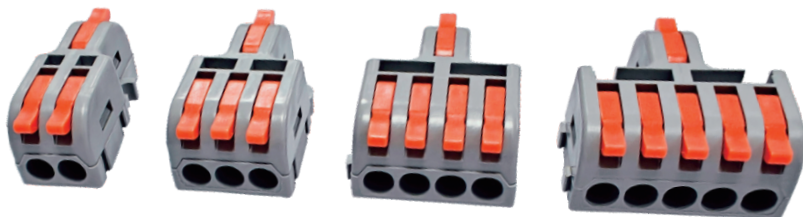

电气性能 - Electrical

产品型号 / Product Model	EQT	
间距 / Pitch	5.0mm	
位数 / Poles	1-2P/1-3P/1-4P/1-5P	
额定参数 / Rated Parameters	cULus	CQC
额定电压 / Voltage rating	600V	250V
额定电流 / Current rating	20A	32A
单芯线径 / Solid wire	12-24 AWG	0.2-4mm ²
多芯线径 / Stranded wire	12-24 AWG	0.2-4mm ²
剥线长度 / Wire strip length	9mm	
工作温度 / Operating Temperature	-20°C to +105°C	
安规认证 / Safety Approval	cULus CQC	
标准色 / Standard Colors		

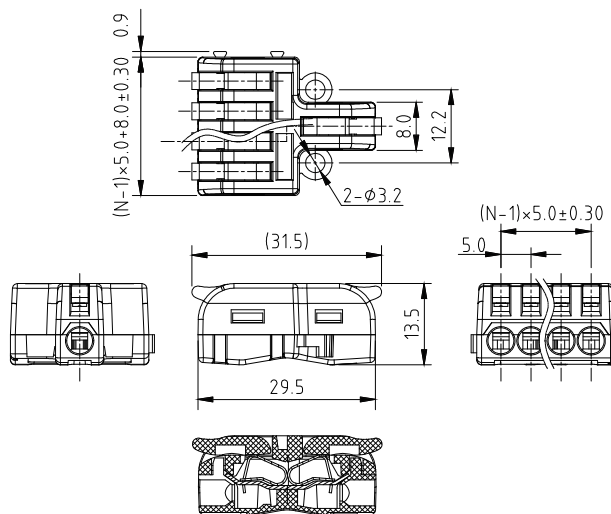

EQT

X X X X XX
Number of contacts Group Body Color Lever Color Serial Number

2 : 1-2 Poles
3 : 1-3 Poles
4 : 1-4 Poles
5 : 1-5 Poles

1 : 1 Group
2 : 2 Group
3 : 3 Group

1 : Orange
2 : Gray
3 : Red
4 : Yellow
5 : Green
6 : Blue
7 : Brown
8 : Black
9 : White
P : Pink
V : Violet

1 : Orange
2 : Gray
3 : Red
4 : Yellow
5 : Green
6 : Blue
7 : Brown
8 : Black
9 : White
P : Pink
V : Violet
M : Multiple Color

00 Standard
(Steel screw plating Cr³⁺)
Any special item by
customer request,
please contact sales
department.

G ROHS compliant
(lead<4%)
In copper alloy
(High current)