


- SPECIFICATIONS
- 1. SMA STRAIGHT PLUG P/N: RFCT-SMA144-M31.
 - 2. RG316 TINNED SHIELDING COAXIAL CABLE, COLOR: BROWN

- NOTES:
- 1. WORKING FREQUENCY RANGE: DC-12.4GHz.
 - 2. OPERATING TEMPERATURE: -40°C TO +125°C
 - 3. IMPEDANCE: 50 OHM

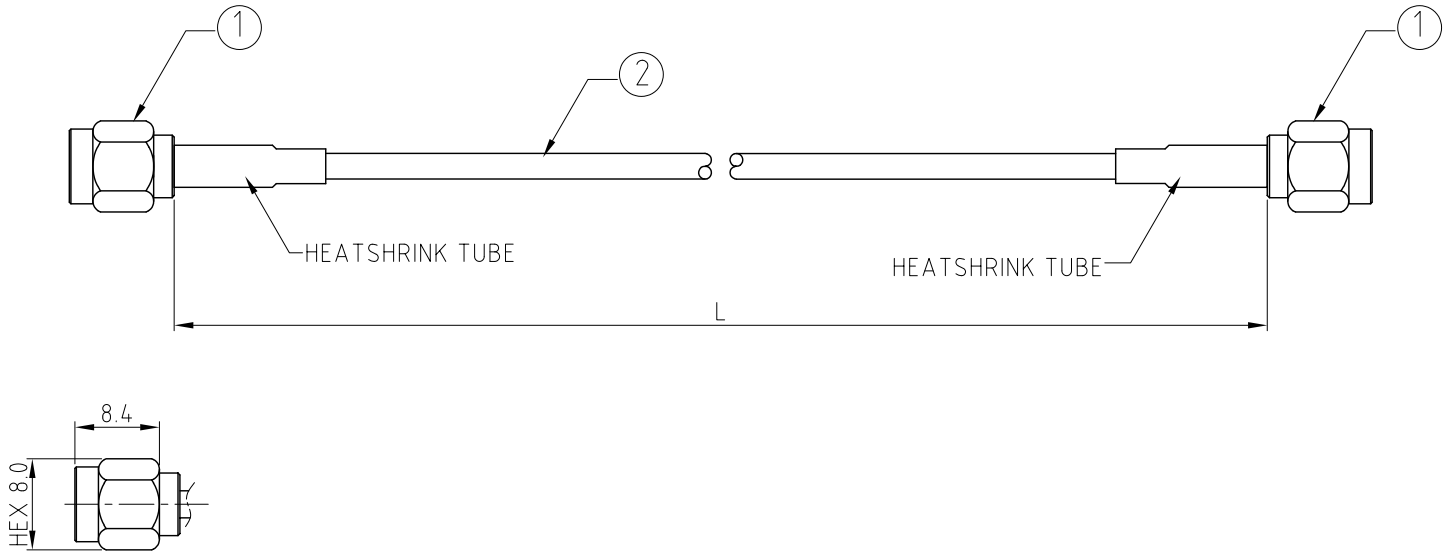

SMA PLUG DETAIL DRAWING

HOW TO ORDER

CAB661RF - XXXX - 1

"L" LENGTH IN MM:
eg: 100MM = 0100
(MIN. 0050-MAX.2000
STANDARD = 0305, 0610, 0915)
Tolerance: 50mm: ±2mm.
51-200mm: ±5mm.
201-500mm: ±7mm.
501-999mm: ±10mm.
≥1000mm: ± (Lx0.02)mm.

CABLE SIZE OPTIONS:
1 = RG316 CABLE, COLOR: BROWN