

Thin Profile Capacitive Proximity Level Sensor

Tripleshield™ protection


Application-optimized design

Easy setup and adjustment

Easy Mounting

IP68

Remote setup and adjustment

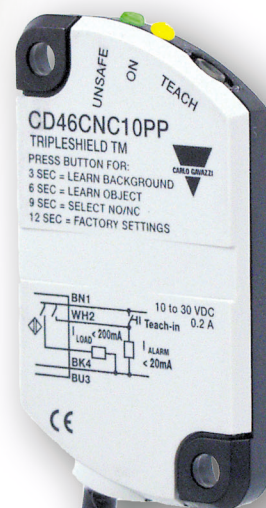

Sense



This thin profile capacitive sensor from Carlo Gavazzi has been designed on the basis of customer demands and our own 20 years of experience. The goal was to develop the smallest and most widely applicable rectangular capacitive sensor in the market.

The very small-size housing has been carefully prepared in all aspects, to enable it to fit into as many applications as possible - without compromising any of the high demands.

The sensor is based on the latest microprocessor technology, which has made it possible to implement features which enhance the user-friendliness and reliability of the application.

In addition, it gives us the flexibility to implement exactly the functionality you need, for example timer functions, filters, pulsed output or even logical expressions.



Breaking Standards Within:

Technology - Design - Price

Teach-in

The most interesting feature is the Teach-in function, with which the sensor is adjusted to detect or not to detect a certain medium.

The sensor can be taught to suppress a non-conductive foreground medium and to detect an item behind that foreground.

The Teach-in function can be activated by a pushbutton on the top of the sensor or remotely by a fourth wire connection.



Sensing distance



The sensors are designed with an extremely wide sensing distance interval with a nominal sensing range of 1,0 mm to 10 mm. You will always gain full advantage of the total performance - no matter whether the sensor is set to minimum or maximum distance. The wide sensing distance also protects the sensor against mechanical damage and ensures reliable detection and production flow.



Trippleshield™

Best Performance against:

- Electrostatic discharge
- Burst
- Airborne HF
- Wire-conducted noise
- High energy transients
- Short circuit
- Reverse polarity




Front mounting

- Direct mounting on non-metallic surfaces
- Stable mounting with screws in diagonal mounting holes
- Close-fitting of the sensor against the surface reduces dirt accumulation
- Mounting by use of hot-melt adhesive further eliminates dirt accumulation and error detection
- Detects most solid and fluid materials
- IP68-prepared for harsh and wet environments
- Sunk pushbutton prevents unintended activation



Pipe mounting

- Stable mounting via retaining strap in guide rail
- The thin profile
 - enables installation on pipes with even small diameters
 - stabilizes the mounting
- Horizontal or vertical cabling
- Easily accessible Teach-in function
- LEDs visible from several sides

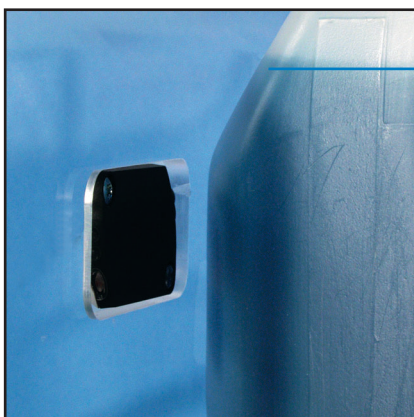

Plane mounting

- Sensor recessed in wall
- Fastened with countersunk screws
- Easily accessible remote Teach-in function
- Provides the highest protection against dirt accumulation and accidental touch by moving target

Type number	Type	Output	Supply voltage	Connection	Sensing Distance
CD46CNC10NP	3-wire DC	NPN NO/NC	10-30 VDC	Cable	0.5 to 10 mm
CD46CNC10PP	3-wire DC	PNP NO/NC	10-30 VDC	Cable	0.5 to 10 mm

OUR SALES NETWORK

Carlo Gavazzi GmbH - AUSTRIA
Ketzergrasse 374, A-1230 Wien
Tel: +43 1 888 4112
Fax: +43 1 889 10 53
office@carlogavazzi.at

Carlo Gavazzi NV/SA - BELGIUM
Schaarbeeklei 213/3, B-1800 Vilvoorde
Tel: +32 2 257 4120
Fax: +32 2 257 41 25
sales@carlogavazzi.be

Carlo Gavazzi Inc. - CANADA
2660 Meadowvale Boulevard,
CDN-Mississauga Ontario L5N 6M6,
Tel: +1 905 542 0979
Fax: +1 905 542 22 48
Carlo Gavazzi Ltee - CANADA
3777 Boulevard du Tricentenaire
Montreal, Quebec H1B 5W3
Tel: +1 514 644 2544
Fax: +1 514 644 2808
gavazzi@carlogavazzi.com

Carlo Gavazzi Handel A/S - DENMARK
Over Hadstenvej 38, DK-8370 Hadsten
Tel: +45 89 60 6100
Fax: +45 86 98 15 30
handel@gavazzi.dk

Carlo Gavazzi OY AB - FINLAND
Petaksentie 2-4, FI-00630 Helsinki
Tel: +358 9 756 2000
Fax: +358 9 756 20010
myynti@carlogavazzi.fi

Carlo Gavazzi Sarl - FRANCE
Zac de Paris Nord II, 69, rue de la Belle
Etoile, F-95956 Roissy CDG Cedex
Tel: +33 1 48 38 98 60
Fax: +33 1 48 63 27 43
french.team@carlogavazzi.fr

Carlo Gavazzi GmbH - GERMANY
Rudolf-Diesel-Strasse 23,
D-64331 Weiterstadt
Tel: +49 6151 81000
Fax: +49 6151 81 00 40
kontakt@carlogavazzi.de

Carlo Gavazzi UK Ltd - GREAT BRITAIN
7 Springlakes Industrial Estate,
Deadbrook Lane, Hants GU12 4UH,
GB-Aldershot
Tel: +44 1 252 339600
Fax: +44 1 252 326 799
sales@carlogavazzi.co.uk

Carlo Gavazzi SpA - ITALY
Via Milano 13, I-20020 Lainate
Tel: +39 02 931 761
Fax: +39 02 931 763 01
info@gavazziacbu.it

Gavazzi Automation Sdn Bhd
No. 1, Jalan Pendidik U1/31, Sek. U1,
Hicom Glenmarie Industrial Park
40150 Shah Alam, Selangor, - MALAYSIA
Tel: +60 3 5569 4212
Fax: +60 3 5568 0004
sales@gavazzi-asia.com

Carlo Gavazzi BV - NETHERLANDS
Wijkmeeweg 23,
NL-1948 NT Beverwijk
Tel: +31 251 22 9345
Fax: +31 251 22 60 55
info@carlogavazzi.nl

Carlo Gavazzi AS - NORWAY
Melkeveien 13, N-3919 Porsgrunn
Tel: +47 35 93 0800
Fax: +47 35 93 08 01
gavazzi@carlogavazzi.no

Carlo Gavazzi Lda - PORTUGAL
Rua dos Jerónimos 38-B,
P-1400-212 Lisboa
Tel: +351 21 361 7060
Fax: +351 21 362 13 73
carlogavazzi@carlogavazzi.pt

Carlo Gavazzi SA - SPAIN
Avda. Iparraguirre, 80-82,
E-48940 Leioa (Bizkaia)
Tel: +34 94 480 4037
Fax: +34 94 480 10 61
gavazzi@carlogavazzi-sa.es

Carlo Gavazzi AB - SWEDEN
Natvindsgatan 1, S-65221 Karlstad
Tel: +46 54 85 1125
Fax: +46 54 85 11 77
gavazzi@carlogavazzi.se

Carlo Gavazzi AG - SWITZERLAND
Verkauf Schweiz/Vente Suisse
Sumpfstrasse 32,
Tel: +41 41 747 4535
Fax: +41 41 740 45 40
verkauf_vente@carlogavazzi.ch

Carlo Gavazzi Inc. - USA
750 Hastings Lane,
USA-Buffalo Grove, IL 60089,
Tel: +1 847 465 6100
Fax: +1 847 465 7373
sales@carlogavazzi.com

OUR PRODUCTION SITES


Carlo Gavazzi Industri A/S
Hadsten - DENMARK
Tel: +45 89 60 6100

Carlo Gavazzi Ltd
Zejtun - MALTA
Tel: +356 21 693 780


Carlo Gavazzi Controls SpA
Belluno - ITALY
Tel: +39 0437 931 000

SAIET Elettronica SpA
Castel Maggiore (BO) - ITALY
Tel: +39 051 417 8811


Carlo Gavazzi Industri A/S
Hadsten - DENMARK
Tel: +45 89 60 6100

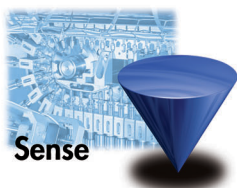

Inductive and Capacitive
Proximity Sensors in full metal
and plastic housings.
Photoelectric Sensors.
Level Sensors: Optical,
Conductive and Capacitive.
Ultrasonic Sensors and
Magnetic Switches.
Limit Switches.

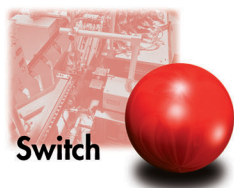

Solid States Relays.
Versions for PCB and
panel mounting.
AC Semiconductor
Motor Controllers
Soft starters.
Industrial and PCB Relays.

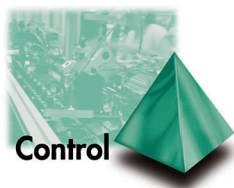

Energy Management.
Timers and
Monitoring Relays.
Digital Panel Meters and
Temperature Controllers.



Safety and Magnetic
Switches, Safety Modules.
Mat Systems, Light Curtains,
Electrical Transient Protection.
Measuring Systems and
Encoders.



Dupline Field and
Installation Bus.
Building Automation Systems.

Further information on www.carlogavazzi.com/ac

CARLO GAVAZZI
Automation Components

