


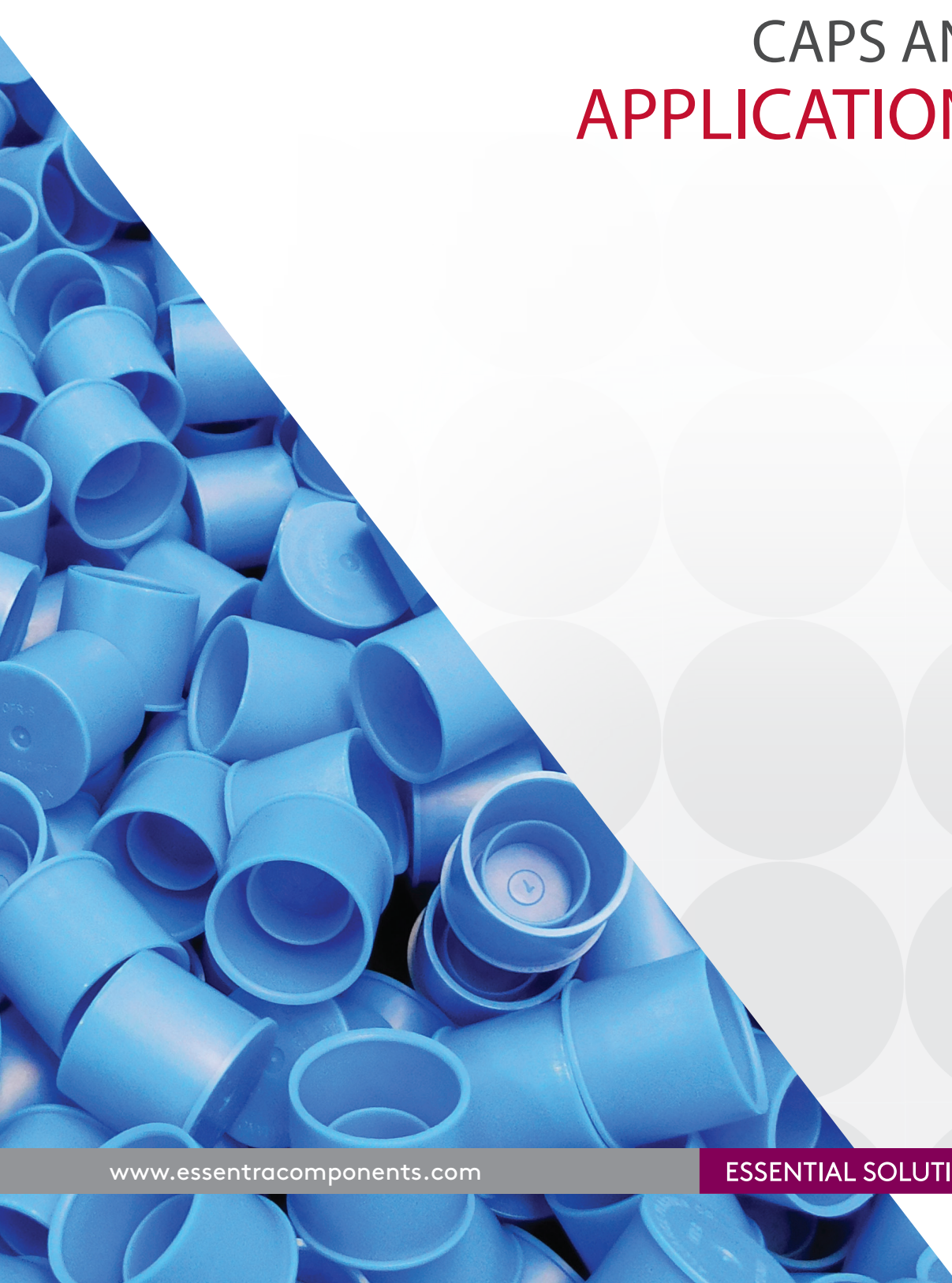

ESSENTRA

CAPS AND PLUGS APPLICATION GUIDE



A new name, making the
same great products

formerly

ALLIANCE

www.essentracomponents.com

ESSENTIAL SOLUTIONS

DELIVERED

PRODUCT PROTECTION YOU CAN TRUST



Choosing the right cap or plug to protect your application can be challenging. Our caps & plugs application guide provides an easy way to choose the perfect solution by thread or hole size. Start by determining whether you need a cap or a plug, identify your application's thread or hole size, then use the charts to select the Essentra product that will work best for you. Our application guide will provide multiple solutions for your needs, so if you're not sure which one will work best, request free samples today to ensure proper fit and function.

To further aid in your cap and plug selection process, check out our 5 Top Tips for choosing the perfect cap or plug located on page 3.

WHO IS ESSENTRA

We are a global manufacturer and distributor of vital component parts for

**HUNDREDS OF MARKETS
AND THOUSANDS OF
PRODUCTS.**




CONTENTS


CAPS

5	PUSH FIT CAPS	
6	CAPS FOR NPT THREADS	
7	PUSH FIT CAPS FOR UNIFIED THREADS	
8	THREADED CAPS FOR UNIFIED THREADS	
9	CAPS FOR METRIC THREADS	

PLUGS

11-12	PUSH FIT PLUGS	
13	PLUGS FOR NPT THREADS	
15-16	PUSH FIT PLUGS FOR UNIFIED THREADS	
17-18	THREADED PLUGS FOR UNIFIED THREADS	
19-20	PLUGS FOR METRIC THREADS	

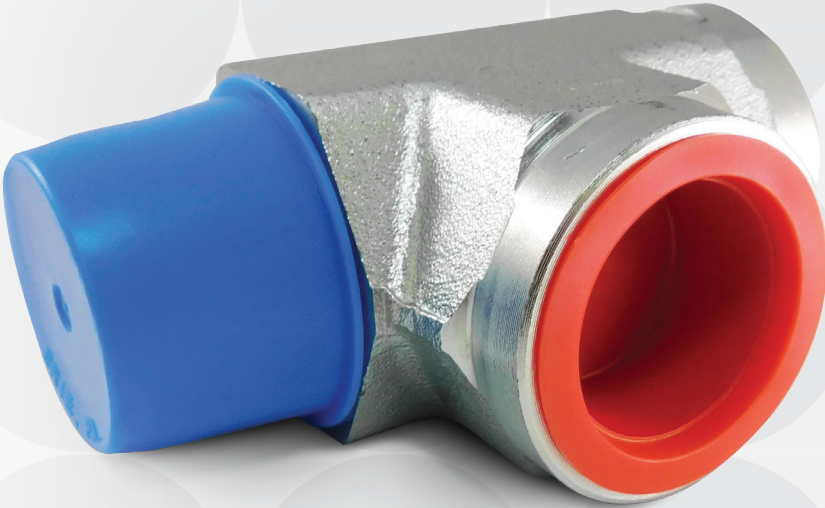

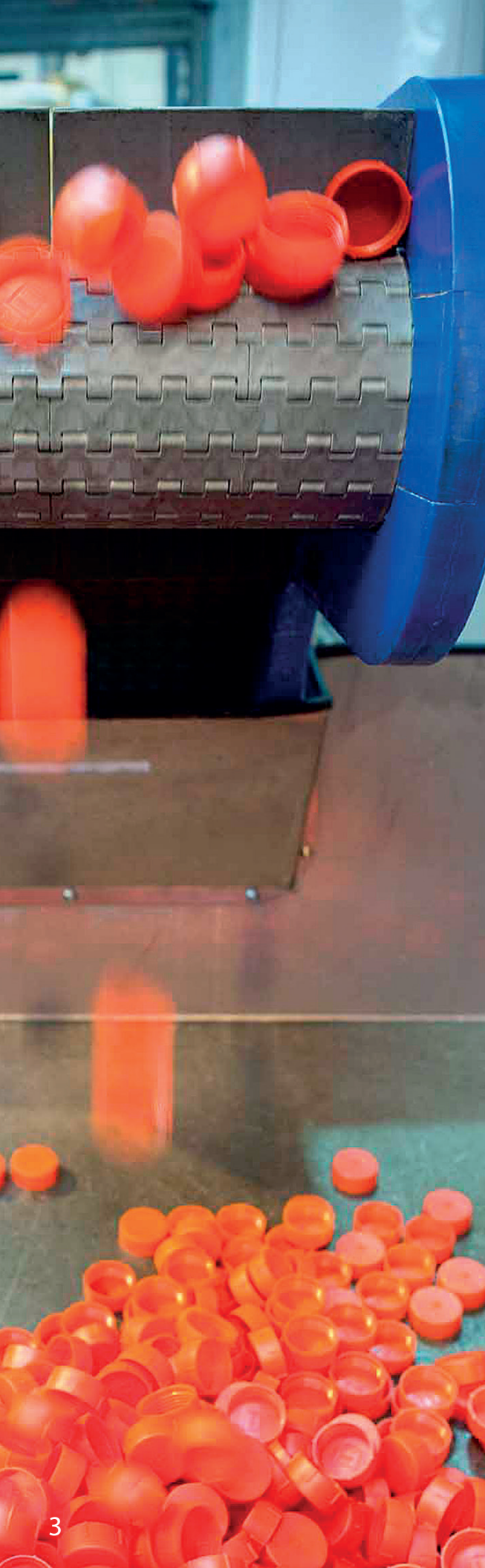

5 TOP TIPS

FOR CHOOSING THE PERFECT CAP OR PLUG

1 CONSIDER YOUR ENVIRONMENT

There are various environmental factors to consider when protecting your application:

- CONTAMINATION- Are dirt and dust present?
- TEMPERATURE- At what temperature range is your application operating?
- VIBRATION- Is your application exposed to vibration or movement?
- PRESSURE- Are there any type of air or fluid pressure testing requirements?

2 UNDERSTAND YOUR APPLICATION

Working with multiple applications can bring different variables. First, think about whether you need to protect or mask:

- PROTECTION – Consider what part requires protecting and how the cap or plug needs to perform. For example, if you are protecting a profile with an interior thread, you may select a threaded plug or if the application requires shielding against entry or escape of liquids, then an o-ring could be applied.

- MASKING – Consider the surface area and the complexities of the masking process, which can include painting, blasting or high-temperature drying. For example, if you are masking a number of holes in a high-temperature environment, you may select a high-temperature flangeless silicone plug that includes tapered rings to allow a variety of hole diameters to be masked.

3 IDENTIFY THE RIGHT MATERIAL

One of the most critical environmental factors to consider is whether or not your application is exposed to heat. If heat tolerance is required, consider a high temp vinyl, EPDM or silicone cap or plug which can operate safely from 425° F up to 600° F.

Another consideration is whether or not the cap or plug is required to withstand a high impact environment. Softer materials such as PVC and EPDM are more flexible to impact versus LPDE or HDPE.

4 THINK ABOUT YOUR PRODUCTION PROCESS


Understanding your production process allows you to consider how caps and plugs can be applied. These can vary from manual to tool-based processes.

A push fit cap or flanged plug can be applied to fit multiple profiles. This allows for fast hand application, which is essential if you are looking to save time. For tool based processes, a cross head threaded plug can be used.

5 CONSIDER THE REMOVAL PROCESS


Ease and speed of removal might be a factor for your production environment. Protection for threads or profiles must be carefully removed, which may take time. Using a push fit product versus a threaded one can save time on removal, which saves time in your production schedule. To increase ease of removal, consider a cap or plug with an ergonomic pull tab or flange, which can inject speed and efficiency of the removal process.

MATERIAL OPTIONS

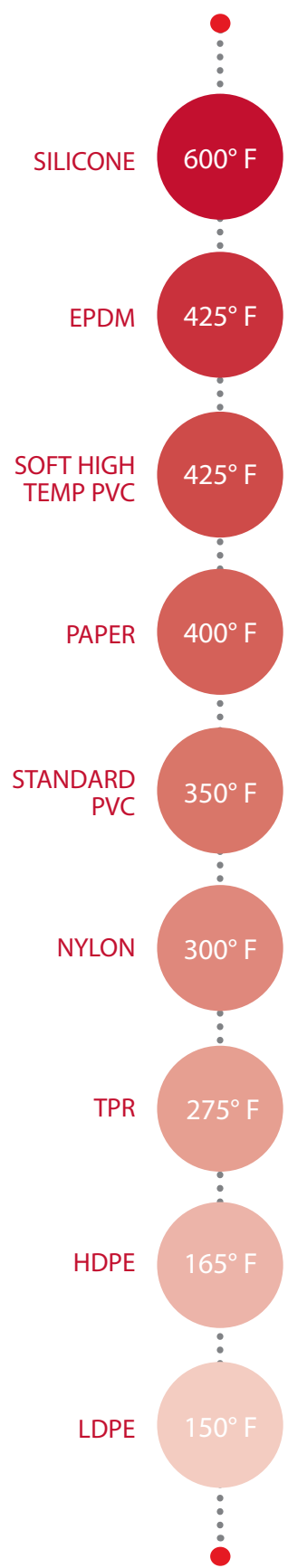

 Material/data contained in this chart is for reference only. Due to the number of variables of your application, we recommend sampling to ensure proper function. Essentra reserves the right to change this information at any time without notification. Please contact your local Essentra facility for more information.
800.847.0486



TO CAP OUTSIDE DIAMETER	GENERAL PROTECTION CAPS						HIGH TEMP MASKING CAPS				MASKING TUBE	
												
	FRACTION	DECIMAL	LDPE	LDPE	PVC VINYL	PVC VINYL	TPR	SILICONE	EPDM	HIGH TEMP PVC	HIGH TEMP PVC	SILICONE
1/8"	.125"	002A	A1/8W/RA	DM0125-1/2A			SC012510A	SC012510C	DM0125-1/2D			ST0125A
3/16"	.187"	005A	A3/16W/RA	DM0187-1/2A	DMPC0180-1/2A	12200B	SC018705A	SC018705B	DM0187-1/2C	DMPC0180-1/2B		ST0187A
1/4"	.250"	007A	A1/4W/RA	DM0250-1/2A	DMPC0240-1/2A	12201B	SC025010A	SC025010C	DM0250-1/2E	DMPC0240-1/2E		ST0250A
5/16"	.312"	009A	A5/16W/RA	DM0313-1/2A	DMPC0302-1/2A	12202B	SC031210A	SC031210C	DM0313-1/2E	DMPC0302-1/2G		ST0312A
3/8"	.375"	011A	A3/8W/RA	DM0375-1/2A	DMPC0365-1/2A	12204B	SC037510A	SC037510B	DM0375-1/2D	DMPC0365-1/2E		ST0375A
7/16"	.437"	014A	A7/16W/RA	DM0437-1/2A	DMPC0427-1/2A	12206B	SC043710A	SC043710B	DM0437-1/2J	DMPC0427-1/2F		ST0437A
1/2"	.500"	1020A	A1/2W/RA	DM0500-1A	DMPC0490-1/2A	12207B	SC050015A	SC050015C	DM0500-1E	DMPC0490-1/2D		ST0500A
9/16"	.562"	020A	A9/16W/RA	DM0562-1A	DMPC0552-1A	12209B	SC056215A	SC056215B	DM0562-1D	DMPC0552-1C		
5/8"	.625"	022A	A5/8W/RA	DM0625-1A	DMPC0615-1A	12210B	SC062515A	SC062515B	DM0625-1F	DMPC0625-1F		ST0625A
11/16"	.687"	026A	A11/16W/RA	DM0687-1A	DMPC0687-1A	12212B	SC068715A	SC068715B	DM0687-1E	DMPC0687-1E		
3/4"	.750"	028A	A3/4W/RA	DM0750-1A	DMPC0740-1A	12214B	SC075015A	SC075015B	DM0750-1F	DMPC0740-1D		ST0750A
13/16"	.812"	031A	A13/16W/RA	DM0812-1A	DMPC0812-1A	12215B	SC081215A	SC081215B	DM0812-1D	DMPC0812-1D		
7/8"	.875"	039A	A7/8W/RA	DM0875-1A	DMPC0865-1A	12217B	SC087515A	SC087515B	DM0875-1E	DMPC0865-1B		ST0875A
15/16"	.937"	040A	A15/16A	DM0937-1A	DMPC0937-1A	12218B	SC093715A	SC093715B	DM0937-1J	DMPC0937-1B		ST0937A
1"	1.000"	041A	A1W/RA	DM1000-1A	DMPC0990-1A	12220B	SC100015A	SC100015B	DM1000-1E	DMPC0990-1B		ST1000A
1-1/16"	1.062"	042A	A1-1/16W/RA	DM1062-1A	DMPC1062-1A	12221B	SC106215A	SC106215B	DM1062-1E	DMPC1060-1D		
1-1/8"	1.125"	1040A	A1-1/8A	DM1125-1A	DMPC1125-1A	12223B	SC112515A	SC112515B	DM1125-1D	DMPC1125-1B		ST1125A
1-3/16"	1.187"	045A	A1-3/16W/RA	DM1187-1A	DMPC1125-1A	12225B	SC118715A	SC118715B	DM1187-1B	DMPC1125-1B		
1-1/4"	1.250"	048A	A1-1/4A	DM1250-1A	DMPC1230-1A		SC125015A	SC125015B	DM1250-1D	DMPC1230-1B		ST1250A
1-5/16"	1.312"	051A	A1-5/16W/RA	DM1312-1A	DMPC1230-1A		SC125015A	SC125015B	DM1312-1B	DMPC1230-1B		
1-3/8"	1.375"	052A	A1-3/8A	DM1375-1A			SC135017A	SC135017B	DM1375-1D			ST1375A
1-7/16"	1.437"	053A	A1-7/16A	DM1437-1A					DM1437-1B			
1-1/2"	1.500"	055A	A1-1/2A	DM1500-1A	DMPC1500-1A		SC150017A	SC150017B	DM1500-1E	DMPC1500-1B		ST1500A
1-9/16"	1.562"	055A	A1-9/16A	DM1500-1A	DMPC1500-1A		SC150017A	SC150017B	DM1500-1E	DMPC1500-1B		
1-5/8"	1.625"	056A	A1-5/8A	DM1625-1A	DMPC1605-1A		SC162520A	SC162520B	DM1625-1H	DMPC1605-1B		ST1625A
1-11/16"	1.687"	057A	A1-11/16A	DM1687-1A	DMPC1605-1A		SC162520A	SC162520B	DM1687-1B	DMPC1605-1B		
1-3/4"	1.750"	059A	A1-3/4A	DM1750-1A			SC175020A	SC175020B	DM1750-1D			ST1750A
1-13/16"	1.812"	060A		DM1812-1A			SC175020A	SC175020B	DM1812-1B			
1-7/8"	1.875"	062A	A1-7/8A	DM1875-1A			SC187520A	SC187520B	DM1875-1D			ST1875A
1-15/16"	1.937"	063A		DM1937-1A			SC187520A	SC187520B	DM1937-1B			
2"	2.000"	065A	A2A	DM2000-1A			SC200020A	SC200020B	DM2000-1E			ST2000A
2-1/16"	2.062"	061A		DM2000-1A					DM2000-1E			
2-1/8"	2.125"	063A	A2-1/8A	DM2125-1A					DM2125-1B			
2-3/16"	2.187"	066A		DM2156-1A					DM2156-1B			
2-1/4"	2.250"	067A	A2-1/4A	DM2250-1A					DM2250-1C			
2-5/16"	2.312"	069A										
2-3/8"	2.375"	069A	A2-3/8A	DM2375-1A					DM2375-1C			
2-7/16"	2.437"	071A		DM2460-1A					DM2460-1B			
2-1/2"	2.500"	073A	A2-1/2A	DM2500-1A					DM2500-1B			
2-9/16"	2.562"	073A	A2-19/32W/RA									
2-5/8"	2.625"	074A	A2-5/8A	DM2625-1A					DM2625-1B			
2-11/16"	2.687"	076A		DM2687-1A					DM2687-1B			
2-3/4"	2.750"	078A	A2-3/4A	DM2750-1A					DM2750-1B			
2-13/16"	2.812"	080A										
2-7/8"	2.875"	081A		DM2875-1A					DM2875-1B			
2-15/16"	2.937"	082A										
3"	3.000"	083A	A3A	DM3000-1A					DM3000-1D			

PUSH FIT CAPS

HIGH TEMP MASKING CAPS

TO CAP NPT									
THREADS	LDPE	LDPE	PVC VINYL	LDPE	LDPE	SILICONE	EPDM	HIGH TEMP PVC	PAPER
1/16" X 27		008A	DM0304-1/2A					DM0304-1/2B	
1/8" x 27	RRC1/8A	012A	DM0375-1/2A	Y1/8A	ECS0125A	SC037510A	SC037510B	DM0375-1/2D	EFTC035040A
1/4" x 18	RRC1/4A	018A	DM0500-1/2A	Y1/4A	ECS0250A	SC050015A	SC050015B	DM0500-1/2F	EFTC047049A
3/8" x 18	RRC3/8A	026A	DM0625-1/2A	Y3/8A	ECS0375A	SC062515A	SC062515B	DM0625-1/2E	EFTC065065A
1/2" x 14	RRC1/2A	035A	DM0843-1A	Y1/2A	ECS0500A			DM0843-1B	EFTC078083A
3/4" X 14	RRC3/4A	042A	DM1000-1A	Y3/4A	ECS0750A	SC100015A	SC100015B	DM1000-1E	EFTC095108A
1" x 11-1/2	RRC1A	052A	DM1250-1A	Y1A	ECS1000A	SC125015A	SC125015B	DM1250-1D	EFTC126127A
1-1/4" x 11-1/2	RRC1-1/4A	056A	DM1875-1A	Y1-1/4A	ECS1250A	SC187520A	SC187520B	DM1875-1D	EFTC162169A
1-1/2" x 11-1/2	RRC1-1/2A	1080A	DM2375-1A	Y1-1/2A	ECS1500A			DM2375-1C	EFTC183189A
2" x 11-1/2	RRC2A	071A	DM2750-1A	Y2A	ECS2000A			DM2750-1B	EFTC233234A
2-1/2" - 8	RRC2-1/2A	082A	DM2875-1A					DM2875-1B	EFTC283285A
3" - 8	RRC3A	GPT689A	DM3500-1A					DM3500-1B	EFTC332363A
3-1/2" - 8	RRC3-1/2A	093A	DM4000-1A					DM4000-1B	
4" - 8	RRC4A	095A	DM4500-1A					DM4500-1B	
5" - 8	RRC5A	102A	DM5500-1A					DM5500-1B	
6" - 8	RRC6A	108A	DM6500-1A					DM6500-1B	

WHY DO I NEED TO USE CAPS & PLUGS?

Eliminates dirt, dust and moisture from contaminating your application

Prevent costly rejected product by protecting them with caps and plugs

Protect vital components from damage during harsh finishing processes and shipment

WE HAVE
THOUSANDS
 OF PRODUCTS AVAILABLE TO
 SAMPLE FOR FREE

www.essentracomponents.com

email | sales@essentracomponents.com web | www.essentracomponents.com

GENERAL PROTECTION CAPS

HIGH TEMP MASKING CAPS

TO CAP	GENERAL PROTECTION CAPS					HIGH TEMP MASKING CAPS		
UNIFIED THREAD SIZE	LDPE	LDPE	PVC VINYL	LDPE	EVA	SILICONE	EPDM	HIGH TEMP PVC
1/4"					FPT464887A	SC023405A	SC023405B	DM0234-1/2D
5/16"	008A		DM0304-1/2A			SC028110A	SC028110B	DM0304-1/2B
3/8"	011A	E3/8A	DM0360-1/2A	TS3A	FPT464888A	SC035515A	SC035515B	DM0360-1/2B
7/16"	013A	E7/16A	DM0437-1/2A	TS4A	FPT464890A	SC040610A	SC040610B	DM0437-1/2J
1/2"	017A	E1/2A	DM0490-1/2A	TS5A	FPT464892A	SC048015A	SC048015B	DM0490-1/2B
9/16"	020A	E9/16A	DM0544-1/2A	TS6A	FPT464893A	SC053515A	SC053515B	DM0544-1/2B
5/8"	021A	E5/8A	DM0600-1A	TS10348A	FPT464895A	SC060015A	SC060015C	DM0600-1B
11/16"	026A	E11/16B	DM0665-1A	TS7A	FPT464896A	SC068715A	SC068715B	DM0665-1B
3/4"	028A	E3/4A	DM0725-1A	TS8A	FPT464897A	SC073015A	SC073015B	DM0725-1B
13/16"	030A	E13/16A	DM0750-1A	TS9A	FPT464898A	SC075035A	SC075035B	DM0750-1F
7/8"	035A	E7/8A	DM0843-1A	TS10A	FPT464898A	SC078015A	SC078015B	DM0843-1B
1"	041A	E1A	DM0985-1A	TS11A	FPT464900A	SC097015A	SC097015B	DM0985-1B
1-1/16"-12	042A	E1-1/16A	DM1000-1A	TS12A		SC100015A	SC100015B	DM1000-1E
1-3/16"-12	1040A	E1-3/16B	DM1125-1A	TS13A		SC112515A	SC112515B	DM1125-1D
1-5/16"-12	049A	E1-5/16B	DM1250-1A	TS16A		SC118715A	SC118715B	DM1250-1D
1-7/16"-12	053A	E1-7/16B	DM1375-1A	TS17A		SC135017A	SC135017B	DM1375-1D
1-5/8"-12	056A	E1-5/8B	DM1593-1A	TS20A		SC150017A	SC150017B	DM1593-1B
1-11/16"-12	056A	E1-11/16B	DM1625-1A	TS21A		SC162520A	SC162520B	DM1625-1H
1-7/8"-12	062A	E1-7/8B	DM1875-1A	TS24A		SC187520A	SC187520B	DM1875-1D
2-1/4"-12	072A		DM2156-1A			SC200020A	SC200020B	DM2156-1A

ADVANTAGES OF PVC

FLEXIBLE

Provides a snug fit and can stretch over larger diameters without tearing

HEAT TOLERANT

Standard PVC withstands up to 350° F and High Temp PVC up to 425° F

DURABILITY

Higher resistance to impact

AESTHETICS

Its glossy finish is ideal to be used as decorative end caps or plugs

CLEAN REMOVAL

Won't leave behind shreds of material on threaded studs

CUSTOMIZABLE

Don't see the color or length that you're looking for?

[REQUEST A CUSTOM QUOTE](#)
SALES@ESSETRACOMPONENTS.COM

THREADED CAPS FOR UNIFIED THREADS

NON-SEALING CAPS

SEALING CAPS



TO CAP

UNIFIED THREAD SIZE	LDPE	LDPE	HDPE	HDPE
1/4"-28 UNF				TSC467054A
3/8"-24 UNF	G1A	10251A		TSC467055A
3/8"-28 UNJ			DC3A	
7/16"-20 UNF	G2A	10332A		TSC467057A
7/16"-24 UNS	G3A	12652A	DC4A	TSC467056A
1/2"-20 UNF	G4A,G5A,G7A,	10528A		TSC467058A
1/2"-24 UNJ			DC5A	
9/16"-18 UNF	G8A	11041A		TSC467059A
9/16"-20 UNJ			DC6A	
5/8"-18 UNF	G9A,G11A,G12A	10653A		TSC467060A
5/8"-24 UNEF	G13A			
23/32"-20 UNJ			DC8A	
3/4"-16 UNF	G14A	12847A		TSC467061A
3/4"-18 UNS	G15A			
3/4"-20 UNEF	G16A			
13/16"-16 UN		12825A		TSC467062A
27/32"-18 UNJ			DC10A	
7/8"-14 UNF	G17A,G18A	11089A		TSC467064A
7/8"-18 UNS	G19A,G20A	12075A		TSC467063A
1"-14 UNS'	G21A	12826A		TSC467065A
1"-16 UNJ			DC12A	
1-1/8"-16 UNJ			DC14A	
1-1/16"-12 UN	G22A	10685A		TSC467066A
1-1/16"-14 UN	G23A			
1-1/16"-16 UN	G24A			
1-3/16"-12 UN	G25A	10163A		TSC467067A
1-1/4"-14 UNJ			DC16A	
1-1/4"-18 UNEF	G26A			
1-5/16"-12 UN	G27A	10151A		TSC467068A
1-3/8"-12 UNF		12654A		TSC467069A
1-7/16"-12 UN		10185A		TSC467070A
1-33/64"-14 UNJ			DC20A	
1-37/64"-14 UNJ			DC215A	
1-5/8"-12 UN	G30A	11053A		TSC467071A
1-3/4"-16 UN				TSC467072A
1-25/32"-14 UNJ			DC24A	
1-27/32"-14 UNJ			DC255A	
1-7/8"-12 UN		11804A		TSC467073A

OVER
65,000
PRODUCTS ONLINE!

WWW.ESSENTRACOMPONENTS.COM

CAPS FOR METRIC THREADS

GENERAL PROTECTION CAPS								HIGH TEMP MASKING CAPS		NON-SEALING CAPS	SEALING CAPS
TO CAP											
METRIC THREAD SIZE	LDPE	LDPE	PVC VINYL	SILICONE	EPDM	HIGH TEMP PVC	HIGH TEMP PVC	LDPE	HDPE		
M4 X 0.7	002A		DM0148-1/2A	SC015605A	SC015605B	DM0148-1/2B					
M5 X 0.8	004A	A3/16W/RA	DM0203-1/2A	SC018710A	SC018710B	DM0203-1/2C	DMPC0180-1/2B				
M6 X 1	005A		DM0230-1/2A	SC022310A	SC022310B	DM0230-1/2B					
M8 X 1.25	009A		DM0304-1/2A	SC029505A	SC029505B	DM0304-1/2B					
M8 X 1	009A	A5/16W/RA	DM0304-1/2A	SC029505A	SC029505B	DM0304-1/2B		12100A	TSC467033A		
M10 X 1.25	010A		DM0375-1/2A	SC037510A	SC037510B	DM0375-1/2D	DMPC0365-1G				
M10 X 1	010A	AR100A	DM0375-1/2A	SC037510A	SC037510B	DM0375-1/2D	DMPC0365-1G	12101A	TSC467034A		
M10 X 0.75	010A		DM0375-1/2A	SC037510A	SC037510B	DM0375-1/2D	DMPC0365-1G				
M12 X 1.75	014A	A1/2BA	DM0460-1/2A	SC045615A	SC045615B	DM0460-1/2B					
M12 X 1.5	014A	A1/2BA	DM0460-1/2A	SC045615A	SC045615B	DM0460-1/2B		12103A	TSC467036A		
M12 X1.25	014A	A1/2BA	DM0460-1/2A	SC045615A	SC045615B	DM0460-1/2B					
M12 X 1	014A	A1/2BA	DM0460-1/2A	SC045615A	SC045615B	DM0460-1/2B		12102A	TSC467035A		
M14 X 2	016A		DM0531-1A	SC053515A	SC053515B	DM0531-1C					
M14 X 1.5	016A		DM0531-1A	SC053515A	SC053515B	DM0531-1C		12104A	TSC467037A		
M15 X 1	018A		DM0587-1A	SC056215A	SC056215B	DM0587-1B	DMPC0552-1C				
M16 X2	020A	A5/8W/RA	DM0600-1A	SC060015A	SC060015C	DM0600-1B					
M16 X 1.5	020A	A5/8W/RA	DM0625-1A	SC060015A	SC060015C	DM0625-1F		12105A	TSC467038A		
M17 X 1	022A		DM0640-1A	SC062515A	SC062515B	DM0640-1B	DMPC0625-1E				
M18 X 1.5	023A	A11/16W/RA	DM0687-1A	SC068715A	SC068715B	DM0687-1E	DMPC0687-1E	12106A	TSC467039A		
M20 X 2.5	028A	AR125A	DM0750-1A	SC075015A	SC075015B	DM0750-1F	DMPC0740-1D				
M20 X 1.5	028A	AR125A	DM0750-1A	SC075015A	SC075015B	DM0750-1F	DMPC0740-1D	12107A	TSC467040A		
M20 X 1	028A	AR125A	DM0750-1A	SC075015A	SC075015B	DM0750-1F	DMPC0740-1D				
M22 X 2.5	029A	AR130A	DM0843-1A	SC081215A	SC081215B	DM0843-1B					
M22 X 1.5	029A	AR130A	DM0843-1A	SC081215A	SC081215B	DM0843-1B		12108A	TSC467041A		
M24 x 1.5	035A	A15/16A	DM0937-1A				DMPC0937-1B	12109A	TSC467042A		
M24 X 2	035A	A15/16A	DM0937-1A	SC093715A	SC093715B	DM0937-1J	DMPC0937-1B				
M25 X 1.5	039A	A63/64A	DM0937-1A	SC097015A	SC097015B	DM0937-1J	DMPC0937-1B	12110A	TSC467043A		
M26 x 1.5	041A	A1W/RA	DM1000-1A	SC100015A	SC100015B	DM1125-1D	DMPC0990-1B	12111A	TSC467044A		
M27 X 2	044A	A1-1/16W/RA	DM1125-1A	SC100015A	SC100015B	DM1125-1D	DMPC0990-1B				
M28 x 1.5	044A		DM1125-1A	SC112515A	SC112515B	DM1125-1D	DMPC1125-1B	12967A	TSC467045A		
M30 X 2	044A		DM1125-1A	SC112515A	SC112515B	DM1125-1D	DMPC1125-1B	12122A	TSC467047A		
M30 x 1.5	044A		DM1125-1A	SC112515A	SC112515B	DM1125-1D	DMPC1125-1B		TSC467046A		
M35 X 1.5	048A	A1-3/8A	DM1375-1A	SC135017A	SC135017B	DM1375-1D					
M36 x 1.5	049A		DM1437-1A	SC135017A	SC135017B	DM1375-1D		12123A	TSC467048A		
M36 x 2	049A		DM1437-1A	SC135017A	SC135017B	DM1375-1D			TSC467049A		
M39 X 2	055A	A1-1/2A	DM1500-1A	SC150017A	SC150017B	DM1500-1E	DMPC1500-1B				
M42 X 2	056A	A1-5/8A	DM1625-1A	SC162520A	SC162520B	DM1625-1H	DMPC1605-1B	12124A	TSC467050A		
M45 X 1.5	1065A	A1-3/4A	DM1750-1A	SC175020A	SC175020B	DM1750-1D			TSC467051A		
M45 x 2	1065A		DM1812-1A						TSC467052A		
M48 X 2	058A	A1-7/8A	DM1875-1A	SC187520A	SC187520B	DM1875-1D					
M52 x 2	063A	A2A	DM2000-1A			DM2000-1E		12126A	TSC467053A		

FREE
CAD

SAME
DAY
SHIPPING

FREE
SAMPLES

LOCAL
STOCK

EASY
ORDERING

DO I NEED A CAP OR A PLUG?

Caps fit snugly on the outside of a component to protect external threaded and non-threaded ends

Plugs grip the inside of a component to protect internal threads or holes

Both protect against dirt and dust from entering your component



TRY BEFORE YOU BUY!

FREE SAMPLES & CAD

WWW.ESENTRACOMPONENTS.COM

GENERAL PROTECTION



TO PLUG HOLE

FRACTION	DECIMAL	LDPE	LDPE	LDPE	PVC VINYL	LDPE	LDPE	LDPE	PVC	TPR
1/8"	.125"	001A				BP1006A			10874A	18071B
3/16"	.187"	1000A	LF2A		GPV53A	BP1012A			12665A	12049B
1/4"	.250"	003A	LF3A			BP1018A	CP4A		12667A	12051B
5/16"	.312"	006A	LF5A	GP607A	GPV101B	BP1020A	CP6A	P7A	12668A	12052B
3/8"	.375"	008A	LF6A	GP610A	GPV101B	BP1030A	CP8A	P8A	12670A	12054B
7/16"	.437"	010A	LF7A		GPV102B	BP1038A	CP10A	P11A	12671A	12055B
1/2"	.500"	012A	LF9A	GP617A	GPV62A	BP1044A	CP12A	P13A	12673A	12057B
9/16"	.562"	015A	LF11A		GPV64B	BP1052A	CP15B	P16A	12674A	12058B
5/8"	.625"	017A	LF11XA		GPV66B	BP1060A	CP16A	P17A	12677A	12060B
11/16"	.687"	021A	LF13XA	GP628A	GPV68B	BP1064A	CP19A	P20A	12679A	12062B
3/4"	.750"	022A	LF15A	GP628A	GPV104B	BP1072A	CP23A	P23A	12681A	12064B
13/16"	.812"	026A	LF16A	GP632A	GPV72B	BP1080A	CP24A	P26A	12683A	12065B
7/8"	.875"	028A	LF17A	K1838A	GPV74B	BP1086A	CP29A	P26A	12684A	FLP21A
15/16"	.937"	030A	LF18A		GPV105B	BP1092A	CP31A	P31A	12686A	12068B
1"	1.000"	035A	LF19A		GPV78A	BP1100A	CP35A	P33A,P40A	12688A	12070B
1-1/16"	1.062"	040A	LF20A			BP1104A	CP37A	P40A	12689A	12071B
1-1/8"	1.125"	041A		GP642A		BP1110A	CP40A	P41A	12691A	12073B
1-3/16"	1.187"	042A				BP1112A	CP42A	P42A	12692A	FLP30A
1-1/4"	1.250"	044A	LF21A	GP648A		BP1114A	CP44A	P44A		
1-5/16"	1.312"	045A	LF22A	GP648A		BP1118A	CP46A	P46A		
1-3/8"	1.375"	1055A	LF23XA	GP650A		BP1124A	CP49A			
1-7/16"	1.437"	049A	LF23XA	GP652A		BP1126A	CP49A			
1-1/2"	1.500"	051A	LF24A	GP654A		BP1130A	CP51A	P53A		
1-9/16"	1.562"	052A	LF24A	GP656A		BP1134A	CP55A	P53A	12963A	12501B
1-5/8"	1.625"	055A		GP658A		BP1136A	CP56A	P55A		
1-11/16"	1.687"	056A	LF26A	GP662A		BP1138A	CP56A	P57A		
1-3/4"	1.750"	1065A	LF26A	GP662A		BP1140A		P57A		
1-13/16"	1.812"	057A	LF28A	GP664A		BP1140A		P59A	12694A	12502B
1-7/8"	1.875"	058A	LF28A	GP666A			CP57A	P61A		
1-15/16"	1.937"	060A	LF30A	GP670A		BP1142A	CP57A	P61A		
2"	2.000"	061A	LF32A	GP672A		BP1144A		P65A		
2-1/16"	2.062"	062A	LF34A	GP674A		BP1146A		P65A		
2-1/8"	2.125"	063A	LF34A	GP676A		BP1148A	CP61A			
2-3/16"	2.187"	066A	LF36A			BP1150A	CP61A			
2-1/4"	2.250"	067A	LF36A			BP1152A	CP63A	P68A		
2-5/16"	2.312"	069A	LF36A			BP1154A	CP65A			
2-3/8"	2.375"	070A	LF36A				CP65A			
2-7/16"	2.437"	071A					CP65A			
2-1/2"	2.500"	073A	LF38A							
2-9/16"	2.562"	074A	LF38A							
2-5/8"	2.625"	077A								
2-11/16"	2.687"	076A								
2-3/4"	2.750"	078A				BP1156A				
2-13/16"	2.812"	080A								
2-7/8"	2.875"	082A				BP1158A				
2-15/16"	2.937"	081A								
3"	3.000"	083A								

DID YOU KNOW?

Looking for a cap or plug resistant to oils and acids? Choose one made from a TPR material.

HIGH TEMP MASKING PLUGS

TO PLUG HOLE										
FRACTION	DECIMAL	SILICONE	EPDM	SILICONE	EPDM	SILICONE	EPDM	PAPER	SILICONE	EPDM
1/8"	.125"	STP006018A	STP006018C			SPP0130A	SPP0130B		SCON250130A	SCON250130B
3/16"	.187"	STP006020A	STP006020D	SFP157236A	SFP157236B	SPP0195A	SPP0195B		SCON250130A	SCON250130B
1/4"	.250"	STP001027A	STP001027B	SFP236315A	SFP236315B	SPP0257A	SPP0257B		SCON316216A	SCON316216B
5/16"	.312"	STP018034A	STP018034D	SFP236315A	SFP236315B	SPP0332A	SPP0332B		SCON316216A	SCON316216B
3/8"	.375"	STP025043A	STP025043C	SFP315394A	SFP315394C	SPP0388A	SPP0388B	EFTP035042A	SCON394197B	SCON394197A
7/16"	.437"	STP035047A	STP035047B	SFP394472A	SFP394472C	SPP0440A	SPP0440B	EFTP037047A	SCON551315A	SCON551315C
1/2"	.500"	STP039059A	STP039059B	SFP472551A	SFP472551B	SPP0510A	SPP0510B	EFTP047057A	SCON551315A	SCON551315C
9/16"	.562"	STP039059A	STP039059B	SFP551630A	SFP551630C	SPP0612A	SPP0612B	EFTP052064A	SCON689453C	SCON689453A
5/8"	.625"	STP051067A	STP051067B	SFP415641A	SFP415641B	SPP0640A	SPP0640B	EFTP058070A	SCON689453C	SCON689453A
11/16"	.687"	STP055075A	STP055075D	SFP630709A	SFP630709C	SPP0700A	SPP0700C	EFTP058070A	SCON689453C	SCON689453A
3/4"	.750"	STP062078A	STP062078D	SFP709787A	SFP709787C	SPP0770A	SPP0770C	EFTP065078A	SCON767532A	SCON767532B
13/16"	.812"	STP071094A	STP071094C	SFP641868A	SFP641868B	SPP0896A	SPP0896B	EFTP068082A		
7/8"	.875"	STP071094A	STP071094C	SFP787886A	SFP787886B	SPP0896A	SPP0896B	EFTP078088A		
15/16"	.937"	STP062094A	STP062094B	SFP886945A	SFP886945C	SPP1020A	SPP1020B	EFTP086095A		
1"	1.000"	STP078102A	STP078102B	SFP9541024A	SFP9541024B	SPP1020A	SPP1020B	EFTP092111A		
1-1/16"	1.062"	STP094110A	STP094110C	SFP8681094A	SFP8681094B	SPP1380A	SPP1380B	EFTP092111A		
1-1/8"	1.125"	STP109118A	STP109118B	SFP10941320A	SFP10941320B	SPP1380A	SPP1380B	EFTP100124A		
1-3/16"	1.187"	STP102126A	STP102126B	SFP10941320A	SFP10941320B	SPP1380A	SPP1380B	EFTP100124A		
1-1/4"	1.250"	STP102126A	STP102126B	SFP10941320A	SFP10941320B	SPP1380A	SPP1380B	EFTP118144A		
1-5/16"	1.312"	STP106134A	STP106134B	SFP10941320A	SFP10941320B	SPP1380A	SPP1380B	EFTP118144A		
1-3/8"	1.375"	STP118145A	STP118145B	SFP13201547A	SFP13201547B	SPP1380A	SPP1380B	EFTP118144A		
1-7/16"	1.437"	STP118145A	STP118145B	SFP13201547A	SFP13201547B			EFTP118144A		
1-1/2"	1.500"	STP122153A	STP122153B	SFP13201547A	SFP13201547B			EFTP136160A		
1-9/16"	1.562"	STP130161A	STP130161B	SFP15471774A	SFP15471774B			EFTP136160A		
1-5/8"	1.625"	STP141169A	STP141169C	SFP15471774A	SFP15471774B			EFTP150178A		
1-11/16"	1.687"	STP145177A	STP145177C	SFP15471774A	SFP15471774B			EFTP150178A		
1-3/4"	1.750"	STP145177A	STP145177C	SFP15471774A	SFP15471774B			EFTP150178A		
1-13/16"	1.812"	STP165196A	STP165196B	SFP17742000A	SFP17742000B			EFTP173206A		
1-7/8"	1.875"	STP165196A	STP165196B	SFP17742000A	SFP17742000B			EFTP173206A		
1-15/16"	1.937"	STP165196A	STP165196B	SFP17742000A	SFP17742000B			EFTP173206A		
2"	2.000"	STP177208A	STP177208B	SFP17742000A	SFP17742000B			EFTP173206A		
2-1/16"	2.062"	STP177208A	STP177208B					EFTP188221A		
2-1/8"	2.125"	STP189220A	STP189220C					EFTP188221A		
2-3/16"	2.187"	STP189220A	STP189220C					EFTP188221A		
2-1/4"	2.250"	STP196248A	STP196248B					EFTP198230A		
2-5/16"	2.312"	STP196248A	STP196248B					EFTP222250A		
2-3/8"	2.375"	STP196248A	STP196248B					EFTP222250A		
2-7/16"	2.437"	STP212252A	STP212252B					EFTP222250A		
2-1/2"	2.500"	STP212252A	STP212252B					EFTP222250A		
2-9/16"	2.562"	STP228267A	STP228267B							
2-5/8"	2.625"	STP228267A	STP228267B							
2-11/16"	2.687"	STP244295A	STP244295B					EFTP264315A		
2-3/4"	2.750"	STP244295A	STP244295B					EFTP264315A		
2-13/16"	2.812"	STP244295A	STP244295B					EFTP264315A		
2-7/8"	2.875"	STP244295A	STP244295B					EFTP264315A		
2-15/16"	2.937"	STP244295A	STP244295B					EFTP264315A		
3"	3.000"	STP295354A	STP295354B					EFTP264315A		

PUSH FIT PLUGS

HIGH TEMP MASKING PLUGS

TO FIT NPT								
THREADED HOLE	LDPE	LDPE	LDPE	LDPE	SILICONE	EPDM	SILICONE	EPDM
1/8" x 27	008A	BP1024A	CP8A	I3/8A	STP025037A	STP025037D	SFP315394A	SFP315394C
1/4" x 18	012A	EN1/4A	CP11A	I1/2A	STP031050A	STP031050C	SFP472551A	SFP472551B
3/8" x 18	NPT3/8A	EN3/8A		I5/8A	STP043062A	STP043062D	SFP551630A	SFP551630C
1/2" x 14	024A	EN1/2A	CP23A	I13/16A	STP062078A	STP062078D	SFP709787A	SFP709787C
3/4" X 14	NPT3/4A	EN3/4A	CP35A	I1A	STP078102A	STP078102B	SFP9541024A	SFP9541024B
1" x 11-1/2	044A	EN1A	CP44A	I1-5/16A	STP102126A	STP102126B	SFP10941320A	SFP10941320B
1-1/4" x 11-1/2	NPT1-1/4A	BP1134A	CP55A		STP130161A	STP130161B	SFP15471774A	SFP15471774B
1-1/2" x 11-1/2	1065A	BP1140A	CP57A		STP149181A	STP149181C	SFP17742000A	SFP17742000B
2" x 11-1/2	NPT2A	BP1152A			STP196248A	STP196248B		
2-1/2" - 8	NPT2-1/2A	BP1156A			STP244295A	STP244295B		
3" - 8	NPT3A	BP1162A			STP295354A	STP295354B		
3-1/2" - 8	NPT3-1/2A	BP1166A			STP326405A	STP326405B		
4" - 8	NPT4A	BP1168A			STP354500A	STP354500B		
5" - 8	NPT5A							
6" - 8	NPT6A							

NON-SEALING THREADED PLUGS

SEALING THREADED PLUGS

TO FIT NPT								
THREADED HOLE	HDPE	HDPE	HDPE	ACETATE	GLASS FILLED NYLON	NYLON	HDPE	NYLON
1/8" x 27	R1/8A	PFP1/8A		PS40B	R1/8C	PFP1/8B	PFP1/8C	PFP1/8D
1/4" x 18	R1/4A	PFP1/4A	PT1/4A		R1/4C	PFP1/4B	PFP1/4C	PFP1/4D
3/8" x 18	R3/8A	PFP3/8A	PT3/8A	PS131B	R3/8B	PFP3/8B	PFP3/8C	PFP3/8D
1/2" x 14	R1/2A	PFP1/2A	PT1/2A	PS132B	R1/2D	PFP1/2B	PFP1/2C	PFP1/2D
3/4" X 14	R3/4A	PFP3/4A	PT3/4A	PS44B	R3/4B	PFP3/4B	PFP3/4C	PFP3/4D
1" x 11-1/2	R1A	PFP1A	PT1A	PS134B	R1B	PFP1B	PFP1C	PFP1D
1-1/4" x 11-1/2	R1-1/4A			PS135A	R1-1/4C			
1-1/2" x 11-1/2	R1-1/2A			PS48B	R1-1/2C			
2" x 11-1/2	R2A							

IT'S SIMPLE,

▶ JUST SAMPLE! ◀

WWW.ESSENTRACOMPONENTS.COM

IF OUR STANDARD PRODUCTS DON'T
MEET YOUR NEEDS...

REQUEST A QUOTE ON A CUSTOM SOLUTION

From concept to production,
we've got you covered.

- In house Engineers
- Rapid 3D prototyping
- Color changes



For orders, no-obligation quotes or
information about our products:



Tel: 800-847-0486



Email: sales@essentracomponents.com



Web: www.essentracomponents.com

GENERAL PROTECTION PLUGS



TO PLUG	LDPE	LDPE	LDPE	LDPE	LDPE
UNIFIED THREAD SIZE					
1/4"	002A	CP4A			
5/16"	005A	CP5A		EZP1010A	
3/8"	007A	CP7A	UN9995A	EZP1010A	
7/16"	008A	CP8A	UN9996A	EZP1020C	10530A
1/2"	010A	CP10A		EZP1030A	12363A
9/16"	013A	CP14A	UN9997A	EZP1030A	
5/8"	014A	CP15B		EZP1030A	12364A
11/16"	018A	CP18A			
3/4"	021A	CP19A	UN9763A	EZP1040A	10314B
13/16"	023A	CP23A			
7/8"	026A	CP24A		EZP1050A	12366A
15/16"	028A	CP29A			
1"	030A	CP31A	UN9764A		
1-1/8"	039A	CP35A		EZP1060A	
1-1/16"	035A	CP35A		EZP1060A	12367A
1-3/16"	041A	CP40A	UN9774A		
1-1/4"	042A	CP42A		EZP1070A	
1-5/16"	044A	CP44A		EZP1070A	12369A
1-3/8"	045A	CP46A		EZP1070A	12622A
1-7/16"	1055A	CP47A	UN9765A		12622A
1-1/2"	049A	CP49A			12622A
1-9/16"	051A	CP51A			
1-5/8"	052A	CP55A			12598A
1-11/16"	053A	CP55A			
1-3/4"	056A	CP56A			
1-13/16"	056A	CP56A			
1-7/8"	1065A	CP57A			
1-15/16"	057A	CP57A			
2"	058A	CP57A			
2-1/16"	060A				
2-1/8"	061A				
2-3/16"	063A	CP61A			
2-1/4"	066A	CP61A			
2-5/16"	066A	CP63A			
2-3/8"	067A	CP65A			
2-7/16"	069A	CP65A			
2-1/2"	071A	CP65A			

TAPERED CAPS & PLUGS

Tapered design allows these
to cap or plug multiple
diameters



HIGH TEMP MASKING PLUGS



TO PLUG				
UNIFIED THREAD SIZE	SILICONE	EPDM	SILICONE	EPDM
1/4"	STP012025-10A	STP012025-10C	SFP236315A	SFP236315D
5/16"	STP018034A	STP018034D	SFP236315A	SFP236315D
3/8"	STP025037A	STP025037D	SFP315394A	SFP315394C
7/16"	STP025043A	STP025043C	SFP394472A	SFP394472C
1/2"	STP035047A	STP035047B	SFP472551A	SFP472551B
9/16"	STP039059A	STP039059B	SFP472551A	SFP472551B
5/8"	STP043062A	STP043062D	SFP551630A	SFP551630C
11/16"	STP051067A	STP051067E	SFP630709A	SFP630709C
3/4"	STP055075A	STP055075D	SFP709787A	SFP709787C
13/16"	STP062078A	STP062078D	SFP709787A	SFP709787C
7/8"	STP062094A	STP062094B	SFP787886A	SFP787886B
15/16"	STP075094A	STP075094C	SFP886945A	SFP886945C
1"	STP078102A	STP078102B	SFP9541024A	SFP9541024B
1-1/8"	STP109118A	STP109118B	SFP11251250A	SFP11251250B
1-1/16"	STP090106A	STP090106C	SFP8681094A	SFP8681094B
1-3/16"	STP102126A	STP102126B	SFP10941320A	SFP10941320B
1-1/4"	STP102126A	STP102126B	SFP10941320A	SFP10941320B
1-5/16"	STP106134A	STP106134B	SFP10941320A	SFP10941320B
1-3/8"	STP106134A	STP106134B	SFP10941320A	SFP10941320B
1-7/16"	STP118145A	STP118145B		
1-1/2"	STP118145A	STP118145B	SFP13201547A	SFP13201547B
1-9/16"	STP122153A	STP122153B	SFP13201547A	SFP13201547B
1-5/8"	STP130161A	STP130161B	SFP13201547A	SFP13201547B
1-11/16"	STP141169A	STP141169C	SFP15471774A	SFP15471774B
1-3/4"	STP145177A	STP145177C	SFP15471774A	SFP15471774B
1-13/16"	STP149181A	STP149181C	SFP15471774A	SFP15471774B
1-7/8"	STP149181A	STP149181C	SFP17742000A	SFP17742000B
1-15/16"	STP165196A	STP165196B	SFP17742000A	SFP17742000B
2"	STP165196A	STP165196B	SFP17742000A	SFP17742000B
2-1/16"	STP177208A	STP177208B	SFP17742000A	SFP17742000B
2-1/8"	STP177208A	STP177208B		
2-3/16"	STP189220A	STP189220C		
2-1/4"	STP189220A	STP189220C		
2-5/16"	STP196248A	STP196248B		
2-3/8"	STP196248A	STP196248B		
2-7/16"	STP196248A	STP196248B		
2-1/2"	STP196248A	STP196248B		

CALL TODAY TO FIND THE ESSENTRA
SOLUTION THAT IS RIGHT FOR YOU

► +1 800.847.0486 ◀

NON-SEALING PLUGS

TO FIT THREADED HOLE	        								
	LDPE	HDPE	POLYPROPYLENE	LDPE	HDPE	HDPE	POLYPROPYLENE	NYLON	ACETATE
5/16"-18 UNC	10498A								
5/16"-24 UNF	10709A								
3/8"-24 UNF	10692A								MP70B
7/16"-20 UNF	10763A	B3A	BL3A		TMO104A	BLM3B	FP104A	BL3D	MP73B
7/16"-24 UNS	12031A					BLM3-24B			
1/2"-13 UNC			BL4A						MP531B
1/2"-20 UNF	10696A	B4A			TMO105A	BLM4B			MP76B
9/16"-18 UNF	10668A	B5A	BL5A	TF10A	TMO106A	BLM5B	FP108A	BL5C	MP78B
9/16"-24 UNEF	12033A								
5/8"-18 UNF	10940A	B6A				BLM6B	FP110A		
5/8"-24 UNEF	12965A								
11/16"-16 UN	12786A			TF20A					
3/4"-16 UNF	10575A	B7A	BL7A		TMO108A	BLM7B	FP115A	BL7C	MP81B
13/16"-16 UN	12827A			TF30A					
7/8"-14 UNF	10326A	B8A	BL8A		TMO110A	BLM8B	FP120A	BL8B	
7/8"-18 UNS									MP90B
1"-14 UNS'	12785A	B9A		TF40A		BLM9B	FP122A		
1-1/8"-12 UNF									MP95B
1-1/16"-12 UN	10460A	B11A	BL10A		TMO112A	BLM10B		BL10C	
1-1/16"-14 UN	12359A	B10A							
1-3/16"-12 UN	11506A		BL11A	TF50A		BLM11B		BL11E	
1-5/16"-12 UN	10671A		BL12A		TMO116A	BLM12B		BL12B	
1-7/16"-12 UN				TF60A					
1-5/8"-12 UN	11752A		BL13A		TMO120A	BLM13B		BL13G	
1-7/8"-12 UN	11755A		BL14A			BLM14B			
2-1/2"-12 UN	12040A								

SEALING PLUGS

TO FIT THREADED HOLE	     					
	POLYPROPYLENE	HDPE	NYLON	NYLON	NYLON	POLYPROPYLENE
3/8"-24 UNF		498672	TSSP3/8-24A			
7/16"-20 UNF	BL3L	498673	TSSP7/16-20A	BL3I	BLWF100A	FP104B
1/2"-13 UNC	BL4B					
1/2"-20 UNF		498674	TSSP1/2-20A		BLWF105A	
9/16"-18 UNF	BL5K	498675	TSSP9/16-18A	BL5N	BLWF110A	FP108B
5/8"-18 UNF		498552	TSSP5/8-18A			FP110B
3/4"-16 UNF	BL7J	498676	TSSP3/4-16A	BL7G	BLWF115A	FP115B
7/8"-14 UNF	BL8H	498677	TSSP7/8-14A	BL8P	BLWF120A	FP120B
1"-14 UNS'		498553	TSSP1-14A			FP122B
1-1/16"-12 UN	BL10I	498554	TSSP1-1/16-12A	BL10M	BLWF125A	
1-3/16"-12 UN	BL11D	498678	TSSP1-3/16-12A	BL11C	BLWF130A	
1-5/16"-12 UN	BL12H	498555	TSSP1-5/16-12A	BL12M	BLWF135A	
1-5/8"-12 UN	BL13D	498679	TSSP1-5/8-12A	BL13C	BLWF140A	
1-7/8"-12 UN	BL14C	498680	TSSP1-7/8-12A		BLWF145A	

ADVANTAGES OF THREADED CAPS & PLUGS

SEALING

Optional o-rings provide a seal that can withstand low pressure tests

SECURE FIT


Good for applications that are exposed to vibration or movement as they thread tightly into place

PROTECTION

Against damage of integral threads

LOOKING FOR A QUICK FIT?

Try one of our easy to install caps & plugs for threaded applications

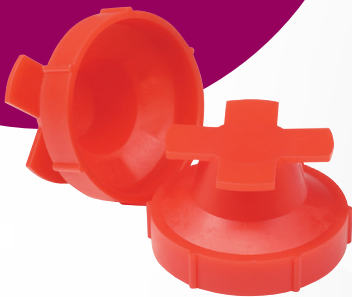

Securing blades make this plug unique as they lock tightly when pushed into a threaded hole and twisted into place.



Caps with rolled threads allow you to push on for fast & easy installation, while still providing a secure fit.



With fewer thread forms, this cap allows for a quicker installation, as the time it takes to thread on is significantly reduced.

GENERAL PROTECTION PLUGS



TO PLUG							
METRIC THREAD SIZE	LDPE	LDPE	TPR	LDPE	LDPE	LDPE	LDPE
M6 x 1	002A	BP1012A	MPP3A				
M8 x 1	005A	BP1018A	MPP4A			EZP1010A	
M10 x 1	007A	BP1026A	MPP10A		UN9996A	EZP1020C	10530A
M10 x 1.5	007A	BP1026A	MPP15A		UN9996A	EZP1020C	
M12 x 1	010A	BP1038A	MPP20A		UN9998A	EZP1020C	12363A
M12 x 1.5	009A	BP1034A	MPP25A		UN9998A	EZP1020C	12363A
M14 x 1.5	012A	BP1044A	MPP30A	QFP105A	UN9997A	EZP1030A	12363A
M16 x 1.5	015A	BP1056A	MPP40A	QFP110A	UN9763A	EZP1030A	12364A
M18 x 1.5	018A	BP1060A	MPP50A		UN9763A	EZP1040A	10314B
M20 x 1.5	022A	BP1068A	MPP60A	QFP115A	UN9763A	EZP1040A	12365A
M22 x 1.5	026A	BP1074A	MPP70A		UN9764A	EZP1050A	12366A
M24 x 1.5	028A	BP1086A	MPP80A		UN9764A	EZP1050A	12621A
M25 x 1.5	030A	BP1090A					
M26 x 1.5	030A	BP1092A				EZP1060A	12367A
M27 x 1.5	035A	BP1100A				EZP1060A	
M27 x 2	035A	BP1100A				EZP1060A	
M28 x 1.5	040A	BP1102A				EZP1060A	12368A
M30 x 1.5	041A	BP1106A			UN9774A	EZP1070A	
M30 x 2	041A	BP1106A		QFP120A		EZP1070A	
M32 x 1.5	044A	BP1112A				EZP1070A	12369A
M33 x 2	044A	BP1114A			UN9765A	EZP1070A	
M36 x 1.5	045A	BP1116A			UN9765A	EZP1070A	
M36 x 2	045A	BP1116A		QFP125A	UN9765A	EZP1070A	12622A
M38 x 1.5	048A	BP1126A					
M42 x 2	053A	BP1134A		QFP130A			12598A
M45 x 1.5	056A	BP1138A					
M45 x 2	056A	BP1138A		QFP135A			
M48 x 2	1065A	BP1140A					
M52 x 1.5	061A	BP1142A					
M52 x 2	1080A	BP1142A		QFP140A			

FREE
SAMPLES
& CAD



HIGH TEMP MASKING PLUGS

NON-SEALING THREADED PLUGS

SEALING THREADED PLUGS

TO PLUG										
METRIC THREAD SIZE	SILICONE	EPDM	SILICONE	EPDM	SILICONE	EPDM	LDPE	HDPE	HDPE	NYLON
M4 x .7	STP006020A	STP006020D	SFP157236A	SFP157236B						
M6 x 1	STP012025-10A	STP012025-10C	SFP236315A	SFP236315D	SPFTM6A	SPFTM6B				
M8 x 1	STP018034-10A	STP018034-10C	SFP315394A	SFP315394C	SPFTM8A	SPFTM8B	12011A	12139A	498659	462836A
M10 x 1	STP025037A	STP025037D	SFP394472A	SFP394472C	SPFTM10A	SPFTM10B	12012A	12140A	498660	462837A
M10 x 1.5	STP025037A	STP025037D	SFP394472A	SFP394472C	SPFTM10A	SPFTM10B			498662	TSSPM10X1.5A
M12 x 1	STP031050A	STP031050C	SFP472551A	SFP472551B	SPFTM12A	SPFTM12B	12013A	12141A	498661	TSSPM12X1A
M12 x 1.5	STP031050A	STP031050C	SFP472551A	SFP472551B	SPFTM12A	SPFTM12B	12017A	12144A	498663	462838A
M14 x 1.5	STP031050A	STP031050C	SFP551630A	SFP551630C			12018A	12142A	498664	462839A
M16 x 1.5	STP043062A	STP043062D	SFP630709A	SFP630709C	SPFTM16A	SPFTM16B	12019A	12146A	498540	462840A
M18 x 1.5	STP051067A	STP051067E	SFP709787A	SFP709787C			10458A	12147A	498541	462841A
M20 x 1.5	STP062078A	STP062078D	SFP787886A	SFP787886B	SPFTM20A	SPFTM20B	12020A	12148A	498542	462842A
M22 x 1.5	STP071094A	STP071094C	SFP641868A	SFP641868B			10128A		498665	462843A
M24 x 1.5	STP071094A	STP071094C	SFP9541024A	SFP9541024B			12021A		498543	TSSPM24X1.5A
M25 x 1.5	STP071094A	STP071094C	SFP10241102A	SFP10241102C			12022A			
M26 x 1.5	STP078102A	STP078102B	SFP8681094A	SFP8681094B			12023A		498544	TSSPM26X1.5A
M27 x 1.5	STP078102A	STP078102B	SFP8681094A	SFP8681094B						466977A
M27 x 2	STP078102A	STP078102B	SFP8681094A	SFP8681094B					498668	466985A
M28 x 1.5	STP078102A	STP078102B	SFP10241102A	SFP10241102C						TSSPM28X1.5A
M30 x 1.5	STP109118A	STP109118B	SFP10241102A	SFP10241102C					498546	TSSPM30X1.5A
M30 x 2	STP109118A	STP109118B	SFP10241102A	SFP10241102C					498548	TSSPM30X2A
M32 x 1.5	STP102126A	STP102126B	SFP10941320A	SFP10941320B					498547	TSSPM32X1.5A
M33 x 2	STP102126A	STP102126B	SFP10941320A	SFP10941320B					498549	TSSPM33X2A
M36 x 1.5	STP118145A	STP118145B	SFP10941320A	SFP10941320B					498666	TSSPM36X1.5A
M36 x 2	STP118145A	STP118145B	SFP10941320A	SFP10941320B					498550	TSSPM36X2A
M38 x 1.5	STP122153A	STP122153B	SFP13201547A	SFP13201547B					498667	TSSPM38X1.5A
M42 x 2	STP130161A	STP130161B	SFP1541774A	SFP1541774B					498669	TSSPM42X2A
M45 x 1.5	STP145177A	STP145177C	SFP17742000A	SFP17742000B						TSSPM45X1.5A
M45 x 2	STP145177A	STP145177C	SFP17742000A	SFP17742000B					498551	TSSPM45X2A
M48 x 2	STP165196A	STP165196B	SFP17742000A	SFP17742000B					498670	TSSPM48X2A
M52 x 1.5	STP177208A	STP177208B	SFP17742000A	SFP17742000B			12030A			TSSPM52X1.5A
M52 x 2	STP177208A	STP177208B	SFP17742000A	SFP17742000B					498671	TSSPM52X2A

PULL TABS

Designed with you in mind, our ergonomic pull tabs provide more surface area for a better grip

A better grip allows for a quicker and easier installation and removal process

TRY BEFORE YOU BUY!

Visit Our Website:

- Order Free Samples
- Request a Free Catalog
- Download Free CAD Drawings
- Shop Our Entire Product Range



800-847-0486



sales@essentracomponents.com



www.essentracomponents.com

ESSENTRA DISTRIBUTION LOCATIONS

United States

Chicago, IL

Edison, NJ

Erie, PA

Greensboro, NC

Houston, TX

Largo, FL

Los Angeles, CA

Muskegon, MI

Canada

Oakville, Ontario

Edmonton, Alberta

Brazil

Sao Paulo