

Bundling and Securing

Cable Ties

 

Standard Cable Ties

T18 - T30 Series in Natural and Black

T-Series Cable Ties feature inside serrations to provide a positive hold on wire and cable bundles. The head design guarantees high tensile strength and a low insertion force. The bent tail design allows quick and simple installations by hand. For high-volume applications, tensioning tools are available to ensure consistent and safe installation.

Features and Benefits

- Engineered and manufactured for maximum performance and quality.
- Made from 100% high-quality plastic to ensure efficient recycling.
- Inside serration for a strong grip onto bundles.
- Easy application either manually or with a tensioning tool.
- Bent tail allows for simpler insertion.

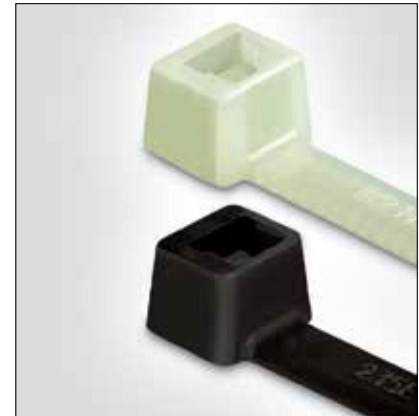

PART NO.	TYPE	Min. Tensile Strength lbs. (N)	Length (L) in. (mm)	Max. Bundle Diameter in. (mm)	Width (W) in. (mm)	Material	Color	Pkg. Qty.
T18I0C2*	T18I	18.0 (80.0)	5.5 (140.0)	1.4 (35.0)	0.1 (2.5)	PA66	Black	100
T18I0M4*		18.0 (80.0)	5.5 (140.0)	1.4 (35.0)	0.1 (2.5)	PA66	Black	1000
T18I9C2*		18.0 (80.0)	5.5 (140.0)	1.4 (35.0)	0.1 (2.5)	PA66	Natural	100
T18I9M4*		18.0 (80.0)	5.5 (140.0)	1.4 (35.0)	0.1 (2.5)	PA66	Natural	1000
T18L0C2*	T18L	18.0 (80.0)	8.0 (205.0)	2.2 (55.0)	0.1 (2.5)	PA66	Black	100
T18L0M4*		18.0 (80.0)	8.0 (205.0)	2.2 (55.0)	0.1 (2.5)	PA66	Black	1000
T18L9C2*		18.0 (80.0)	8.0 (205.0)	2.2 (55.0)	0.1 (2.5)	PA66	Natural	100
T18L9M4*		18.0 (80.0)	8.0 (205.0)	2.2 (55.0)	0.1 (2.5)	PA66	Natural	1000
T18R0C2*	T18R	18.0 (80.0)	4.0 (100.0)	0.9 (22.0)	0.1 (2.5)	PA66	Black	100
T18R0M4*		18.0 (80.0)	4.0 (100.0)	0.9 (22.0)	0.1 (2.5)	PA66	Black	1000
T18R9C2*		18.0 (80.0)	4.0 (100.0)	0.9 (22.0)	0.1 (2.5)	PA66	Natural	100
T18R9M4*		18.0 (80.0)	4.0 (100.0)	0.9 (22.0)	0.1 (2.5)	PA66	Natural	1000
T18S0C2*	T18S	18.0 (80.0)	3.3 (83.0)	0.6 (16.0)	0.1 (2.3)	PA66	Black	100
T18S0M4*		18.0 (80.0)	3.3 (83.0)	0.6 (16.0)	0.1 (2.3)	PA66	Black	1000
T18S9C2*		18.0 (80.0)	3.3 (83.0)	0.6 (16.0)	0.1 (2.3)	PA66	Natural	100
T18S9M4*		18.0 (80.0)	3.3 (83.0)	0.6 (16.0)	0.1 (2.3)	PA66	Natural	1000

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Installation tools: EVO7, EVO7SP, EVO9, EVO9HT, MK7P, MK7HT, MK9P. EVO9 and MK9P cannot be used with T18S cable ties. Military black available. Contact HellermannTyton for more information.

*This product meets UL standards. Please see appendix for specific file numbers.



Please note! Not all products listed on this page may have this approval. Please check our website for latest approvals.