



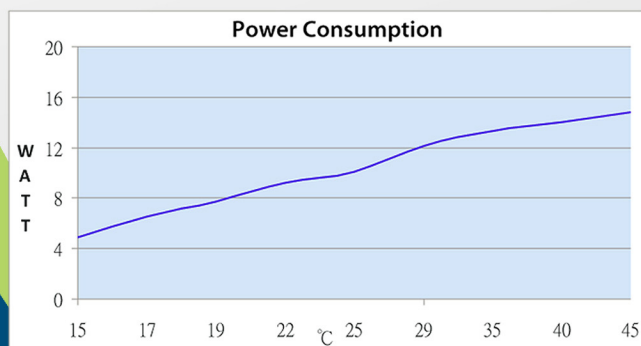

Qualtek has introduced the iQFAN which is a low cost, high reliability, and energy saving AC fan.

The iQFAN can vary its speed based upon ambient temperature changes using a thermal sensor which allows reduced energy consumption, lower noise, and longer life. Energy costs using the iQFAN can be reduced up to 30% compared to a standard AC fan.

All iQFAN's are certified with UL, cUL, TUV, and CE approval agencies to ensure a safe and reliable product.

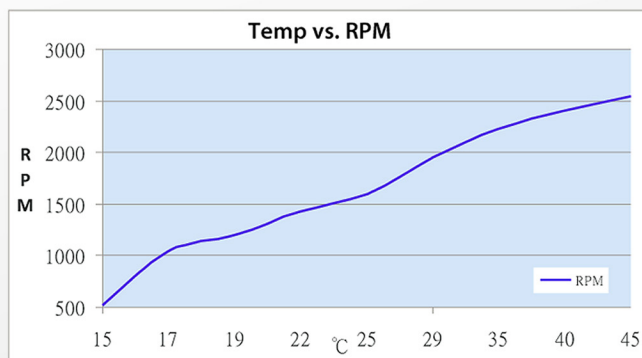

Presented By:

**Qualtek**  
Electronics Corporation



Fan-S Division



# Qualtek

## Electronics Corporation



Fan-S  
Division

As the leader in high quality and low cost fans and fan accessories for over 30 years, Qualtek now offers a full range of high tech, low cost AC and DC axial fans for your thermal management requirements.

Our fans are offered in a large variety of bearing types: 2-Ball, 1 Ball 1 Sleeve, Sleeve and Hydro-Dynamic, with voltages for AC fans from 115 to 230VAC and DC fans from 3.3 to 60VDC.



ALUMINUM FILTERS



PLASTIC RETAINERS



WIRE GUARDS



Qualtek fans range in sizes of 60mm to 280mm for AC and 25mm to 254mm for DC with a large array of functions and special features.

Every fan is available with multiple fan speeds and dual input voltage for AC fans. All fans meet the RoHS requirements and are safety agency certified for the worldwide market.