

## L-com's USB Cable Portfolio, a Solution for every Application


L-com offers the most extensive selection of off the shelf USB cable assemblies to address myriad applications. Our USB cable options include PVC, LSZH, USB 2.0, USB 3.0, USB 3.1, USB 4.0 armored, waterproof, high flex, drag chain, panel mount, angled and more.

### Panel Mount USB Cables


ECF504-12AAL



UPMB5-M

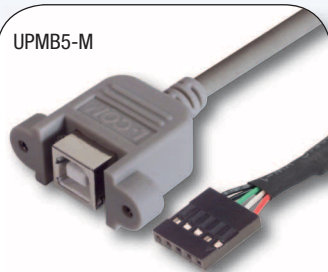

UPMAA-30-M

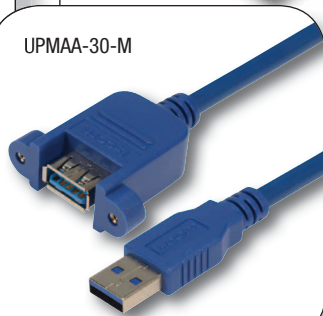


#### Panel Mount USB Cables

- USB 2.0 and USB 3.0 options
- Allows USB cables to be passed through panels or enclosures
- Flying lead and 5-pin housing versions available
- All variations of male/female and Type A/B connectors offered

### High Speed USB Cables

CAU3AB-M

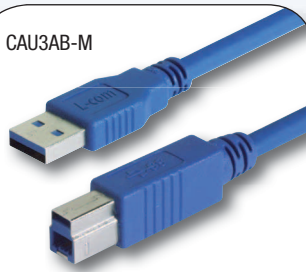

U1A00002-03M



CAU4CC-40MC-1M



#### High Speed USB Cables

- USB 3.2 10gig and USB 4.0 up to 40gig speeds available with C type connectors
- USB 3.0 Type A, B, Micro B and panel mount versions available
- Thumbscrew options for USB3 Vision applications
- Low Smoke Zero Halogen (LSZH) available

### Specialty USB Cable Assemblies

#### Coiled



COILMB5EXT-2M



COILUAB

#### Latching




CAUZALAL-M



U3A00005-05M

#### LSZH

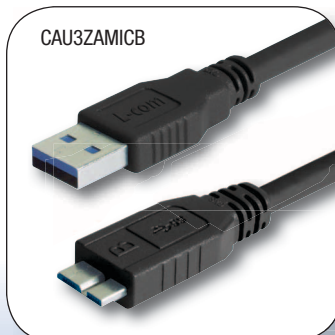

CAU3ZAMICB



CAUZALB-M

#### Waterproof IP67



U3A00021-1M




WPUSBAX

## L-com's USB Cable Portfolio, a Solution for every Application

In addition to thousands of in stock off the shelf USB cable assemblies, L-com can custom manufacture USB cables to your specific requirements. As a leader in the connectivity industry L-com provides the widest selection and highest quality USB cables found anywhere.


### Deluxe USB Cables

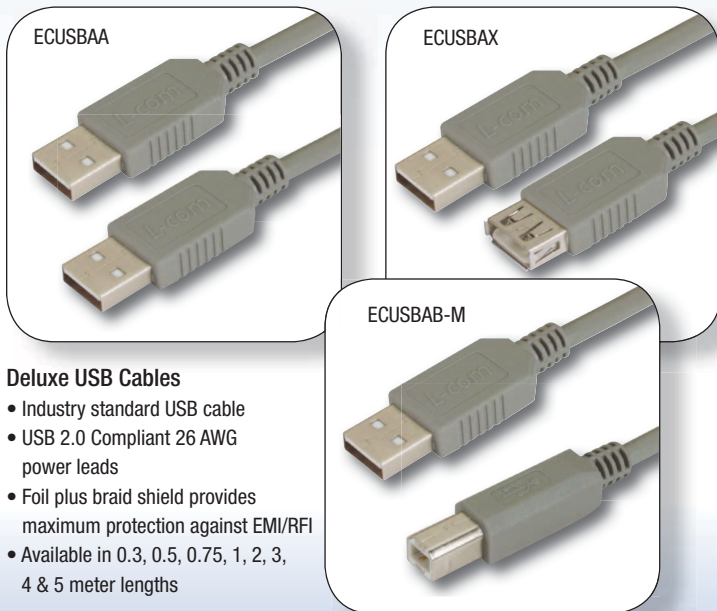

#### Deluxe USB Cables

- Industry standard USB cable
- USB 2.0 Compliant 26 AWG power leads
- Foil plus braid shield provides maximum protection against EMI/RFI
- Available in 0.3, 0.5, 0.75, 1, 2, 3, 4 & 5 meter lengths


### Premium USB Cables

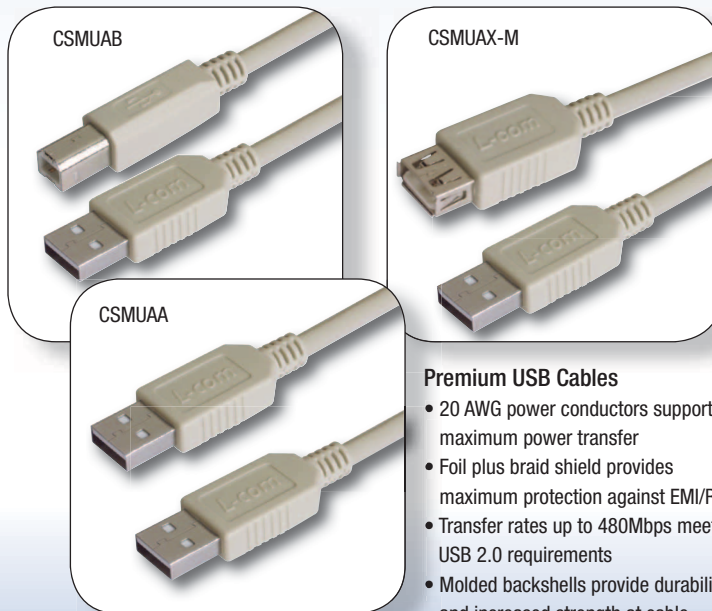

#### Premium USB Cables

- 20 AWG power conductors support maximum power transfer
- Foil plus braid shield provides maximum protection against EMI/RFI
- Transfer rates up to 480Mbps meets USB 2.0 requirements
- Molded backshells provide durability and increased strength at cable entry point


### 45 Degree USB Cables

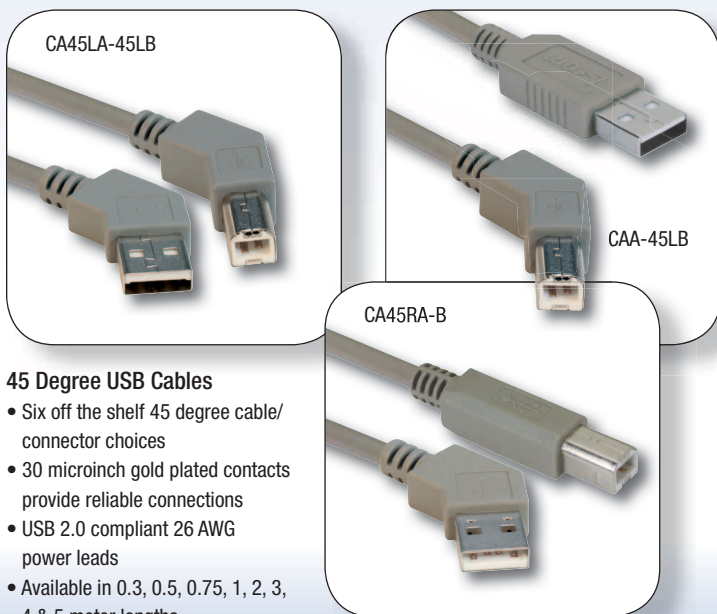

#### 45 Degree USB Cables

- Six off the shelf 45 degree cable/connector choices
- 30 microinch gold plated contacts provide reliable connections
- USB 2.0 compliant 26 AWG power leads
- Available in 0.3, 0.5, 0.75, 1, 2, 3, 4 & 5 meter lengths

### 90 Degree USB Cables

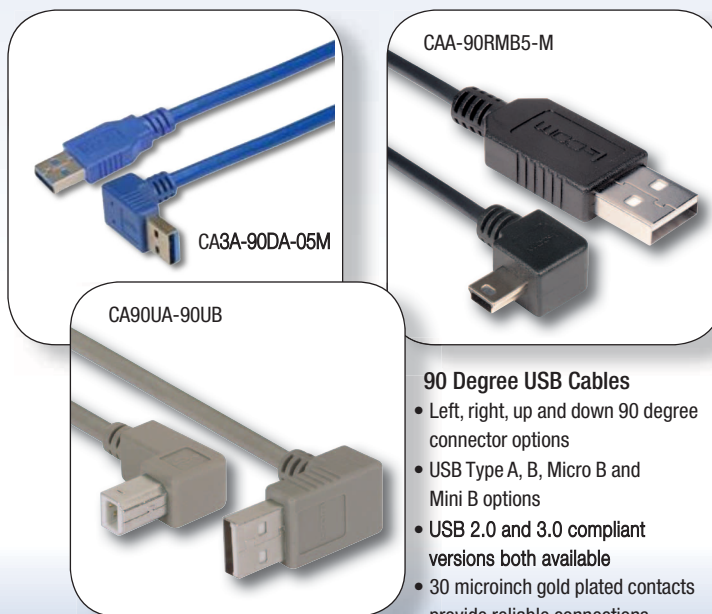

#### 90 Degree USB Cables

- Left, right, up and down 90 degree connector options
- USB Type A, B, Micro B and Mini B options
- USB 2.0 and 3.0 compliant versions both available
- 30 microinch gold plated contacts provide reliable connections