


FLEXIBLE POWER DISCRETE WIRE SOLUTIONS

2.54 mm PITCH MINI MATE® SOLUTIONS

- Cable-to-board, cable-to-cable and cable-to-panel applications
- Available as components with tooling or complete cable assemblies
- Choice of socket and terminal assemblies
- Individually shrouded contacts for electrical and mechanical protection
- Selectively load contacts for creepage and clearance requirements
- Mating terminal strip in vertical, right-angle and elevated right-angle
- Single or double row
- Up to 50 total pins
- 20 to 30 AWG cable options in PVC or Teflon®
- Color coded cables available
- 4.8 A/pin (20 AWG)
- Rugged positive latching for increased retention

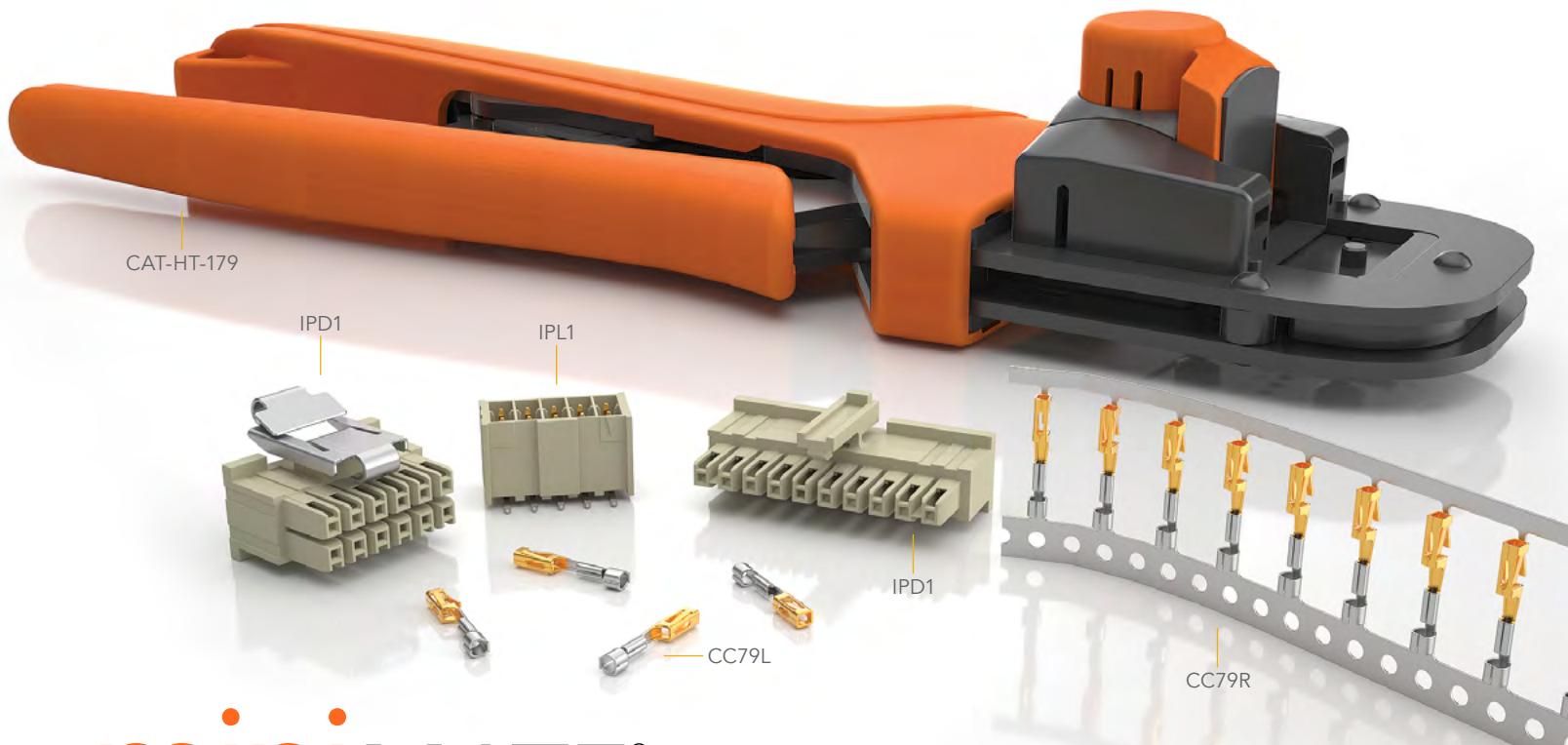

miniMATE®


DuPont™ Teflon® is a registered trademark of E.I. duPont de Nemours and Company or its affiliates.

Applications

• Measuring/Controlling Devices	• Switchgear/Switchboards	• Optical Instruments/Lenses
• Vehicle Lighting Equipment	• Radio/TV Communications Equipment	• Motors/Generators
• Home Audio/Video Equipment	• Refrigeration/Heating Equipment	• Telephone/Telegraph Apparatus
• Surgical and Medical Instruments	• Search/Navigation Equipment	• Whole Computers/Peripherals

To learn more about Samtec's Mini Mate® solutions, please visit mouser.com or samtec.com

2.54 mm PITCH MINI MATE® SOLUTIONS

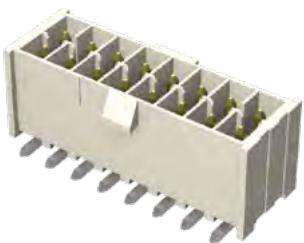

IPL1

Single and Double Row
Terminal Header



IPD1

Single and Double Row
Socket Housing



IPM1

Single and Double Row
Terminal Housing



IPR1

Double Row Panel
Mount Housing



CC79L/CC79R

Contact, Loose Piece
and Full Reel (12K/reel)



T1M74-L/T1M74-R

Terminal, Loose Piece
and Full Reel (15K/reel)

TOOLING SOLUTIONS



Bench Top Mini Applicators

CAT-MC-174-2024-XX-01
CAT-MC-174-2630-XX-01
CAT-MC-179-2024-XX-01
CAT-MC-179-2630-XX-01



Hand Tools


CAT-HT-174-2030-13
CAT-HT-179-2030-13
CAT-EX-74-01
CAT-EX-179-01

CABLE ASSEMBLIES

MMSS(T)/MMSD(T)
- Socket

MMTS(T)/MMTD(T)
- Terminal

MRTD(T)
- Panel Mount Terminal

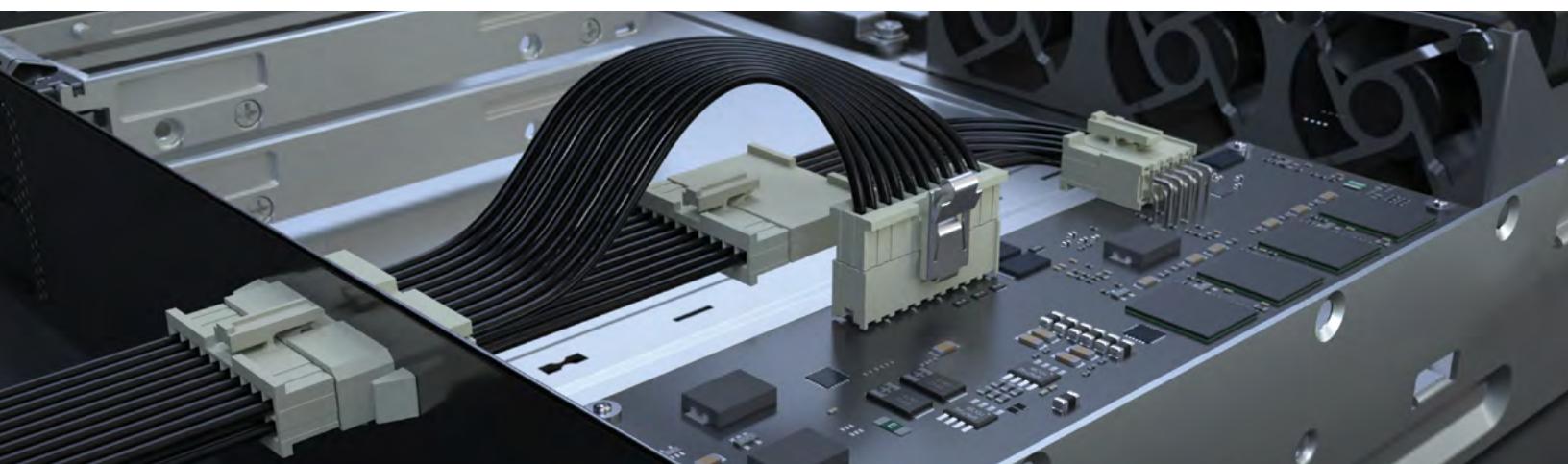

To learn more about Samtec's Mini Mate® solutions, please visit mouser.com or samtec.com