

AUTOMOTIVE CONNECTORS SOLUTIONS




RAYDIALL
AUTOMOTIVE

Cable Connectors – PCB connectors – Electric Vehicle Solutions

www.raydiall.com


RAYDIALL WORLDWIDE

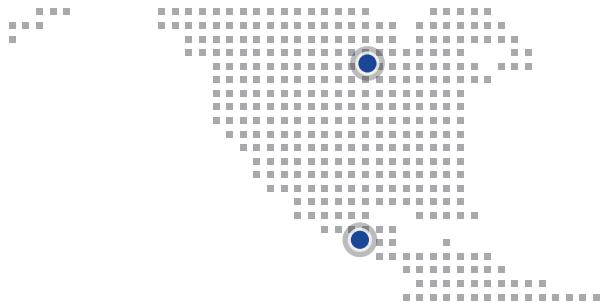

■ EUROPE

France - Headquarters & manufacturing

Raydiall SAS
30 rue Léon Béridot
38500 Voiron
France

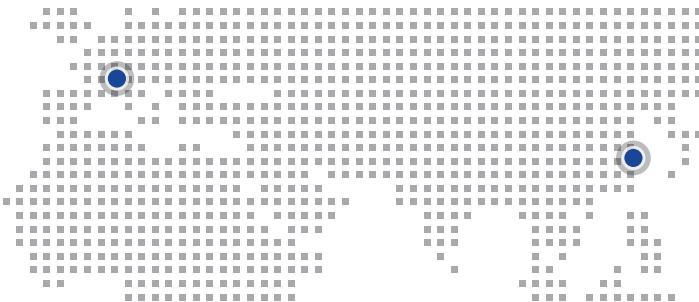


■ AMERICA

USA - Sales & R&D

Raydiall Inc.
3091 Research Drive
Rochester Hills, MI 48309
United States

Mexico - Manufacturing

Bd Circunvalacion 1087
Parque Industrial, 85060 Cd Obregón, Son.
Mexico

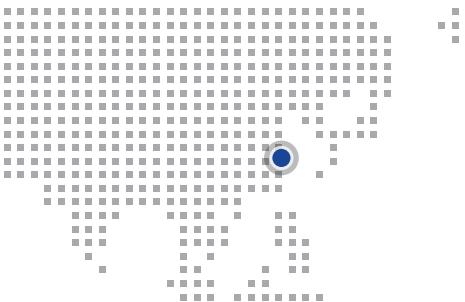

■ ASIA

China - Sales, R&D & Manufacturing

Raydiall Automotive
Interconnections Solutions, Co. Ltd.
19 Wei Si Road - Ding Mao New Area
Jiang Su
212009 Zhenjiang
China



OUR VALUES

Agility
Creativity
Team spirit
Commitment

Raydiall is a joint venture between ARaymond, **a world leader in the automotive fastening industry**, and Radiall, **a world leader in interconnection solutions**.

We combine **our strengths and experience to give better**, more reliable connectivity solutions to our automotive customers.

High-speed data connectors, lightweight PCB connectors, low-insertion force power contacts and one step crimp RF cable connectors are a few examples of product innovations recently developed.



OUR FUNDAMENTALS



Collaboration

We work closely with your engineers to understand your applications, your technical needs, and your budgetary issues.



Global Presence

We're everywhere you need us, with worldwide sales, manufacturing and engineering support.



Wide Product Range

We manage our product lines through the entire lifecycle in order to offer you a wide selection of standard products at an affordable cost.



Responsive Support and Service

From the design stage to planning and post-installation support, we're with you at every step, whether you need sales support or engineering expertise.




Custom Products

We can tailor products to specific equipments and applications.




Warranty

We proudly stand behind our products.
ISO 14001 certified
ISO 16949 : 2009 certified

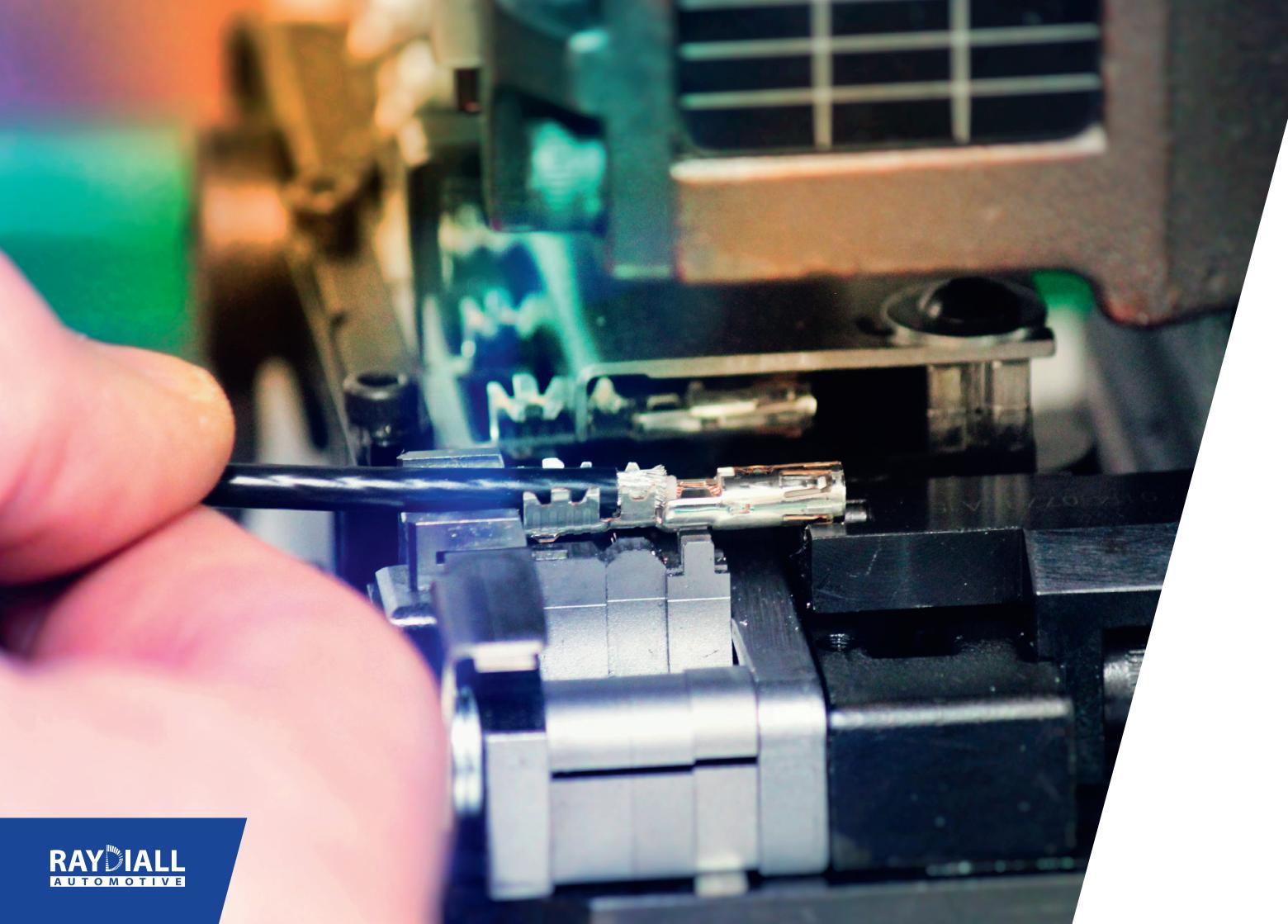


UNIQUE 1 STEP CRIMPING PROCESS

**A solution that requires low investment, and that is compatible with all kind of processes:
Manual, Semi-automatic and Full-automatic processes.**

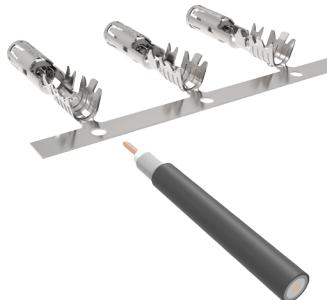

Terminal are delivered
pre-assembled:
The center contact is
already assembled

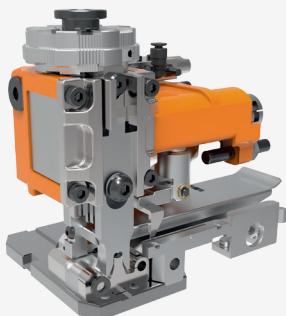

1 step crimping with
mini applicator



Cable, braid and center
contact are crimped
at once.

APPLICATIONS


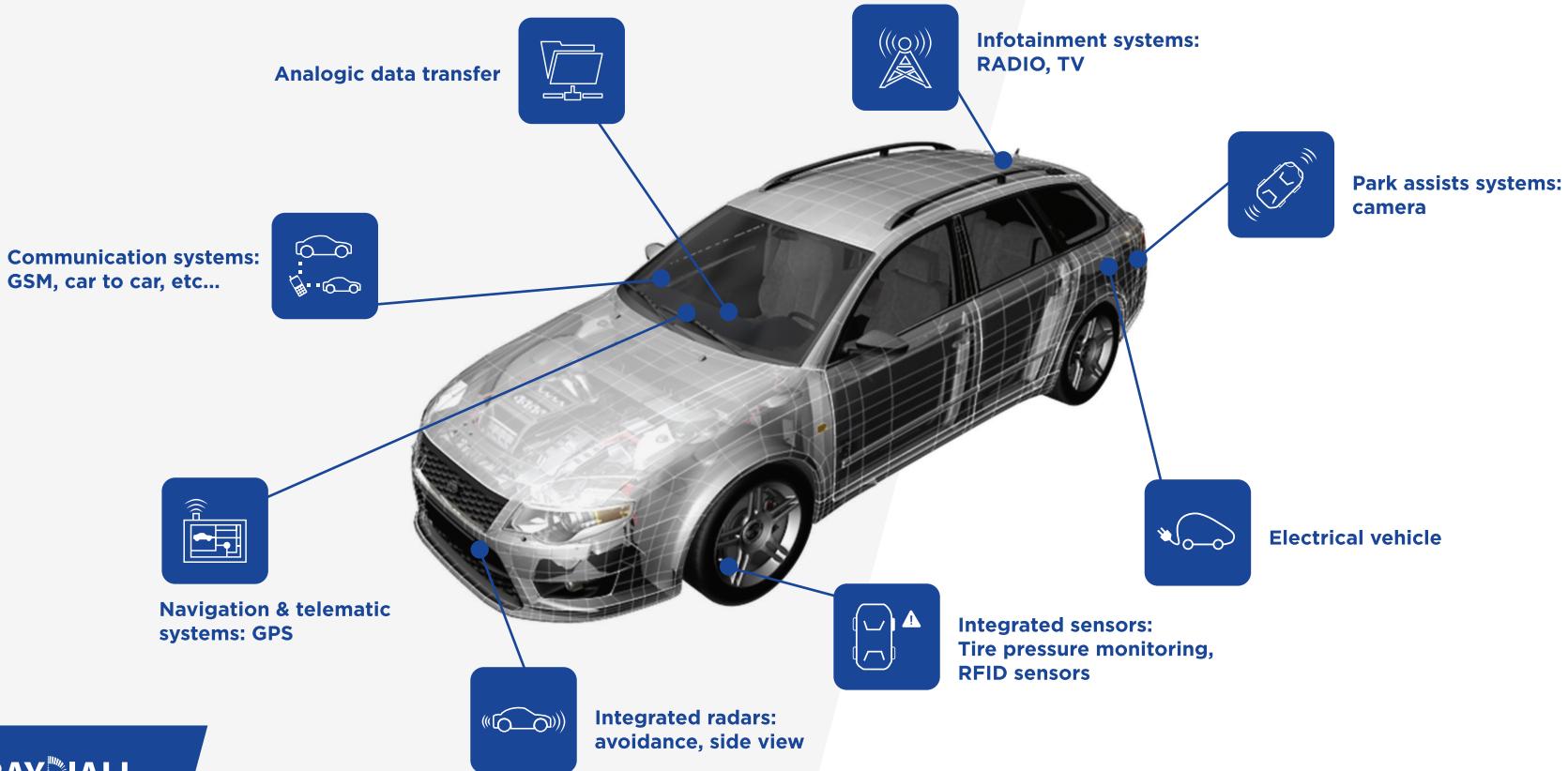


TABLE OF CONTENTS

| | | | | | |
|-----------------------------|---|--|--|---|---|
| FAKRA FOR CABLE |  p12 |  p14 |  p16 |  p18 |  p20 |
| FAKRA FOR PCB |  p24 |  p26 |  p28 | | |
| HSD FOR PCB |  p32 |  p34 | | | |
| ELECTRIC VEHICLE |  p38 |  p40 | | | |



FAKRA CABLE CONNECTORS

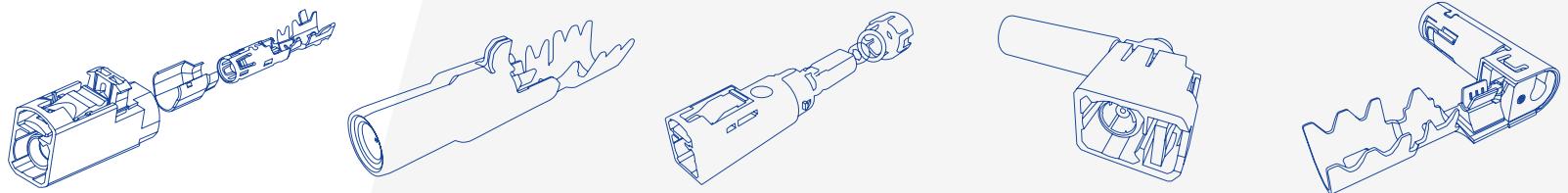

HFR3C

- **Qualification**.....ISO 20860
- **Frequency**.....Up to 6 GHz*
- **Technology**.....Stamped & rolled
- **Cable types**.....RG174, RTK


■ **Packaging**

- Terminal: reel
- Housing: bulk

■ **Product alternative**


- Machined Fakra II

*Performance according to OEM specific requirements
and cable types

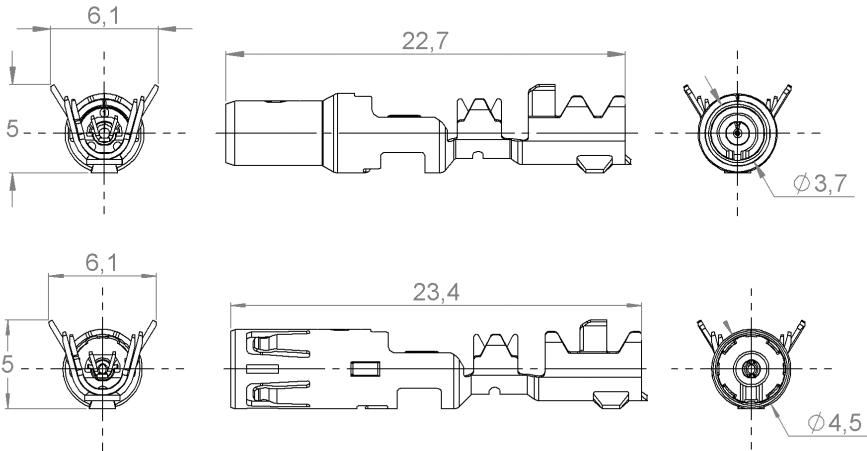

FEATURES :

- 2 step crimping terminal: terminal + crimp sleeve
- Monolithic TPA / Housing
- Closed entry: robust & protected interface design

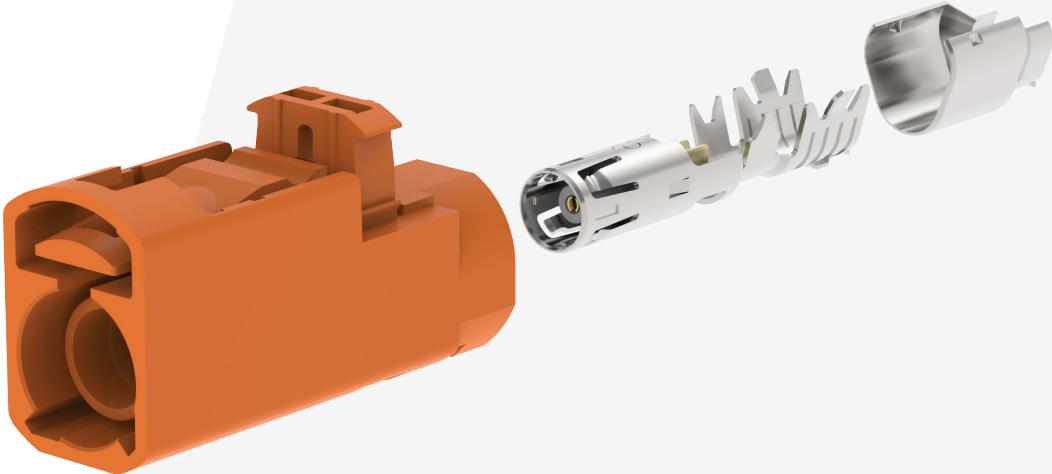

| | Cable type | Terminal + Crimp sleeve | Simplex housing | Duplex housing |
|--------|------------|-----------------------------|-----------------|----------------|
| Female | RG174 | R299.197.300 + R280.197.100 | R197.116._80 | R197.216._80 |
| | RTK | R299.197.310 + R280.197.100 | | |
| Male | RG174 | R299.197.100 + R280.197.100 | R197.136._80 | R197.236._80 |
| | RTK | R299.197.110 + R280.197.100 | | |

- **Qualification**.....USCAR
- **Frequency**.....Up to 3 GHz
- **Technology**.....Stamped & rolled
- **Cable types**.....RG174, RTK, RG58, RG59

■ **Packaging**



- Terminal: reel
- Housing: bulk
- Crimp sleeve: reel

■ **Comment**

- USCAR: Terminal + Crimp sleeve*
- USCAR Interoperable: Terminal


■ **Product alternative**

- Machined Fakra II

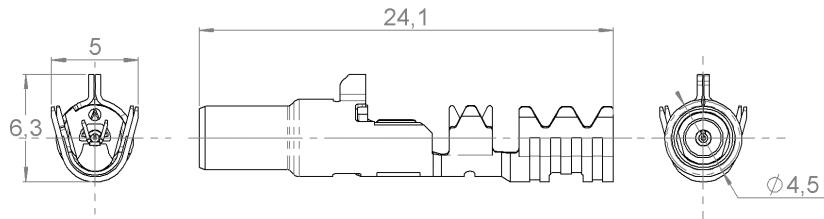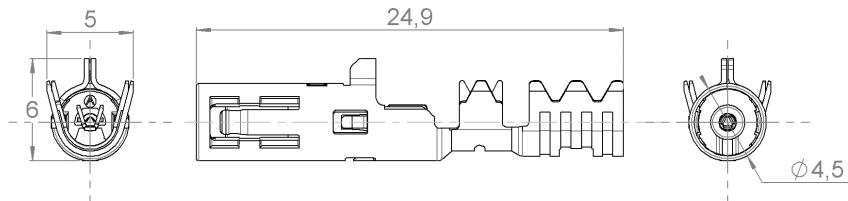

FEATURES :

- 1 step crimping terminal
- Closed entry: robust & protected interface design
- Positioning guaranteed design
- Automation friendly

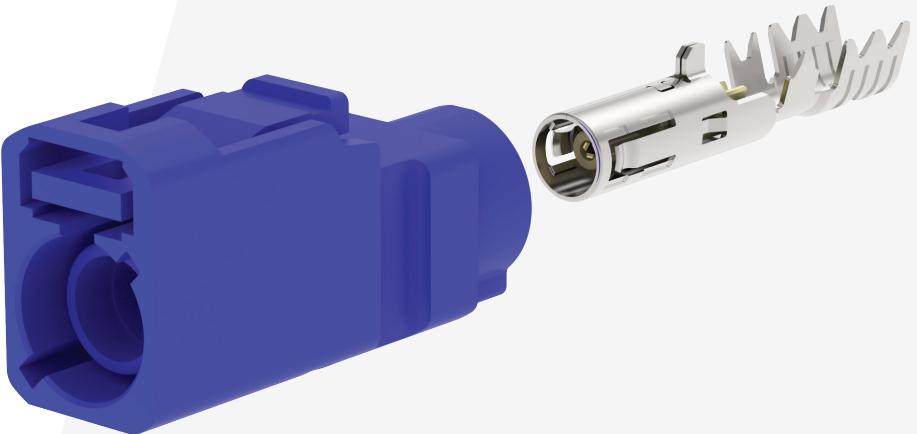

| | Cable type | Terminal | Simplex housing | Duplex housing |
|---------------|-------------------|-----------------|------------------------|-----------------------|
| Female | RG174 | R299.197.200 | R197.115._80 | R197.215._80 |
| | RTK | R299.197.210 | | |
| | RG59 | R299.197.260 | R197.115._81 | --- |
| | RG58 | R299.197.230 | | |
| Male | RG174 | R299.197.000 | R197.135._80 | R197.235._80 |
| | RTK | R299.197.010 | | |
| | RG59 | R299.197.060 | R197.135._81 | --- |
| | RG158 | R299.197.030 | | |


*Contact us for crimp sleeve option.

R3C WATERPROOF

- **Qualification**.....USCAR + IP67
- **Frequency**.....Up to 3 GHz
- **Technology**.....Stamped & rolled
- **Cable types**.....RG174, RTK
- **Packaging**

- *Terminal: reel*
- *Housing kit: bulk*

Waterproof housing
External joint
Cable joint
Cap
Sleeve

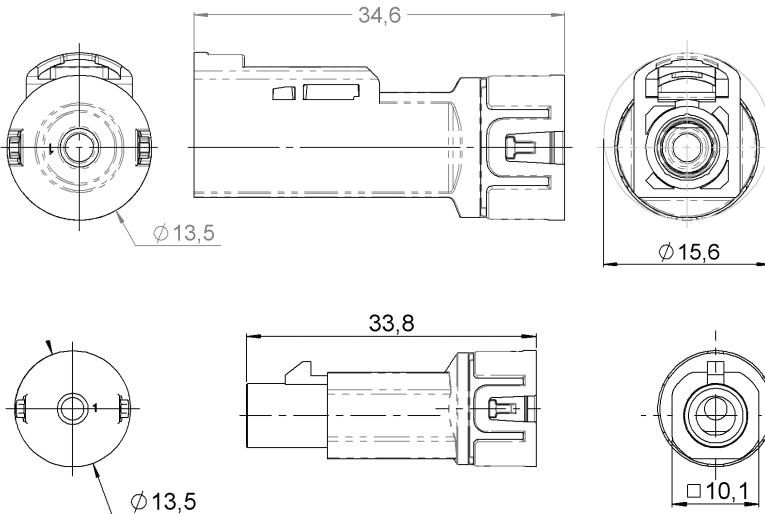

FEATURES :

- 1 step crimping terminal
- Waterproof IP67
- Interoperable with USCAR / FAKRA PCB components
- Automation friendly



| | Cable type | Terminal | Simplex housing waterproof kit |
|---------------|-------------------|-----------------|---------------------------------------|
| Female | RG174 | R299.197.200 | R197.115._11 |
| | RTK | R299.197.210 | R197.115._12 |
| Male | RG174 | R299.197.000 | R197.135._11 |
| | RTK | R299.197.010 | R197.135._12 |

R3C 90°


- **Qualification**.....USCAR validated
- **Frequency**.....Up to 3 GHz
- **Technology**.....Stamped & rolled
- **Cable types**.....RG174, RTK, RG58, RG59

■ **Packaging**

- *Terminal: reel*
- *Housing: bulk*

■ **Product alternative**

- *Machined version*

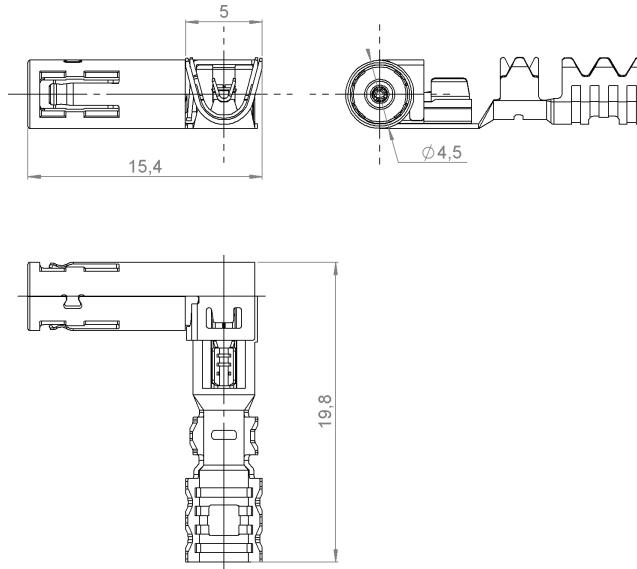

FEATURES :

- 1 step crimping terminal
- Turnable or fixed housing version
- Closed entry: robust & protected interface design
- Automation friendly




| Cable type | Terminal | Turnable simplex housing |
|------------|--------------|--------------------------|
| RG174 | R299.197.600 | R197.125._80 |
| RTK | R299.197.610 | |
| RG59 | R299.197.660 | R197.125._81 |
| RG58 | R299.197.630 | |

Contact us for fixed housing

WATERPROOF 90°

- **Qualification**.....USCAR + IP67
- **Frequency**.....Up to 6 GHz*
- **Technology**.....Die cast
- **Cable types**.....RG174, RTK
- **Packaging**.....Bulk

*Performance according to OEM specific requirements
and cable types

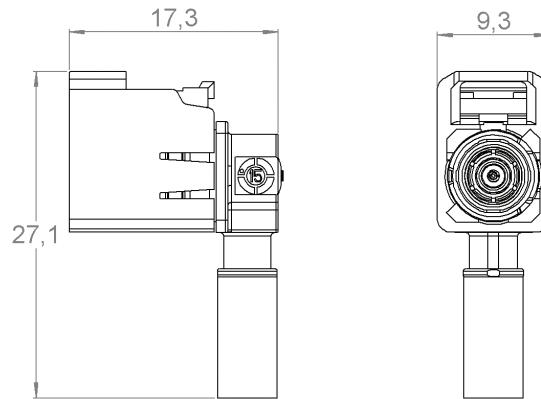


FEATURES :




- Turnable housing
- Waterproof IP67
- Compact and robust



| Cable type | Plug with housing |
|------------|-------------------|
| RG174 | R197.126._21 |
| RTK | R197.126._22 |

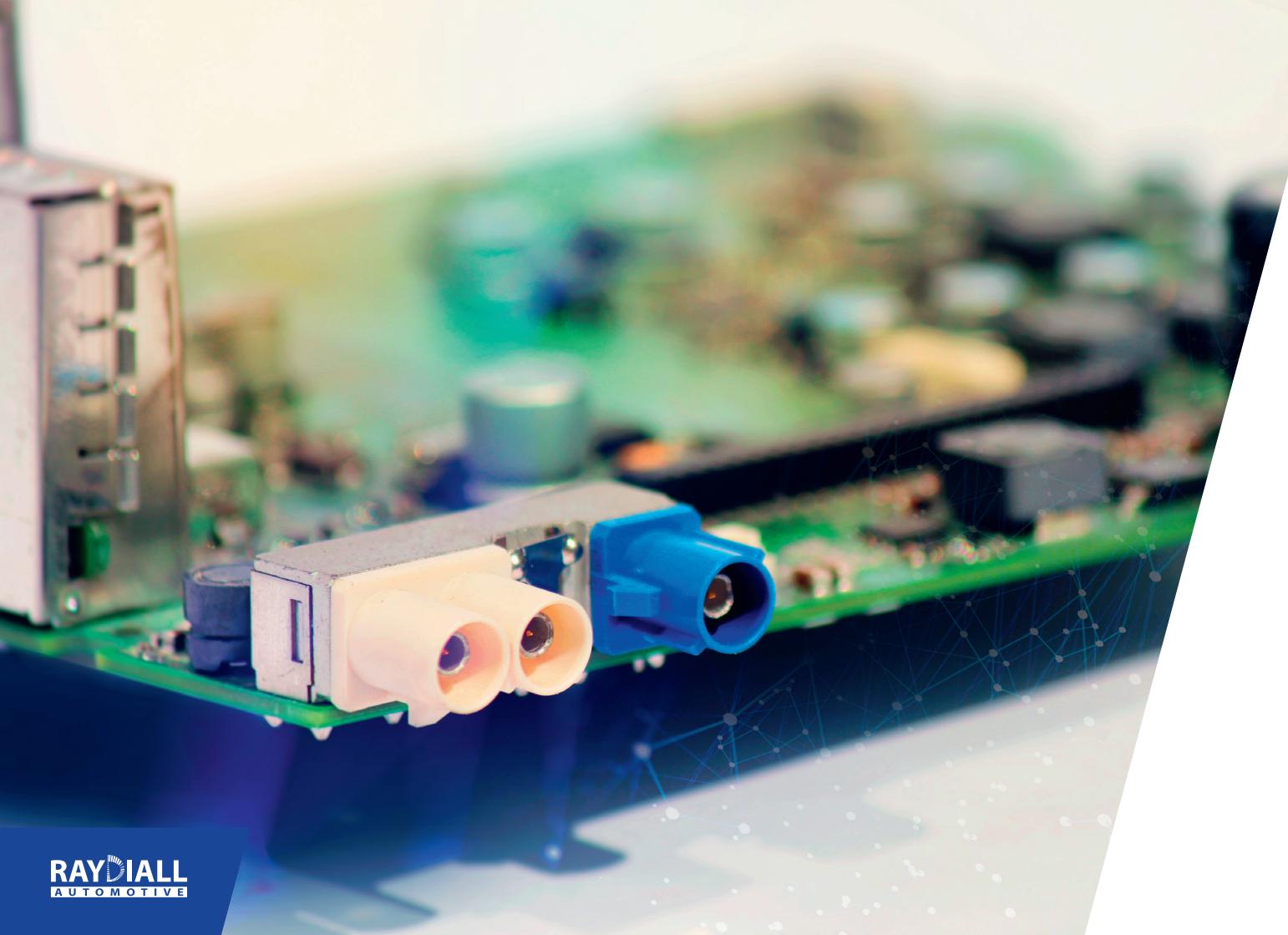


FAKRA PCB CONNECTORS

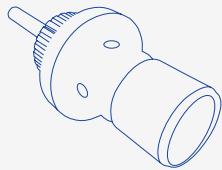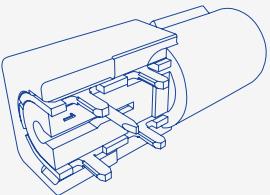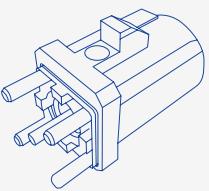

FAKRA PCB 180°



- **Process**.....Reflow soldering
- **Qualification**.....USCAR
- **Frequency**.....Up to 4 GHz
- **Technology**.....Stamped & rolled
- **Packaging**.....Tape & reel
- **Product alternative**
 - *Machined version*

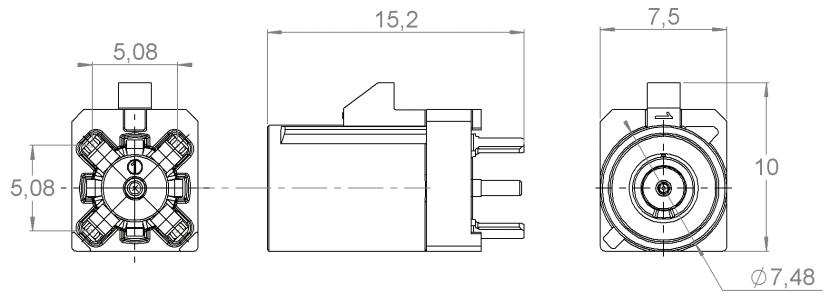

FEATURES :

- Lightweight
- Compliant with pick and place process
- 350 units per reel
- Customization friendly

| Reference |
|--------------|
| R197.156._28 |

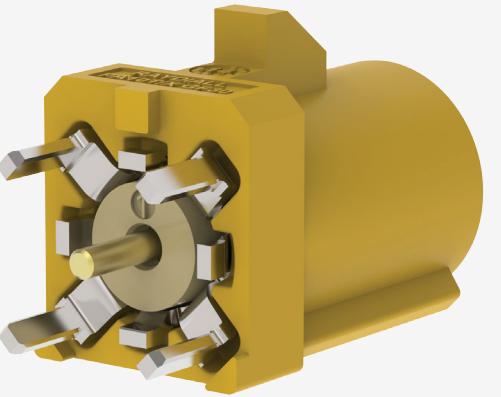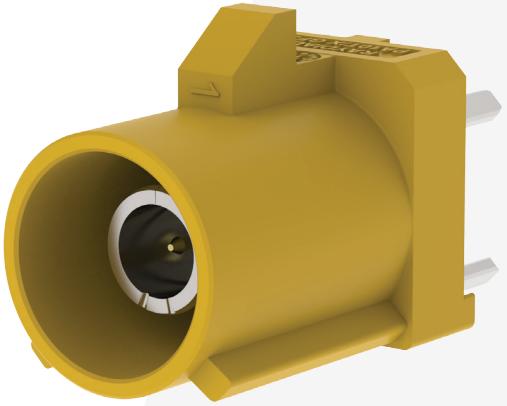

FAKRA PCB 90°




- **Process**.....Reflow or Wave soldering
- **Qualification**.....USCAR
- **Frequency**.....Up to 4 GHz
- **Technology**.....Stamped & rolled
- **Packaging**.....Tape & reel
- **Product alternative**

- *Die cast version*

5 mm pitch


6 mm pitch

7 mm pitch

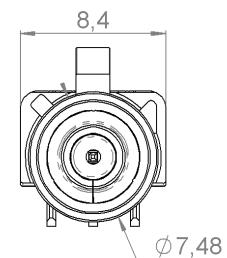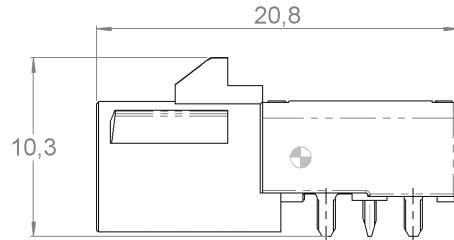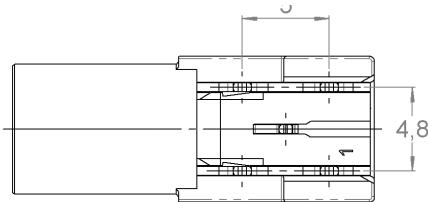

FEATURES :

- Nose orientations: 3h, 6h, 9h, 12h
- Compliant with pick and place process
- 450 units per reel
- Customization friendly

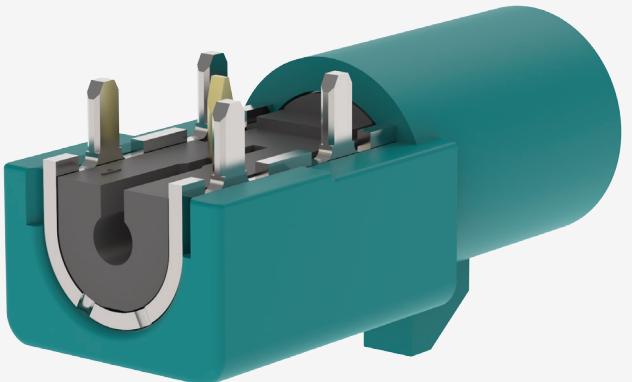


Reference

R197.166._XX


PRESS IN CONTACT

- **Process**.....Pressed in die cast chassis
- **Qualification**.....USCAR
- **Frequency**.....Up to 4 GHz
- **Technology**.....Machined
- **Packaging**.....Bulk

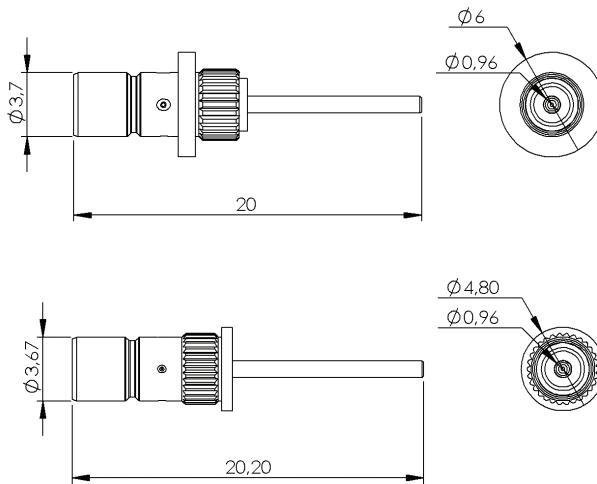


FEATURES :



- 0,8 μ or 0,15 μ gold plating on center contact
- 6mm, 8mm, 10mm or 11mm center contact length (other on demand)
- Straight or bended center contact
- Rear and front mount version
- Direct grounding with die cast chassis

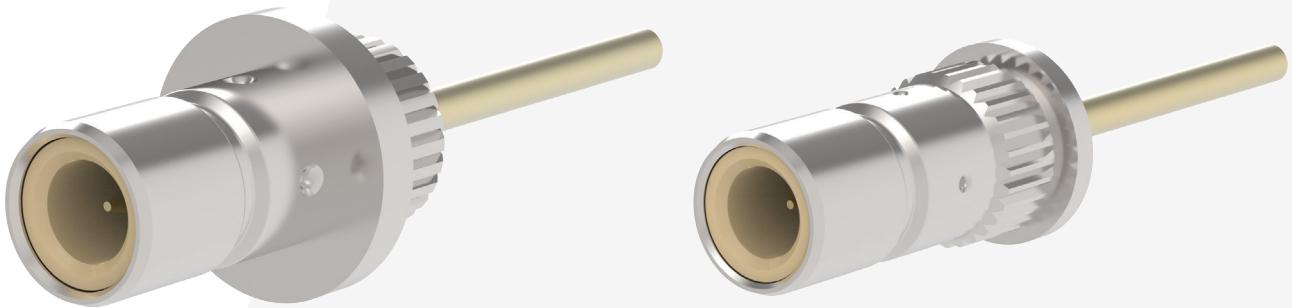

| | Center contact length (mm) | Gold thickness (µm) | Press in |
|-------------|----------------------------|---------------------|--------------|
| Front Mount | 6mm | 0,15 | R114.504.205 |
| | 8mm | 0,15 | R114.504.225 |
| | 10mm | 0,15 | R114.504.230 |
| | 10mm | 0,80 | R114.504.235 |
| Rear Mount | 9,3mm | 0,15 | R114.505.220 |
| | 11mm | 0,15 | R114.505.235 |
| | 11mm | 0,80 | R114.505.230 |

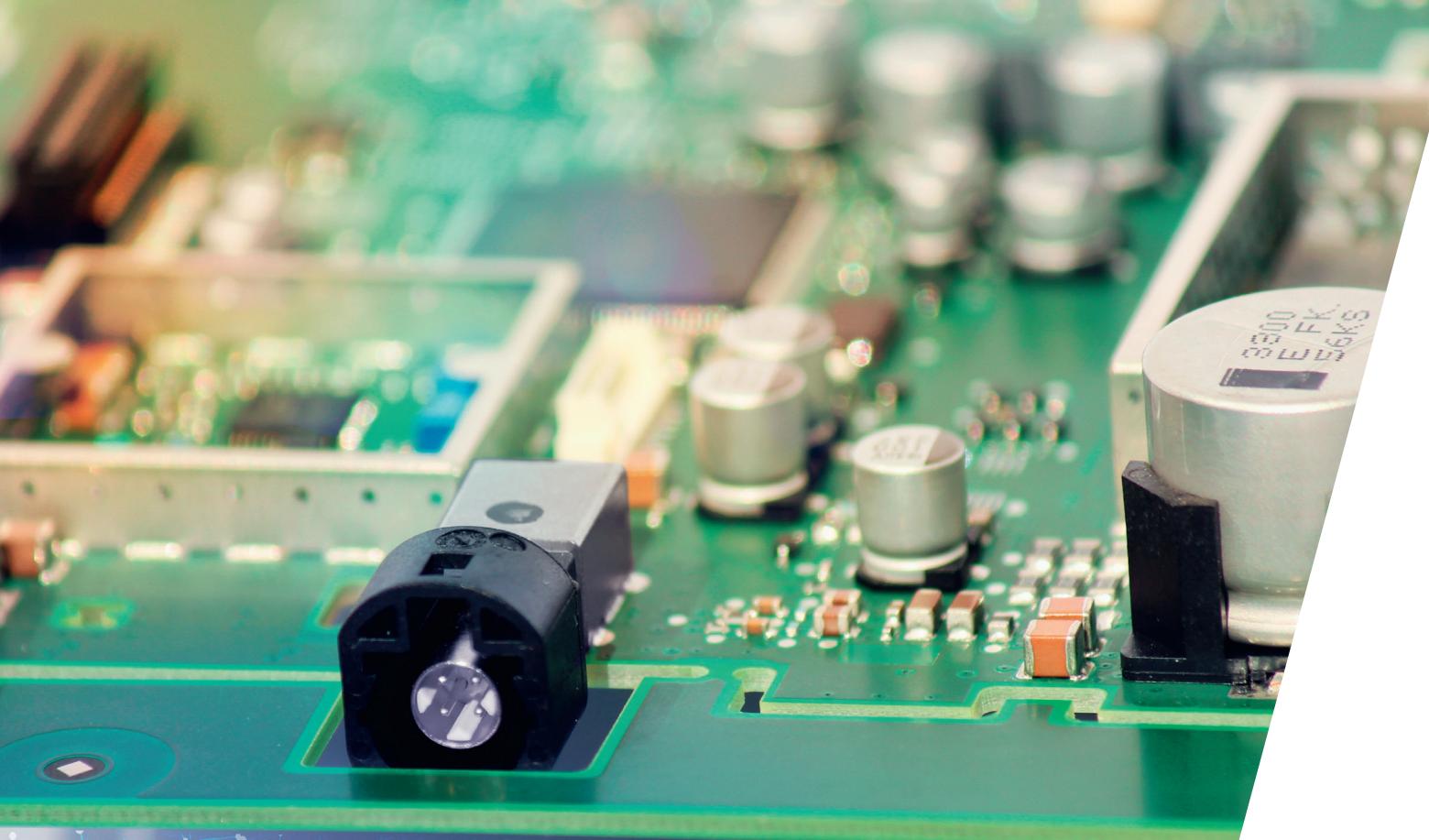


HSD PCB CONNECTORS

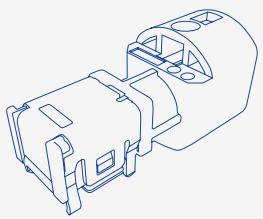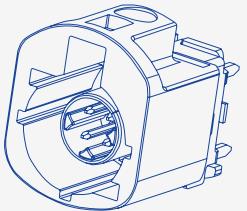



HSD PCB 180°

- **Process**.....Reflow soldering
- **Qualification**.....Tiers specifications
- **Frequency**.....Up to 2 GHz
- **Technology**.....Stamped & rolled
- **Packaging**.....Tape and reel

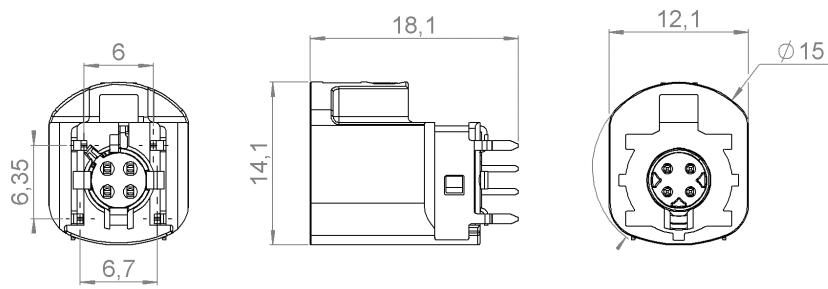

FEATURES :




- Lightweight
- 250 units per reel
- Customization friendly

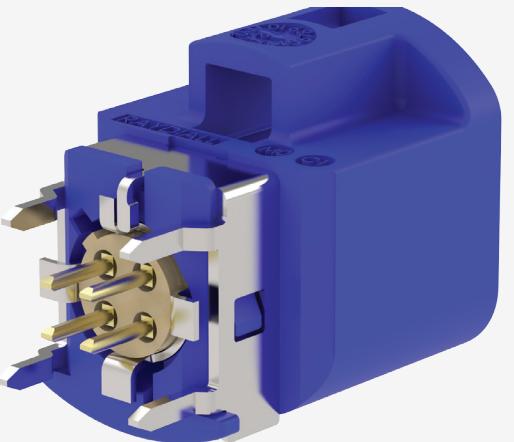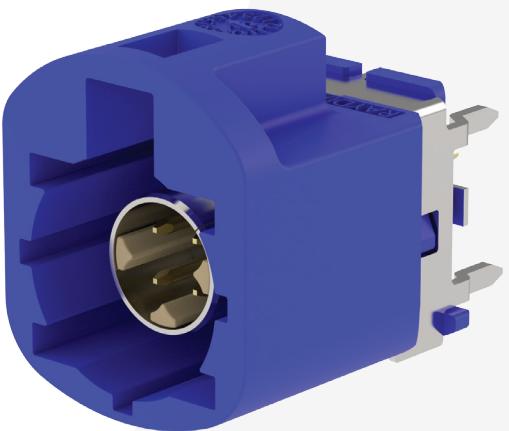**Reference**

R197.197_09


HSD PCB 90°

- **Process**.....Reflow soldering
- **Qualification**.....Tiers specifications
- **Frequency**.....Up to 2 GHz
- **Technology**.....Stamped & rolled
- **Packaging**.....Tape and reel

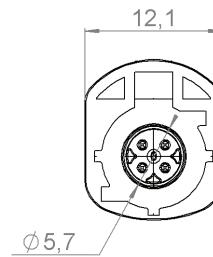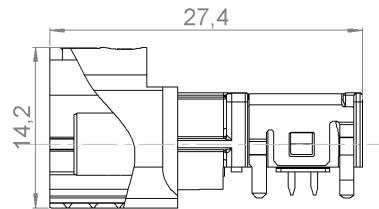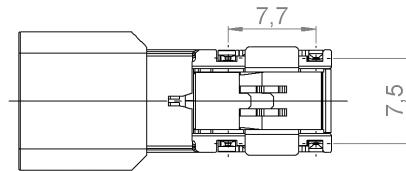

FEATURES :

- Lightweight
- 250 units per reel
- Customization friendly

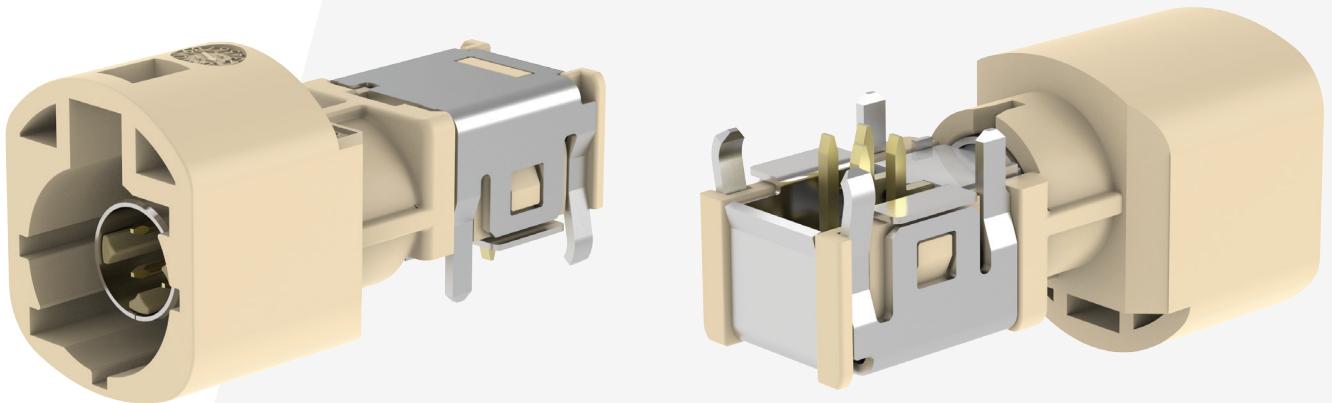


Reference

R299.197._28





ELECTRIC VEHICLE SOLUTIONS

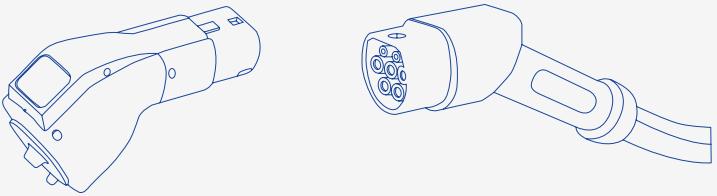

POWER PLUG

- **Power**.....43 kW AC
- **Operating current**.....63 A
- **3 Phases + Neutral + Ground**
- **Interface**.....IEC 62196
- **Certification**.....CE certified

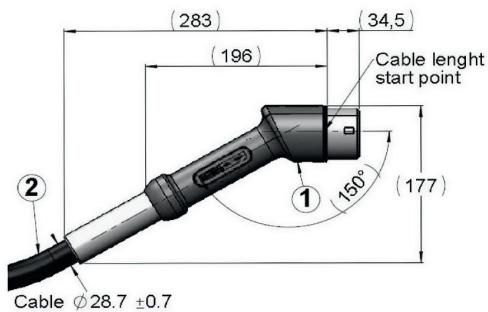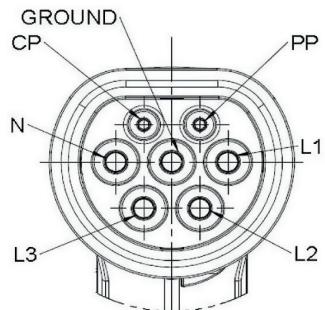

FEATURES :

- Silver plated contacts
- Custom cable length
- High reliability (tested until 100 k matings)
- Low insertion force




| | References |
|-----------------------|---------------------|
| 5 meters cable | R297CAZ10500 |
| 6 meters cable | R297CAZ10600 |
| 7 meters cable | R297CAZ10700 |

© Copyright PHI DESIGN 2015 - Design/Modeling/Rendering

Other cable lengths available upon request

ADAPTOR

- **Power**.....22 kW AC
- **Operating current**.....32 A
- **3 Phases + Neutral + Ground**
- **Interface**.....IEC 62196
- **Certification**.....CE certified

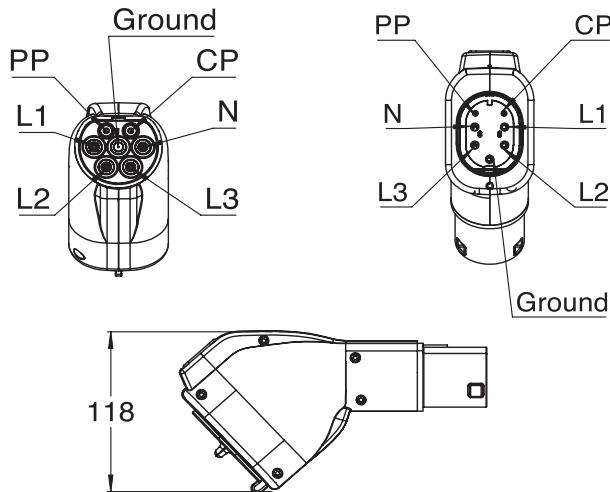

FEATURES :


- Adaptor T3c to T2b interface
- Integrated safety switch
- Locking sequence
- Reliable and selected by OEMs
- Silver plated contacts



| Reference |
|----------------|
| R297CFD2.00-00 |
| R297CFD2.00-10 |

If you could not find the product you were looking for, please contact us, other products are available and customization is always possible.

Let's create together a broader range of possibilities.

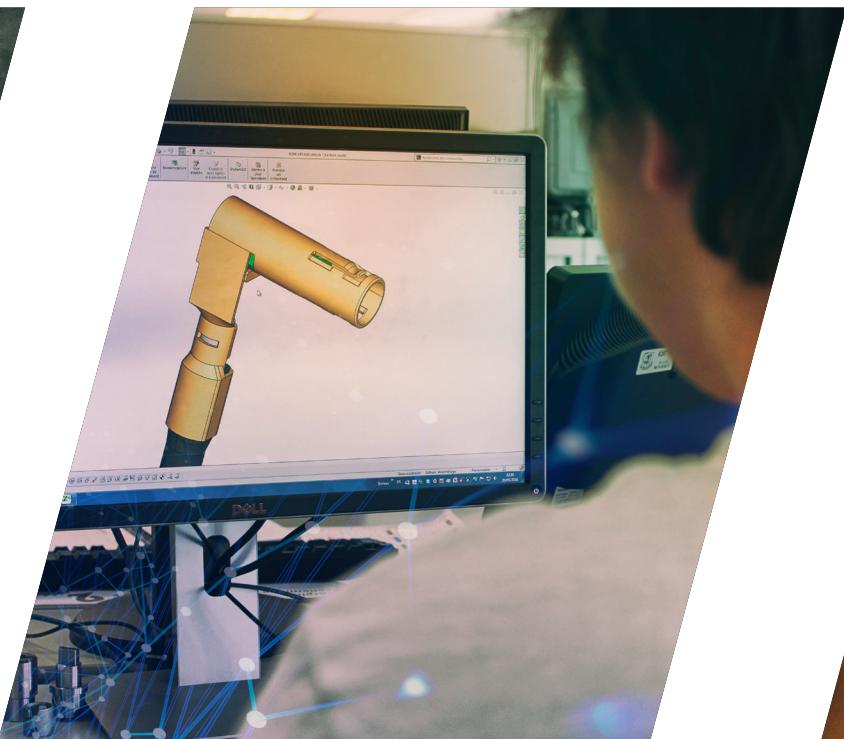



WE ARE LOOKING FORWARD
TO ANSWERING YOUR QUESTIONS.

Don't hesitate to contact us!

RAYDIALL
AUTOMOTIVE

www.raydiall.com



Errors and technical changes reserved. Raydiall products are sold according Raydiall Standard Terms and Conditions of Sale, issue of January, 2012.
For further information contact us. Raydiall-catalogue-V-01