


LAN Transformers

Delivering Digital Transformation
Exos Series

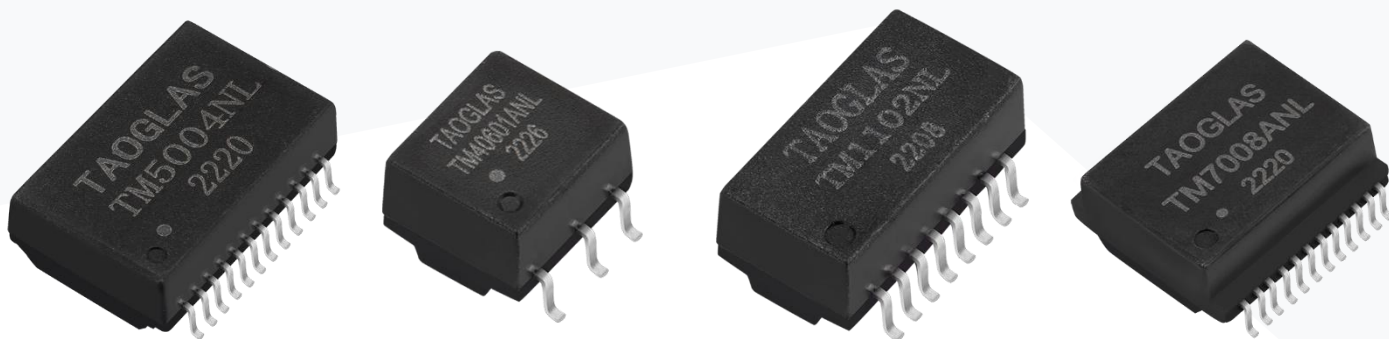

Product description

Taoglas Magnetics with over 15+ years of LAN magnetics design and manufacturing experience from its team, is providing services to customers with a wide range of applications such as: Networking and Interconnect Devices, Servers, Switches, Router, Communication systems and any Digital Consumer electronics.

The Taoglas Exos Series offer an extensive product line of LAN Transformers designed for commercial and industrial grade applications, supporting 10/100 Base-T (Exos100), 1G Base-T (Exos1G) and 10G Base-T (Exos10G). The Taoglas Exo series includes Single, Dual, and Quad configurations not only for standard applications but also for Power over Ethernet (PoE, PoE+, PoE++).

Features

- 10/100 Base-T, 1G, 10G
- 0°C ~ +70°C ; -40°C ~ +85°C
- IEEE802.3 Compliant & UL Certified
- Low profile package in 10/100 & 1G

Benefits

- Superior EMI suppression
- Wide selection on package size
- Max. reflow temperature 245°C
- Designed for leading PHY IC manufacturers

Taoglas makes no warranties based on the accuracy or completeness of the contents of this document and reserves the right to make changes to specifications and product descriptions at any time without notice. Taoglas reserves all rights to this document and the information contained herein. Reproduction, use or disclosure to third parties without express permission is strictly prohibited.

Target Applications



Gateways
Modems
Remote-powering
Machinery



Security Systems
Video Game Systems
Industrial PCs
Laptops



Mother board
Network solutions
5G deployments



Servers
Routers
Switches
Robotics

Exos Series:

Exos100


Taoglas P/N	Description
TM1102NL	LAN Transformer, 10/100 Base-T, Single Port, 16pin, AutoMDIX, CMC/Cable, Commercial
TM1188NL	LAN Transformer, 10/100 Base-T, Single Port, 16pin, AutoMDIX, CMC/Cable, Industrial
TM1198NL	LAN Transformer, 10/100 Base-T, Single Port, 16pin, AutoMDIX, CMC/Phy, Industrial
TM1234NL	LAN Transformer, 10/100 Base-T, Quad Port, 40pin, AutoMDIX, CMC/Cable, Industrial
TM2019ANL	LAN Transformer, 10/100 Base-T, Single Port, 16pin, PoE(350mA), Industrial
TM42430ANL	LAN Transformer, 10/100 Base-T, Single Port, 24pin, 3Wire/Cable, Industrial

Exos1G

Taoglas P/N	Description
TM5004NL	LAN Transformer, 1G Base-T/1000 Base-T, Single Port, 24pin, AutoMDIX, Industrial
TM5007NL	LAN Transformer, 1G Base-T/1000 Base-T, Single Port, 24pin, AutoX'fmr, Commercial
TM5008ANLE	LAN Transformer, 1G Base-T/1000 Base-T, Single Port, 24pin, AutoX'fmr, Industrial
TM5020NLR	LAN Transformer, Dual 1G Base-T, Dual Port, 50pin, PoE, AutoMDIX, Industrial
TM82440ANL	LAN Transformer, 1G Base-T/1000 Base-T, Single Port, 24pin, AutoMDIX, Industrial
TM82453NL	LAN Transformer, 1G Base-T/1000 Base-T, Single Port, 24pin, AutoMDIX, PCMCIA, Commercial

Exos10G

Taoglas P/N	Description
TM7008ANL	LAN Transformer, 10G Base-T, Single Port, 24pin, PoE+ (600mA@57V), Industrial
TM7008NL	LAN Transformer, 10G Base-T, Single Port, 24pin, PoE+ (600mA@57V), Commercial

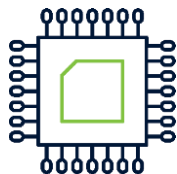

Trusted Technology
We have enabled tens of thousands of successful IoT/M2M hardware and software projects globally over the last 17 years.



Customer Support
Located close to customers globally with latest test, design and support services.



Global Engineering Excellence
World-class design, consultancy and engineering expertise, along with support and test centers globally.