


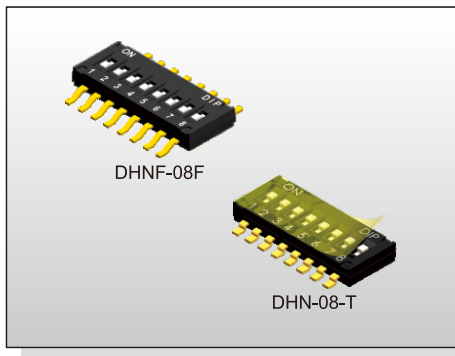

FEATURES

- ※Low profile 1.6mm height
- ※Gold contact for high reliability
- ※Top tape type for washing process


APPLICATION

- ※Industrial control
- ※Automatic machines control
- ※NB, electronic devices

SPECIFICATION

Contact Rating	25mA, 24V DC
Contact Resistance	100mΩ max.
Insulation Resistance	100MΩ min. 500V DC
Dielectric Strength	300V AC/1 minute
Operating Force	500gf max.
Travel	0.6mm
Operating Life	1,000 cycles
Operating Temp.	-40°C ~ +85°C
Storage Temp.	-40°C ~ +85°C

CIRCUIT

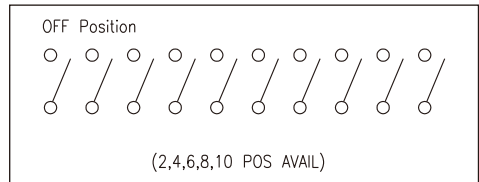

PACKAGE

<Tube>

DHN(F)-02: 125 pcs
DHN(F)-04: 75 pcs
DHN(F)-06: 54 pcs
DHN(F)-08: 40 pcs
DHN(F)-10: 33 pcs

<Tape & Reel>

DHN: 4000 pcs
DHNF: 2500 pcs

HOW TO ORDER

D H N □ - □ □ □ - □ - □ - □

Pin Length:
 □=6.70mm
 F=8.10mm

Positions:
 02, 04, 06, 08, 10



□="ON" Position
 F="OFF" Position

Package:
 □=Tube
 T/R=Tape & Reel



V=RoHS & Lead Free Solderable
 Q=Halogen Free

□=Regular
 T=Top Tape Sealed

DHN

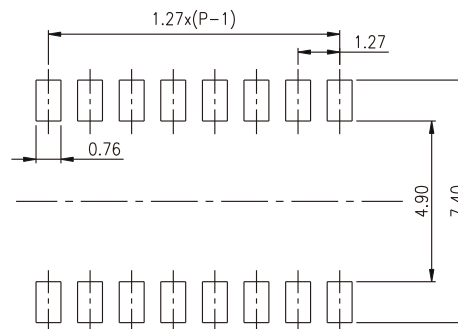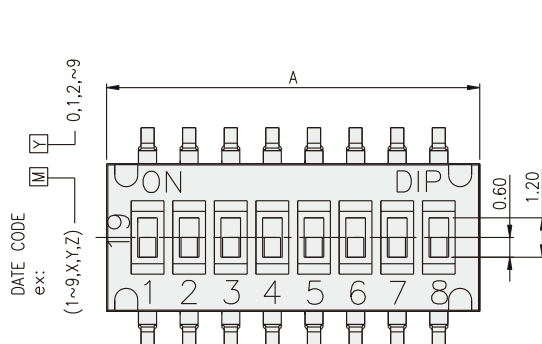



P.C.B. LAYOUT

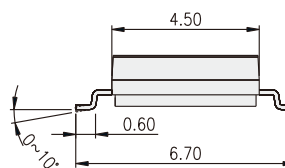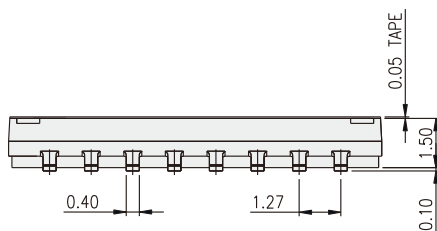



PART NO.	NO.OF POS	DIM A
DHN-02	2	3.77
DHN-04	4	6.31
DHN-06	6	8.85
DHN-08	8	11.39
DHN-10	10	13.93

DHNF

DIP SWITCH

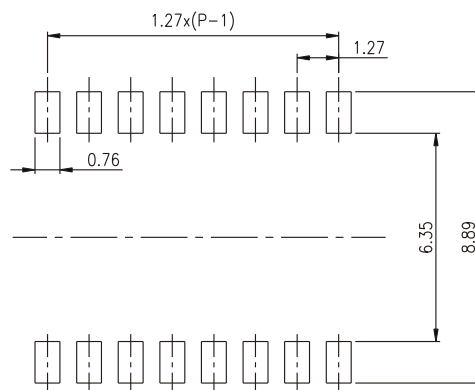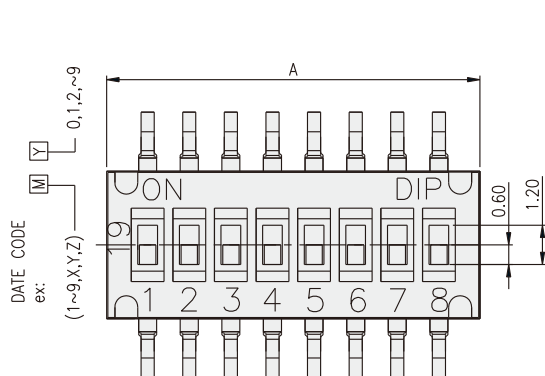

P.C.B. LAYOUT

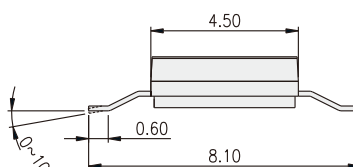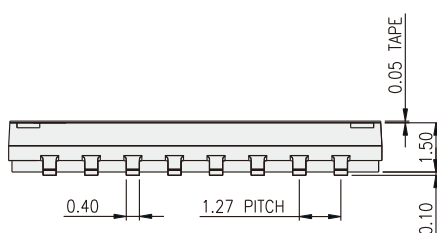

PART NO.	NO.OF POS	DIM A
DHNF-02	2	3.77
DHNF-04	4	6.31
DHNF-06	6	8.85
DHNF-08	8	11.39
DHNF-10	10	13.93