




904 SERIES

External HD Mini SAS Right Angle Connector
0.75 mm Pitch

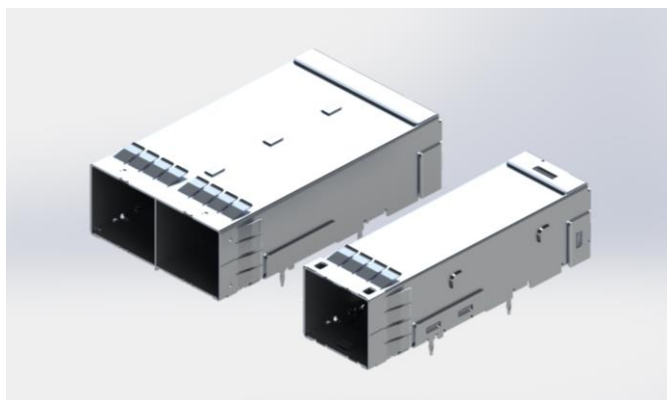

Features:

- Power Sum :
PSNEXT 12Gbps@<-30dB
PSFEXT 12Gbps@<-30dB
- Available in 1x1 port, 1x2 ports
- Compliance with SAS 3.0
- Application : Server, Data Storage, Switch

Specifications:

Housing Material	High Temperature Thermoplastic UL-94V-0
Contact Material	Copper Alloy
Contact Plating	Gold Flash Plating
Voltage Rating	30V AC Max.
Current Rating	0.5 A/ Pin Max.
Contact Resistance	10mΩ Max.
Dielectric Withstand Voltage	300 V AC for 60s
Insulation Resistance	1000 MΩ Min.
Operating Temperature	-55°C to +80°C
Mating Force	50N Max.
Unmating Force	10N Max.

Part Number	No. of Contacts	Photo	Height
904-036-225-002	1 Port, 36 Contacts		14.05mm
904-072-225-002	2 Port, 72 Contacts		14.05mm