

【Feature】

- Slim 13mm display with attached self supporting base.
- High contrast display using non-glare filter
- Available in 4 types of display configurations - VFD or FSTN-LCD and ANK or Kanji Character set.
- Display head tilts up to 40 degrees for improved view
- Available Case color selection (Black or White)



【Selectable Display】

	FSTN-LCD	VFD
ANK	AH148** Two by twenty 5 × 8 dot matrix characters 	AH156** (FLDP) Two by twenty 5 × 8 dot matrix characters 
KANJI	AH147** 160x40 dot matrix display 	AH145** (VFD) 160x36 dot matrix display 

<Contact>


Futaba Corporation Tokyo Sales Office oak kandakajicho Bldg. 8F, 3-4 Kandakaji-cho Chiyoda-ku, Tokyo, 101-0045, Japan

TEL : 81-43-296-5112 FAX : 81-43-296-5122

URL <http://www.futaba.co.jp/>

【Specifications】

Series	AH145**	AH156**	AH147**	AH148**
Display	VFD 160x36 dot matrix	FLDP (Front Luminescence Display) Two by twenty 5 × 8 dot matrix characters	FSTN-LCD 160x40 dot matrix	FSTN-LCD Two by twenty 5 × 8 dot matrix characters
Display size [mm]	98.46 x 18.98	101.75 x 18.5	106.4 x 29.6	105.75 x 22.5
Luminance [cd/m ²]	160 (with Filter) 700 (without Filter)	160 (with Filter) 700 (without Filter)	130	130
Interface	USB or RS232C or Bluetooth3.0(iAP) *Selected from the lineup.			
Operating Temperature Range [°C]	0°C ~ +40°C			
Case color	White or Black *Selected from the lineup.			
Outer Dimension [mm]	W141 x H79 x T60			
Power Supply Voltage	DC5V/0.38A (Typ.)	DC5V/0.38A (Typ.)	DC5V/0.07A (Typ.)	DC5V/0.05A (Typ.)

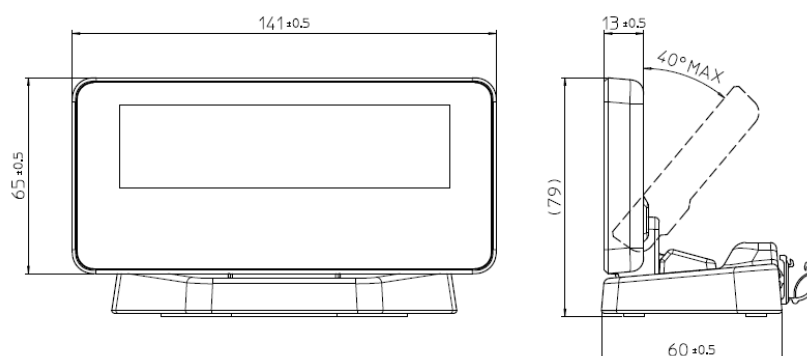

Case Mechanical Dimensions [mm]

<Contact>

Futaba Corporation Tokyo Sales Office oak kandakajicho Bldg. 8F, 3-4 Kandakaji-cho Chiyoda-ku, Tokyo, 101-0045, Japan

TEL : 81-43-296-5112 FAX : 81-43-296-5122

URL <http://www.futaba.co.jp/>