



The Field Mountable REVConnect Plug is the answer to your IoT and AV needs. One reliable, easy, versatile termination process is all that's required for your building security systems, LED lighting and sensors, wireless access points, HVAC, digital signage, audio mixing consoles, and more.

Saves Money

Eliminates the jack, box, and patch cord assembly needed to plug into devices

Saves Time

Single termination process for every application

Peace of Mind

Strong, Belden warranted performance for Networking and HDBaseT


PoE Ready

Supports devices requiring up to 100W power

Strongest IL Performance

Direct use of horizontal cable eliminates patch cord derating

Tested to 625MHz

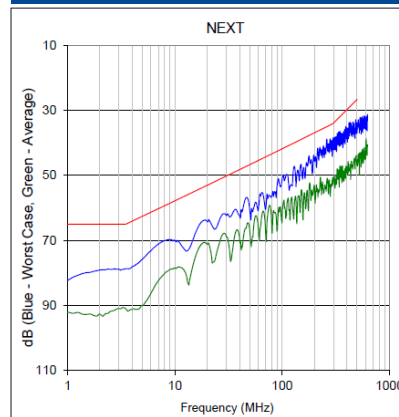

NEXT			
Freq.	Worst Case	Average	Spec. TIA
1	82.3	92.0	65.0
4	78.1	91.2	64.1
8	70.1	80.2	59.4
10	70.0	78.5	57.8
16	66.8	73.8	54.6
20	64.1	71.2	53.1
25	65.3	72.7	51.5
31	61.8	69.2	50.0
62	55.7	66.8	45.2
100	51.1	62.9	41.8
160	48.1	55.8	38.5
200	45.7	53.6	36.9
250	41.9	53.0	35.3
300	39.2	52.6	34.0
350	40.9	50.5	31.8
400	35.4	49.3	29.9
450	37.0	46.8	28.2
500	36.1	46.3	26.7
550	32.8	44.4	na
600	35.9	44.9	na
625	31.3	41.0	na

Ordering Information

REVConnect 10GX Category 6A

Description	Elec White	Black	Gray	Ivory	Almond		
REVConnect 10GX Jack - Single Pack	RVAMJKUEW-S1	RVAMJKUBK-S1	RVAMJKUGY-S1	RVAMJKUIV-S1	RVAMJKUAL-S1		
REVConnect 10GX Jack - Bulk Pack	RVAMJKUEW-B24	RVAMJKUBK-B24	RVAMJKUGY-B24	RVAMJKUIV-B24	RVAMJKUAL-B24		
Description	Brown	Red	Orange	Yellow	Green	Blue	Purple
REVConnect 10GX Jack - Single Pack	RVAMJKUBR-S1	RVAMJKURD-S1	RVAMJKUOR-S1	RVAMJKUYL-S1	RVAMJKUGN-S1	RVAMJKUBL-S1	RVAMJKUPR-S1
REVConnect 10GX Jack - Bulk Pack	RVAMJKUBR-B24	RVAMJKURD-B24	RVAMJKUOR-B24	RVAMJKUYL-B24	RVAMJKUGN-B24	RVAMJKUBL-B24	RVAMJKUPR-B24
Description	Brown TIA	Red TIA	Orange TIA	Yellow TIA	Green TIA	Blue TIA	Purple TIA
REVConnect 10GX Jack - Single Pack	RVAMJKUTN-S1	RVAMJKUTR-S1	RVAMJKUTO-S1	RVAMJKUTY-S1	RVAMJKUTG-S1	RVAMJKUTB-S1	RVAMJKUTP-S1
REVConnect 10GX Jack - Bulk Pack	RVAMJKUTN-B24	RVAMJKUTR-B24	RVAMJKUTO-B24	RVAMJKUTY-B24	RVAMJKUTG-B24	RVAMJKUTB-B24	RVAMJKUTP-B24



REVConnect CAT6+ Category 6

Description	Elec White	Black	Gray	Ivory	Almond		
REVConnect CAT6+ Jack - Single Pack	RV6MJKUEW-S1	RV6MJKUBK-S1	RV6MJKUGY-S1	RV6MJKUIV-S1	RV6MJKUAL-S1		
REVConnect CAT6+ Jack - Bulk Pack	RV6MJKUEW-B24	RV6MJKUBK-B24	RV6MJKUGY-B24	RV6MJKUIV-B24	RV6MJKUAL-B24		
Description	Brown	Red	Orange	Yellow	Green	Blue	Purple
REVConnect CAT6+ Jack - Single Pack	RV6MJKUBR-S1	RV6MJKURD-S1	RV6MJKUOR-S1	RV6MJKUYL-S1	RV6MJKUGN-S1	RV6MJKUBL-S1	RV6MJKUPR-S1
REVConnect CAT6+ Jack - Bulk Pack	RV6MJKUBR-B24	RV6MJKURD-B24	RV6MJKUOR-B24	RV6MJKUYL-B24	RV6MJKUGN-B24	RV6MJKUBL-B24	RV6MJKUPR-B24
Description	Brown TIA	Red TIA	Orange TIA	Yellow TIA	Green TIA	Blue TIA	Purple TIA
REVConnect CAT6+ Jack - Single Pack	RV6MJKUTN-S1	RV6MJKUTR-S1	RV6MJKUTO-S1	RV6MJKUTY-S1	RV6MJKUTG-S1	RV6MJKUTB-S1	RV6MJKUTP-S1
REVConnect CAT6+ Jack - Bulk Pack	RV6MJKUTN-B24	RV6MJKUTR-B24	RV6MJKUTO-B24	RV6MJKUTY-B24	RV6MJKUTG-B24	RV6MJKUTB-B24	RV6MJKUTP-B24




REVConnect CAT5E Category 5e

Description	Elec White	Black	Gray	Ivory	Almond		
REVConnect CAT5E Jack - Single Pack	RV5MJKUEW-S1	RV5MJKUBK-S1	RV5MJKUGY-S1	RV5MJKUIV-S1	RV5MJKUAL-S1		
REVConnect CAT5E Jack - Bulk Pack	RV5MJKUEW-B24	RV5MJKUBK-B24	RV5MJKUGY-B24	RV5MJKUIV-B24	RV5MJKUAL-B24		
Description	Brown	Red	Orange	Yellow	Green	Blue	Purple
REVConnect CAT5E Jack - Single Pack	RV5MJKUBR-S1	RV5MJKURD-S1	RV5MJKUOR-S1	RV5MJKUYL-S1	RV5MJKUGN-S1	RV5MJKUBL-S1	RV5MJKUPR-S1
REVConnect CAT5E Jack - Bulk Pack	RV5MJKUBR-B24	RV5MJKURD-B24	RV5MJKUOR-B24	RV5MJKUYL-B24	RV5MJKUGN-B24	RV5MJKUBL-B24	RV5MJKUPR-B24
Description	Brown TIA	Red TIA	Orange TIA	Yellow TIA	Green TIA	Blue TIA	Purple TIA
REVConnect CAT5E Jack - Single Pack	RV5MJKUTN-S1	RV5MJKUTR-S1	RV5MJKUTO-S1	RV5MJKUTY-S1	RV5MJKUTG-S1	RV5MJKUTB-S1	RV5MJKUTP-S1
REVConnect CAT5E Jack - Bulk Pack	RV5MJKUTN-B24	RV5MJKUTR-B24	RV5MJKUTO-B24	RV5MJKUTY-B24	RV5MJKUTG-B24	RV5MJKUTB-B24	RV5MJKUTP-B24



Shielded Jacks and Field Mount Plugs

Package Size	10GX Shielded Jacks	CAT6+ Shielded Jacks	CAT5E Shielded Jacks	10GX Shielded Plugs	10GX UTP Plugs
Single Pack	RVAMJKSME-S1	RV6MJKSME-S1	RV5MJKSME-S1	RVAFPSME-S1	RVAFPUBK-S1
Bulk Pack (24 Modules)	RVAMJKSME-B24	RV6MJKSME-B24	RV5MJKSME-B24	RVAFPSME-B24	RVAFPUBK-B24

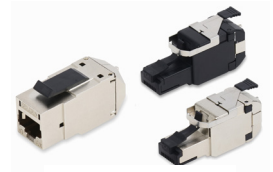

REVConnect Tool and Accessories

Universal Termination Tool	Tool Spare Blade Set	Cable Prep Tool Replacement	Tool Belt Clip	Dust Caps for Jacks	Icons for Jacks	Bulk Pack of REVConnect Cores
RVUTT01	RVUTB01	RVUCT01	RVUTC01	RVUDCXX-B24	RVUICXX-B24	RVUCOEW-B50
Includes tool, cable prep insert, and spare blade set	Optional extra set of blades with Allen key included	Optional cable prep tool replacement insert	Optional belt clip for universal tool	Optional dust caps for all jacks; XX is color code, pack of 24	Optional icons for all jacks; XX is color code, pack of 24	Bulk pack of 50 cable managers and caps



Color codes: AL (almond), BK (black), BL (blue), BR (brown), EW (electric white), GN (green), GY (gray), IV (ivory), OR (orange), PR (purple), RD (red), YL (yellow), TB (TIA blue), TG (TIA green), TN (TIA brown), TO (TIA orange), TP (TIA purple), TR (TIA red), TY (TIA yellow)

For more information visit
www.belden.com/REVConnect
 or call 1.800.BELDEN.1

© Copyright 2016, Belden Inc.
 Direct Connect with REVConnect_PB00078_ECOS_BDC_1016_A_AG