

“Stay Connected” with



a PennEngineering® Company

HEYware Products

HEYBite Mini's®

Unassembled or Assembled with 8" Cable Tie



HEYBite Mini's® - Stainless Steel with Nylon 6/6 Cable Tie, 8" Long

| UNASSEMBLED EDGE CLIP | | | EDGE CLIP ASSEMBLED WITH CABLE TIE | | | ASSEMBLED NYTYE CABLE TIE | | |
|--|----------|-----------------|------------------------------------|-----------------|-----------------|---------------------------|------------------|-------------------|
| Fixing | Part No. | Description | Cable Tie | Part No. | Description | Tensile Strength | Max. Bundle Dia. | Overall Length |
| | | Stainless | Orientation | Stainless/Black | | Lbs. N | in. mm. | in. mm. |
| For Panels from .06" (1.5mm) to .12" (3.0mm) Thick | | | | | | | | |
| Top | S6474 | SunRunner CT | Perpendicular | S14275 | S6474-TP-50-078 | 50 | 222 | 1.77 |
| | | | Parallel | S14276 | S6474-TL-50-078 | | | 45.0 7.87 200 |
| For Panels from .12" (3.0mm) to .25" (6.4mm) Thick | | | | | | | | |
| Top | S6475 | SunRunner CT-EZ | Perpendicular | S14280 | S6475-TP-50-078 | 50 | 222 | 1.77 |
| | | | Parallel | S14281 | S6475-TL-50-078 | | | 45.0 7.87 200 |


Standard color black.

- Stainless steel mini clip “bites” into panel, chassis or module edges.
- Ideal for use where holes cannot be used or where adhesives are unacceptable due to temperature issues.
- Applies easily to plastic and metal without the need for a mounting hole.
- Ideal for assembly usage. Clip provides low insertion force and high extraction.
- Two piece assembly allows the clip to slide along the strap ensuring proper orientation.

HEYBite Mini's® - Stainless Steel with Nylon 12 Cable Tie, 8" Long


| UNASSEMBLED EDGE CLIP | | | EDGE CLIP ASSEMBLED WITH CABLE TIE | | | ASSEMBLED NYTYE CABLE TIE | | |
|--|----------|-----------------|------------------------------------|-----------------|--------------------|---------------------------|------------------|-------------------|
| Fixing | Part No. | Description | Cable Tie | Part No. | Description | Tensile Strength | Max. Bundle Dia. | Overall Length |
| | | Stainless | Orientation | Stainless/Black | | Lbs. N | in. mm. | in. mm. |
| For Panels from .06" (1.5mm) to .12" (3.0mm) Thick | | | | | | | | |
| Top | S6474 | SunRunner CT | Perpendicular | S14275-12 | S6474-TP-50-078-12 | 50 | 222 | 1.77 |
| | | | Parallel | S14276-12 | S6474-TL-50-078-12 | | | 45.0 7.87 200 |
| For Panels from .12" (3.0mm) to .25" (6.4mm) Thick | | | | | | | | |
| Top | S6475 | SunRunner CT-EZ | Perpendicular | S14280-12 | S6475-TP-50-078-12 | 50 | 222 | 1.77 |
| | | | Parallel | S14281-12 | S6475-TL-50-078-12 | | | 45.0 7.87 200 |

PERPENDICULAR

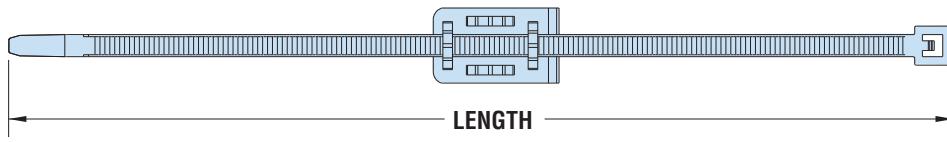

S14275, S14280, S14275-12, S14280-12

PARALLEL

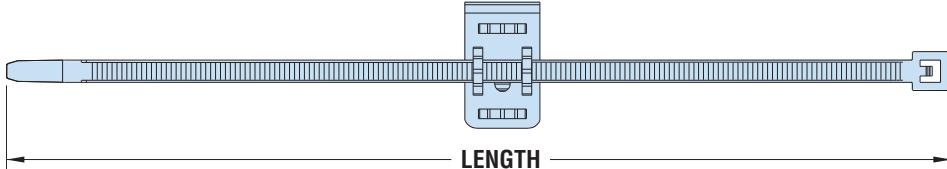

S14276, S14281, S14276-12, S14281-12

Material

S6474 & S6475 Clips: 304 stainless steel
Cable Tie: Nylon 6/6 high impact modified, heat and UV stabilized or Nylon 12

Flammability Rating

94V-2

Temperature Range

-40°F (-40°C) to 221°F (105°C)

*Quick
Specs*