




- Feature metal pawl for high strength and better durability.
- Self-locking head design speeds installation and locks into place at any length along the tie body.
- Provide a strong, durable method of cable bundling.
- Can be used in a wide range of indoor, outdoor, and underground (including direct burial) applications.
- Smooth surfaces and rounded edges assure cable protection and worker safety.
- Part Description Key: NTMP-XXX-YYY where XXX = tensile (foot pounds) and YYY = length (inches x 10).
- These parts are not covered under Heyco's solar warranty.

For Heyco's
complete line of Nylon
Cable Ties & Platforms,
see pages 7-64
thru 7-69

Heyco[®] Nytyes[®] with Stainless Steel Locking Device

PART SPECIFICATIONS				PART NO.		DESCRIPTION		PART DIMENSIONS					
Min. Tensile Strength Lbs. N	Max. Bundle Diameter in. mm.	Natural	Black					A Length in. mm.	B Width in. mm.	C Thickness in. mm.			
18 80	.87 22,0	13000	13000B	NTMP-018-039		3.90 100	.12 3,0	.04 1,1					
35 160	1.42 36,0	13001	13001B	NTMP-036-059		5.90 150	.16 4,0	.05 1,2					
45 200	2.09 53,0	13002	13002B	NTMP-036-079		7.90 200	.20 5,0						
	2.56 65,0	13003	13003B	NTMP-045-098		9.80 250							
	2.99 76,0	13004	13004B	NTMP-045-118		11.80 300							
56 250	2.09 53,0	13008	13008B	NTMP-056-079		7.90 200							
	2.60 66,0	13009	13009B	NTMP-056-094		9.40 240							
	2.99 76,0	13010	13010B	NTMP-056-118		11.80 300							
112 500	2.99 76,0	13011	13011B	NTMP-112-118		11.80 300							
	3.74 95,0	13012	13012B	NTMP-112-138		13.80 350							
	4.45 113,0	13013	13013B	NTMP-112-157		15.70 400							
124 550	4.72 120,0	13014	13014B	NTMP-124-177		17.70 450							
	6.22 158,0	13015	13015B	NTMP-124-197		19.70 500							

Standard colors natural and UV Black.

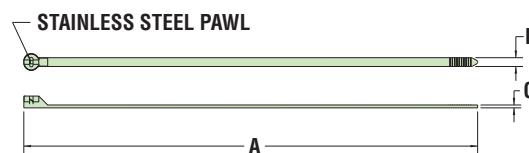

Material	Nylon 6/6 wire tie with a stainless steel locking pawl
Flammability Rating	94V-2
Temperature Range	-40°F (-40°C) to 185°F (85°C)


UL
APPROVED

Heyco[®] SunBundler[®]

Crimp Lock PVC Coated Stainless Steel Wire Cable Ties

PART SPECIFICATIONS				PART NO.		DESCRIPTION		PART DIMENSIONS			
Max. Tensile Strength Lbs. N	Max. Bundle Diameter in. mm.	100 Pack	Bulk					A Length in. mm.	B Diameter in. mm.		
Black vinyl jacketed 302/304 stainless steel wire											
100 440	2.30 58,4	S6408	S6409	SunBundler [®] 8	8	203					
	2.92 74,2	S6410	S6411	SunBundler [®] 10	10	254					
	3.88 98,6	S6412	S6413	SunBundler [®] 12	12	305					
	4.20 106,7	S6414	S6415	SunBundler [®] 14	14	356					
	6.36 161,5	S6420	S6421	SunBundler [®] 20	20	508					

Standard color Black.

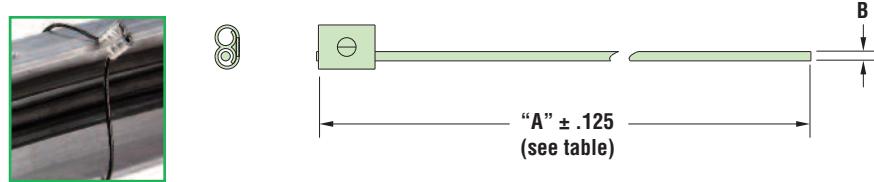

Material	Commercial Aircraft Grade 302/304 stainless wire w/UV protected vinyl jacket
Certifications	Certified by Underwriters' Laboratories for Compliance to both Canadian and U.S. Requirements under File E54523
Temperature Range	-40°F (-40°C) to 221°F (105°C)