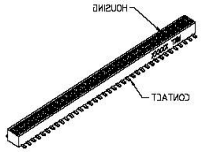
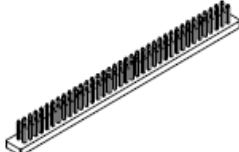
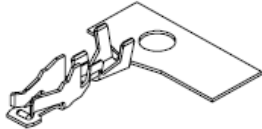
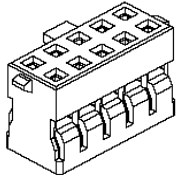
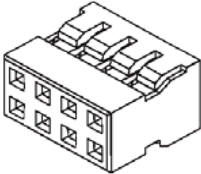
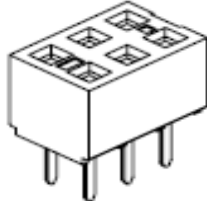
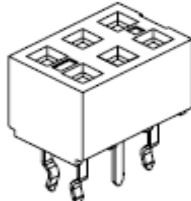
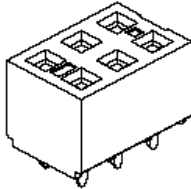
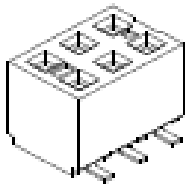
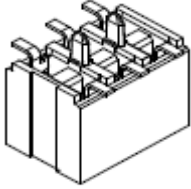
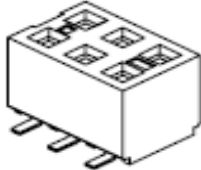
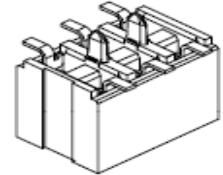
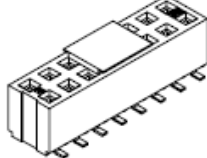
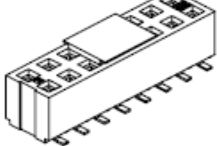
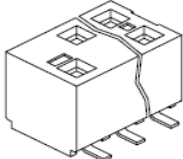
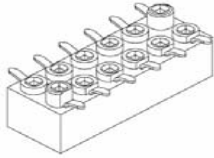
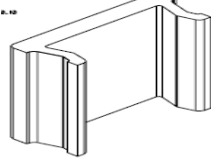
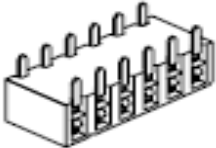
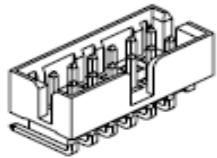
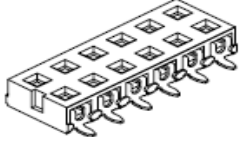
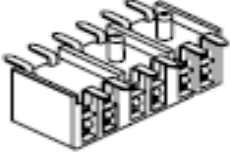
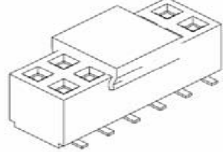
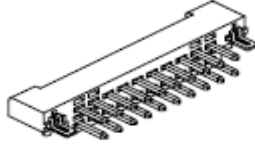
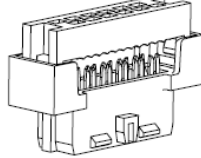
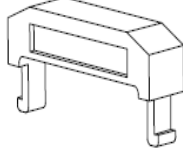
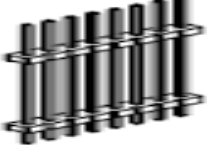
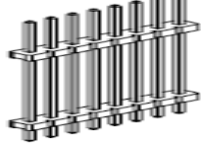
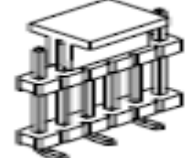
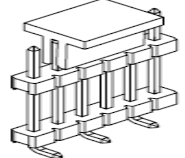
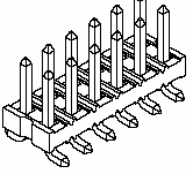
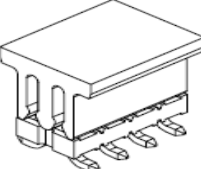
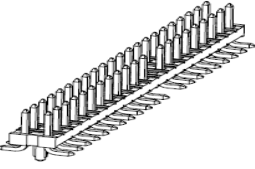
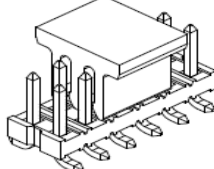
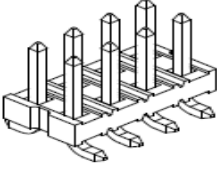
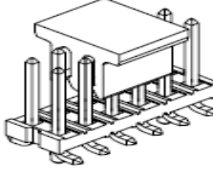
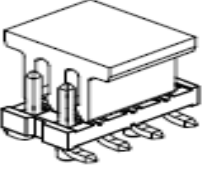
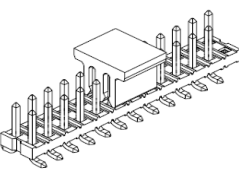
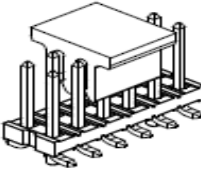
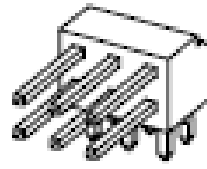
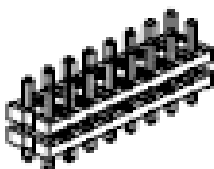
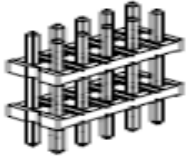
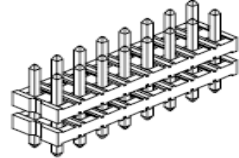
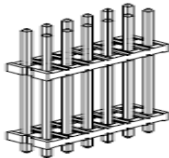
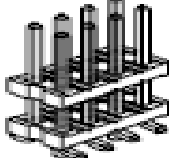
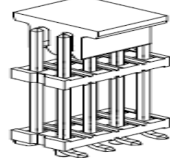
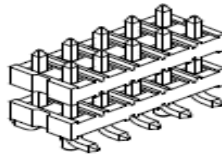
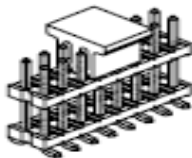
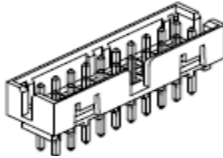
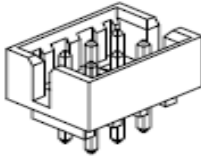
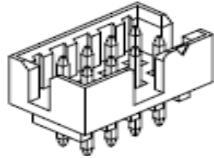
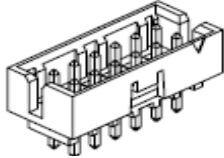
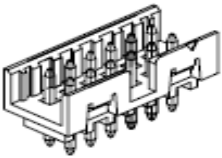
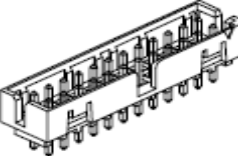
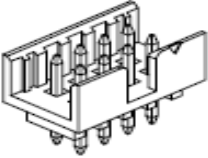
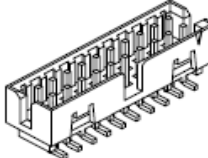
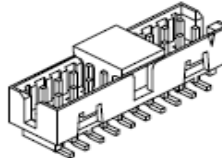
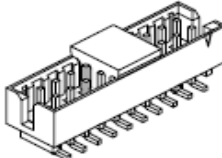
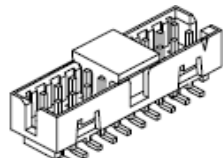
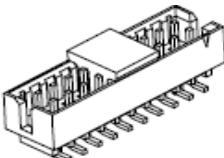
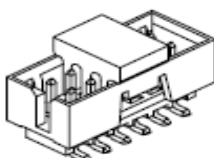
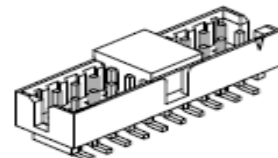
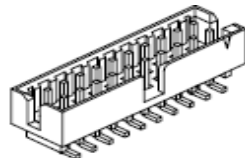
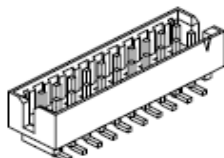
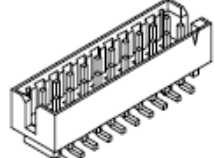
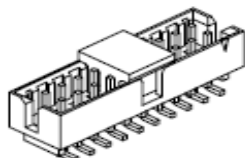
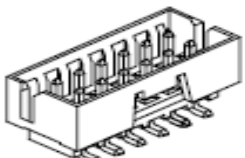
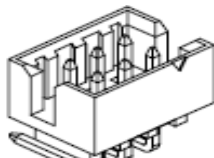
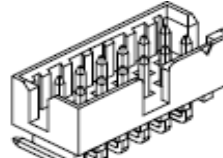
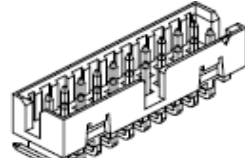
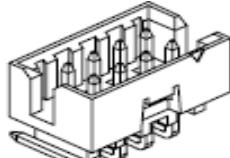
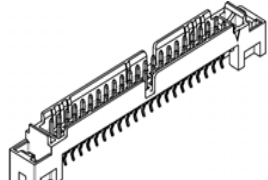
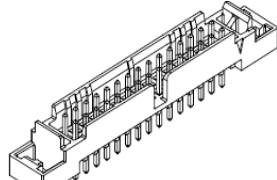
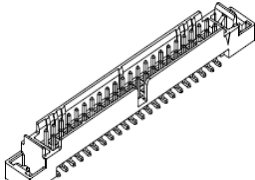
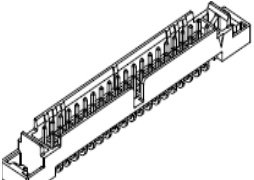
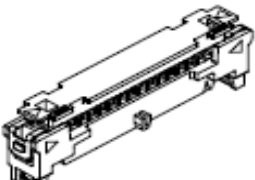
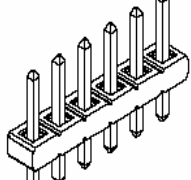
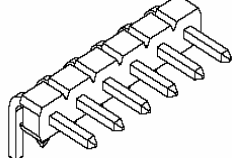
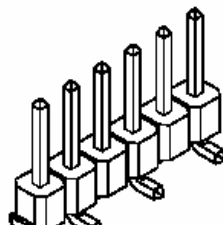
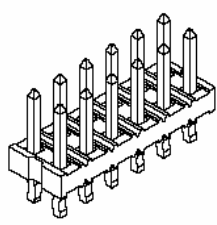
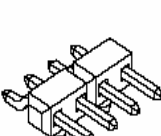
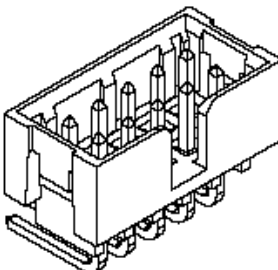
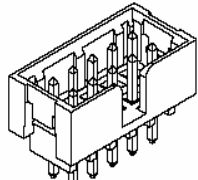
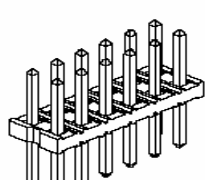


Milli-Grid Products

 48281-001 1.27mm Socket 74 CKTS Vertical SMT	 48282-001 1.27mm Header 74 CKTS Vertical DIP	 50394-A 2mm Grid Wire-To- Board, Crimp Terminal	 78045-001 2mm Wire-To-Board, Crimp Receptacle Housing w/Side Locks	 51110 2mm Grid, Wire-To- Board, Crimp Receptacle Housing	 79107 2mm Dual Row Vertical Receptacle T/H	 79107-100 2mm Dual Row Vertical Receptacle T/H w/Kink	 79108 2mm Dual Row, FFC Vertical Receptacle	 79109 2mm Dual Row Vertical Receptacle, SMT	 79109 2mm Dual Row Vertical Receptacle, SMT
 79109-A 2mm Dual Row SMT Assy. Vertical Receptacle	 79109-B 2mm Dual Row SMT Assy. Vertical Receptacle	 79109-014 2mm Dual Row SMT w/Cap & Pegs Vertical Receptacle	 79109-018 2mm Dual Row SMT w/Cap Vertical Receptacle	 79109-5003 2mm Dual Row Vertical Receptacle, SMT	 87263 Receptacle, Surface MT, Bottom Entry	 87263-7003 Cover, Slip-off Mgrid Receptacles (4.2 Width)	 87264-A Side Entry Receptacle Right Angel Mount	 87333-A Right Angel Shrouded Header w/Slot, Standoffs	 87340-004 VLPR 2mm Dual Row Top Entry Receptacle SMT
 87368-A 2mm Dual Row Side Entry Receptacle SMT	 87381 Top Entry Receptacle 4.5mm HT., SMT	 87526-011 I/O Header 4.6mm HT. (2.1mm above PCB) w/Fitting Nail	 87568-A 2mm Dual Row IDT Receptacle	 87569-008 2mm Dual Row IDT	 87755-A 2mm Pitch Single Row Header, Dual Wafer T/H	 87755-030 2mm Pitch Single Row Header, Dual Wafer Vertical T/H	 87756-A 2mm Pitch Single Row Header, Dual Wafer, SMT	 87756-001 2mm Pitch Single Row Header, Dual Wafer, SMT	 87759 2mm Dual Row Header, SMT
 87759-100 2mm Dual Row Header, SMT w/Shrouded Cap	 87759-231 2mm Pitch, Header Dual Row S/Wafer, SMT	 87759-247 Dual Row Header Single Wafer, SMT	 87759-249 Dual Row Header Single Wafer, SMT	 87759-257 2mm Pitch Dual Row Header Single Wafer SMT	 87759-277 2mm Pitch Dual Row Header, Single Wafer, SMT	 87759-278 2.54mm Pitch Dual Row Header Single Wafer, SMT	 87759-297 Dual Row SMT Header w/ Or w/o Loc. Pegs, LF	 87760-145 2mm Dual Row Header w/Kink, R/A	 87761-A 2mm Dual Row Dual Wafer Header, Vertical T/H
 87761-048 Dual Row Dual Wafer Header, T/H	 87761-052 2mm Dual Row Dual Wafer Header, Vertical T/H	 87761-058 Dual Wafer Header, Vertical T/H	 87762-A 2mm Pitch w/Peg Dual Row Dual Wafer, SMT	 87762-058 2mm Pitch, Header Dual Row Dual Wafer w/Peg, SMT	 87762-135 2mm Pitch w/Peg Dual Row Dual Wafer, SMT	 87762-136 Dual Row Header Dual Wafer, SMT	 87762-136 Dual Row Header Dual Wafer, SMT	 87762-151 Dual Row Header Dual Wafer w/Peg, SMT	 87762-175 2mm Pitch Dual Row Header Dual Wafer, SMT

 87831-053 Vertical Shrouded Header w/Locating Peg & Locking Windows US\$0.023/ckt	 87831-055 Shrouded Header, T/H w/o Slot & Locking Windows	 87831-056 Shrouded Header Vertical, w/Slot w/o Lock	 87831-057 Shrouded Header, T/H w/Center Locking Windows	 87831-058 Shrouded Header Vertical, w/Slot Locks & Open End Wall	 87831-059 Shrouded Header, T/H w/Slot & Locking Windows	 87831-060 Shrouded Header Vertical, w/Slot Open Wall w/o Lock	 87832-005 Shrouded Header w/Pegs / Lock / Polarizing Slot, SMT	 87832-006 Shrouded Header w/Pegs / Lock / Polarization Slot, SMT	 87832-007 Shrouded Header w/Cap, SMT
 87832-008 Shrouded Header w/Cap / Lock / Polarizing Slot, SMT	 87832-009 Shrouded Header SMT, w/Pegs / Cap	 87832-010 Shrouded Header SMT, w/Pegs / Cap / Lock	 87832-011 Shrouded Header SMT, w/ Polarization Slot	 87832-012 Shrouded Header SMT, w/Pegs / Polarization Slot	 87832-013 Shrouded Header SMT, w/Pegs	 87832-014 Shrouded Header SMT	 87832-015 Shrouded Header w/Polarizing Slot / Cap, SMT	 87832-016 2mm Shrouded Header SMT, in Tube and T&R w/o Cap, w/1 Window	 87833-001 Shrouded Header w/o Lock & Slot R/A
 87833-002 Shrouded Header w/Slot, w/o Lock R/A	 87833-003 Shrouded Header w/2 Locks & Slot R/A	 87833-004 Shrouded Header w/Lock, w/o Slot R/A	 87981-001 Shrouded Header Straddle Mount w/Embossed Metal Latch Slot	 87982-001 Shrouded Header Vertical w/Embossed Metal Latch Slot	 87983-001 Shrouded Header w/Embossed Metal Latch Slot SMT	 87984-001 Shrouded Header Right-Angle w/Embossed Metal Latch Slot	 87985-014 2mm IDT Receptacle w/Embossed Metal Latch	 87752	 87754
 87753	 87830	 87858	 78046	 78246	 87758				