

Series 851,853,855-PP-NNN-20-001101
Right Angle Solder tail, 1,27mm pin pitch sockets

PRECI-DIP is pleased to introduce our series of precision single, double, and triple row right angle machined solder tail sockets on 1,27mm pin spacing, ideal for tight-packaging applications. High-density 85x series sockets accept mating pin diameters between 0,38mm to 0,50mm. Each receptacle is rated to 1A current. All 85x sockets are RoHS compliant and manufactured with high-temperature insulators suitable for reflow soldering process. Inside of every preci-dip receptacle is a precision stamped, multi-finger, beryllium copper clip which provides a reliable mechanical and electrical connection to the mating pin. Brass socket shells are high-speed machined to precision tolerances.

Part Number – enter PP and NNN selections

Single Row: 851-PP-NNN-20-001101

Double Row: 853-PP-NNN-20-001101

Triple Row: 855-PP-NNN-20-001101



PP = Select plating

87= Tin plating on shell, Flash gold on contact clip.

83= Tin plating on shell, 0,75µm gold on contact clip.

Two-piece construction of shell and contact clip.

NNN = Specify number of positions

851...20-001 single row from 002 to 050 positions.

853...20-001 double row from 004 to 100 positions.


855...20-001 triple row from 009 to 150 positions.



855 Series is triple row



851-87-010-20-001101

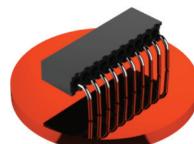

10 positions smaller than a penny.



855-87-015-20-001101



853-87-020-20-001101