



High Frequency Wire Wound Transformers

PA4470.XXXNL



Features and Benefits



- ER7.5 – 8 Pins SMD Platform
- Power Range: Up to 1.8 W
- Topology: Flyback
- Isolation Voltage: 1650 VDC
- Easy design in solution
- Small board space
- Low cost
- No optocoupler needed

Package Sizes and Quantity

- 9.5 x 8.0 x 6.0 mm Max– 700pcs/Reel

Applications:

- Isolated power design
- Sensor interfaces
- Isolated telecom converters
- Power over Ethernet
- Industrial Control
- Motor Control
- Switched Mode Power Supply

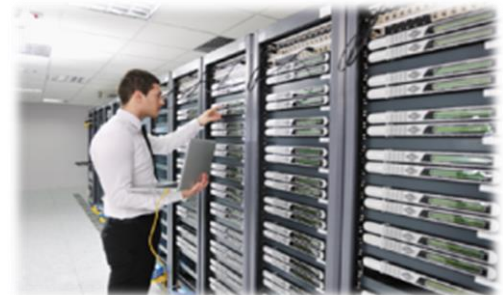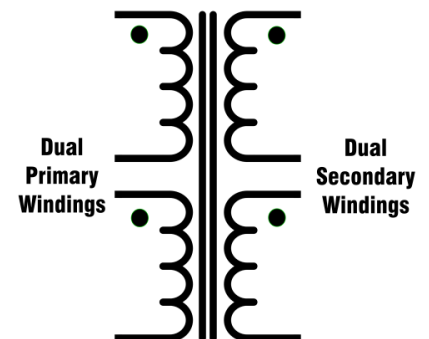

[Order Samples](#)

[Visit Site](#)



"The Pulse Power Business Unit offers a broad range of catalog and custom magnetics used in AC/DC power supply and DC/DC converter applications: power inductors, high-frequency power transformers, common mode chokes, gate drive transformers, and current sense magnetics".