


PART NUMBER BREAKDOWN

XLRnet A AND B TYPE Printed Circuit Board Connectors

E. G. **RJX8FB5HLRREB**
RJX (Series Prefix), **8** (Contacts), **F**emale **B** type, **5** Cat5E Horizontal, Latchless,
Red - Red LEDs, **EMI** / RFI Hood, **Bulk** Packaged.

SERIES PREFIX	RJX	=	Series Prefix
CONTACT LAYOUT	8	=	RJ45 type
GENDER	F	=	Receptacle housing
SHELL SERIES	A B	=	A Type B Type
TRANSMISSION CLASS	3 5 6	=	Class D CAT 5e CAT 6
TERMINATION	H V	=	Horizontal Printed Circuit Board Vertical Printed Circuit Board
LOCKING MECHANISM	Blank P	=	Latching Push lever supplied separately for customer installation (Contact factory for detailed fitting instructions)
LED COLOUR SEQUENCE*	Blank RG RY RR GR GY GG YR YY YG UU	=	No LEDs Red / Green Red / Yellow Red / Red Green / Red Green / Yellow Green / Green Yellow / Red Yellow / Yellow Yellow / Green Blue / Blue
EMI / RFI SHIELDING HOOD	Blank E	=	No shield hood EMI / RFI shield hood
PACKAGING	Blank B	=	Individual Bulk packed

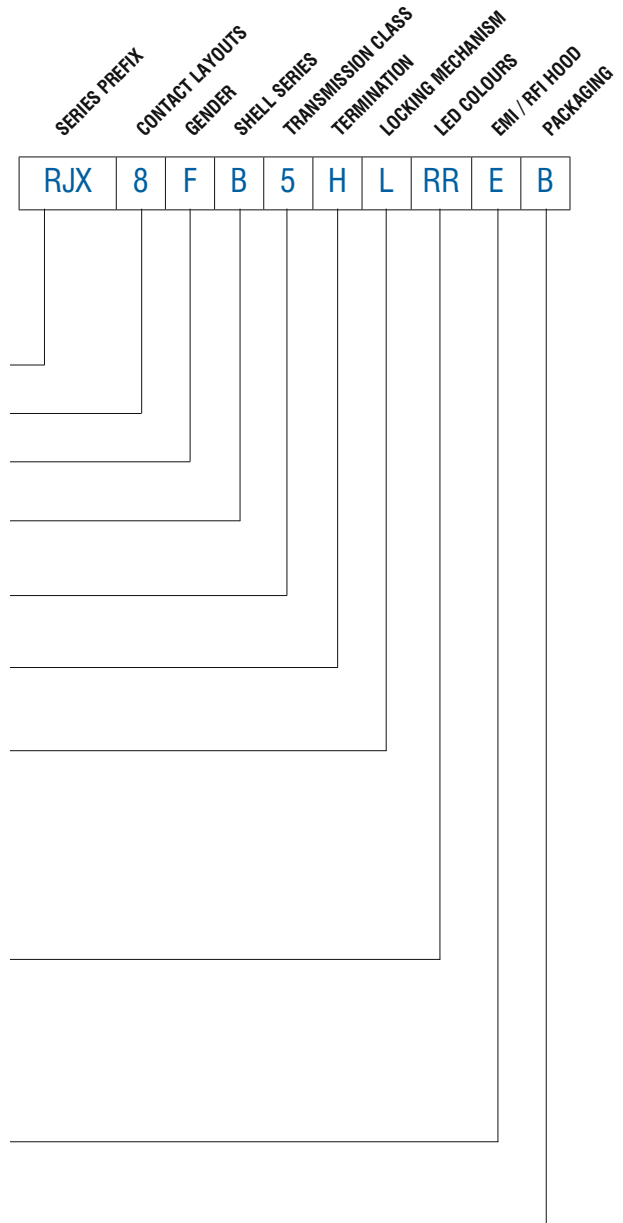

*Note: LED colours are denoted left to right from the panel side front view.
Refer Page 79