


STAR-BUENO Snap Ferrite with optical closing control mechanism

Characteristics:

- Internal prefixing cable system facilitates the cable assembly process
- The security lock guarantees electromagnetic compatibility because only authorized persons can unlock the snap ferrite with the STAR-TEC key
- Classification of the plastic case: UL94-V0
- Operating temperature: -25°C to +105°C

Applications:

- EMC ferrite for the EMI suppression in the frequency area from 1MHz to 1GHz
- Fastening for round cables with diameters from 2.5 mm to 8.5 mm or if or if winded more turns through the ferrite
- Reusable because of the key technology therefore perfect for test and measuring purposes in EMC labs

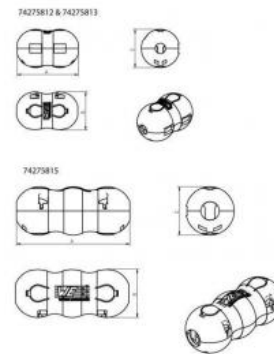

Electrical properties

	Order Code	Colour	Z @ 25 MHz 1 turn (Ω)	Z @ 100 MHz 1 turn (Ω)	Cable diameter (mm)	Material	A (mm)	B (mm)	C (mm)	Download
	74275812	Grey	100	150	2.5-5.0	4W620	28.0	20.0	20.0	  
	74275813	Grey	120	200	4.5-8.5	4W620	39.0	24.0	24.0	  
	74275815	Grey	180	250	4.5-8.5	4W620	55.0	24.0	24.0	  

74271 safety keys (5pcs.)

- [To Parameter Search](#)
- Please contact our [24h eMail hotline](#) for questions and feedback