

FLEX Cable Connectors

HF507, HF509, and NNS Series

HF507 FLEX Cable Connectors


- Side Latch Locking Design
- Offering various mounting options (R/A & Vertical)
- Pitch: 0.50 mm
- Available Pin Count: 21 – 80pins



Product PN	Available Pin Count	Description	Design Option
HF507S Series	21, 31, 41, 51, 80	Receptacle Connectors	Right Angle Mount Vertical Mount
HF507P Series	21, 31, 41, 51, 80	Plug connector	With or Without Shielding

HF509 FLEX Cable Connectors

- Side Latch Locking Design
- EMI Enhanced design with Shell GND
- 10 Gbps Transmission Speed
- Pitch: 0.50 mm
- Available Pin Count: 10 pins

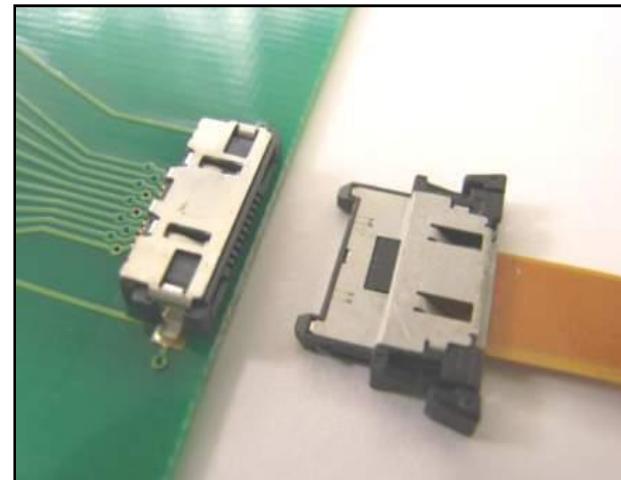


Product PN	Available Pin Count	Description
HF509S Series	10pin	Receptacle Connectors
HF509P Series	10pin	Plug connector

FLEX Cable Connectors

HF507, HF509, and NNS Series

NNS SATA Cable Connectors

- Side Latch Locking Design
- Direct connection to HDD-SATA & ODD-SATA interface without additional PCB = Cost Saving
- Pitch: 1.27 mm
- Available Pin Count: 22pins

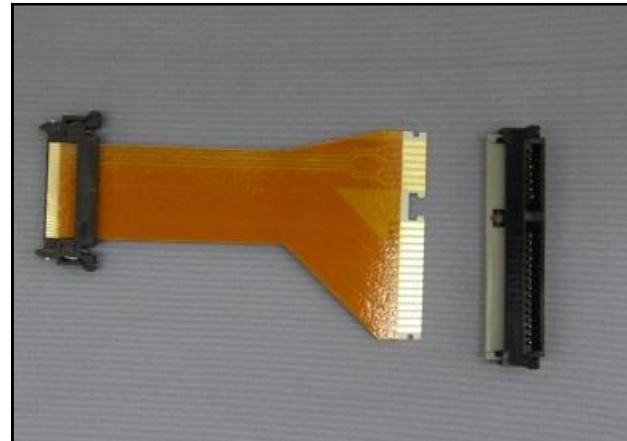

Product PN	Available Pin Count	Description
NNS022S-1001-0	22pins	SATA Flex Cable Assembly Connectors

HF507, HF509, and NNS022 Series Application




ODD-SATA & HDD-SATA Drive Device Connection



Medical Hand-Held & Stationary Monitor



Commercial TV and Electronics Monitors

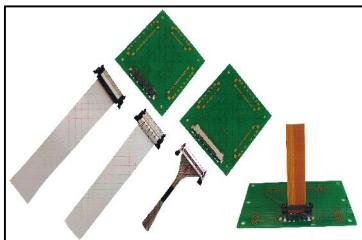

General Flex-to-Board Connections



Automotive Infotainment System Connection



Industrial Computer & Automation Camera