


Keysight N5700 and N8700 Series System DC Power Supplies

Family of affordable, high-density, 750 W to 5000 W DC power supplies

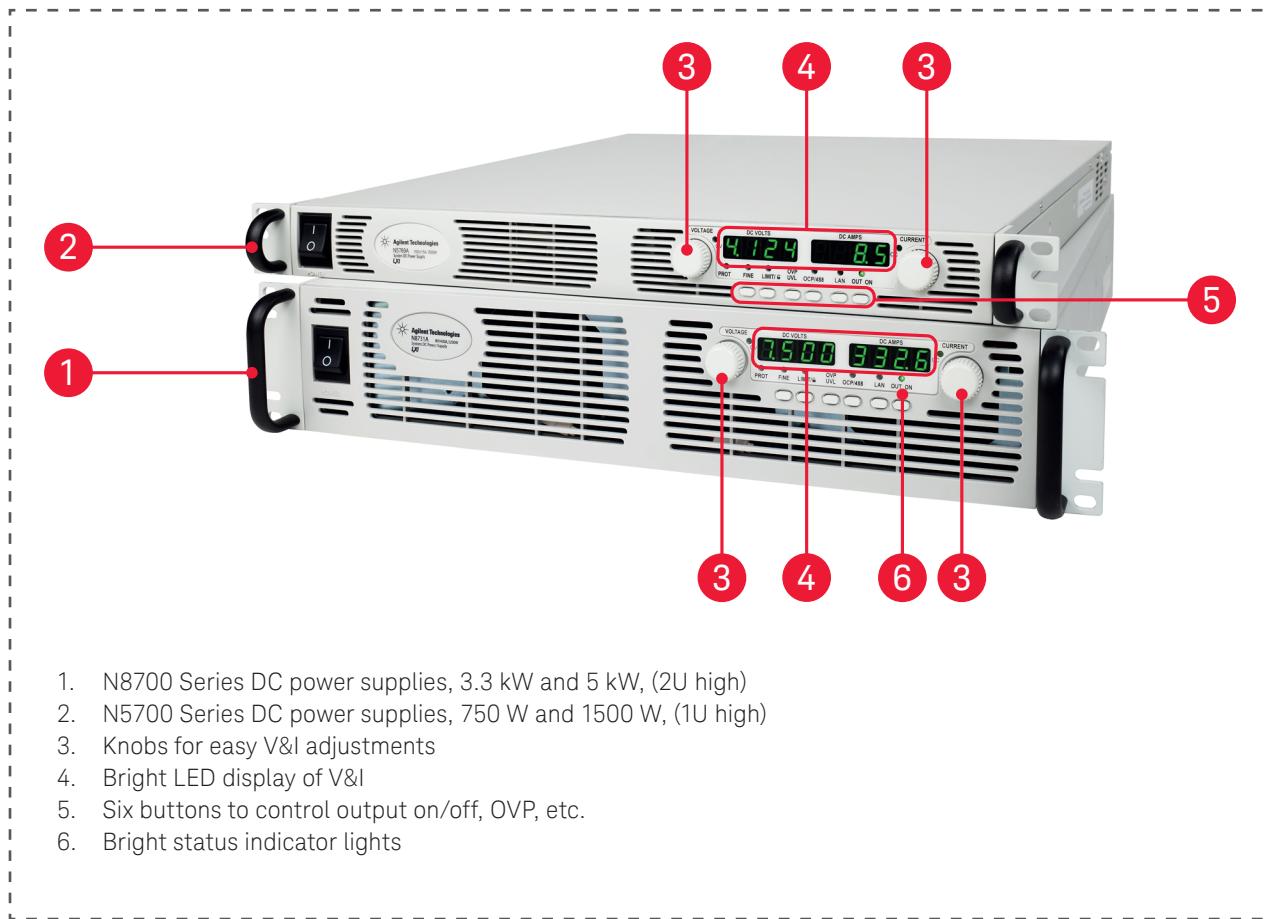

Key features

- 45 models: 750 W, 1500 W, 3300 W and 5000 W
- Output up to 600 V and up to 400 A
- Small, high-density 1U and 2U
- Built-in voltage and current measurements
- Outputs can be connected in parallel or in series
- Analog programming and monitoring
- GPIB, LAN (LXI Core), USB 2.0 interfaces standard
- Over-voltage, over-current and over-temperature protection

750 W to 5000 W output power

	N5700 - 750 W	N5700 - 1500 W	N8700 - 3.3 kW	N8700 - 5 kW
Form factor	1U, full rack	1U, full rack	2U, full rack	2U, full rack
Output power	750 W	1.5 kW	3.3 kW	5 kW
Voltage	Up to 600 V	Up to 600 V	Up to 600 V	Up to 600 V
Current	Up to 100 A	Up to 180 A	Up to 400 A	Up to 250 A
Interface	GPIB, USB, LAN (LXI Core)	GPIB, USB, LAN (LXI Core)	GPIB, USB, LAN (LXI Core)	GPIB, USB, LAN (LXI Core)
Features	Analog program, universal AC input 16 store/recall states, web server	Analog program, universal AC input 16 store/recall states, web server	Analog programming 16 store/recall state, web server	Analog programming 16 store/recall states, web server

Options and accessories

Option	Description
N5740A	Rack-mount slide kit

Three-Year Warranty



www.keysight.com/find/ThreeYearWarranty

Keysight's committed to superior product quality and lower total cost of ownership. Keysight is the only test and measurement company with a three-year warranty standard on all instruments, worldwide. And, we provide a one-year warranty on many accessories, calibration devices, systems and custom products.

Keysight Assurance Plans



www.keysight.com/find/AssurancePlans

Up to ten years of protection and no budgetary surprises to ensure your instruments are operating to specification, so you can rely on accurate measurements.